

MINIATURE SWITCHES

3.5x6mm Tact Switches

- Compact design
- Advanced switch technology
- Positive tactile action
- Tamper proof application
- Flow solder wash-away cleaning
- Through-hole PCB and surface mount terminals
- Can be supplied taped for auto-insertion, add suffix /T


SPECIFICATION

Rating	50mA/12VDC	
Contact resistance	100mΩ max	
Insulation strength	100MΩ min/500VDC	
Electrical life	50,000 operations min	
Temperature range	-10°C to +60°C	
Operating force	180 ± 100g	
Material	Case	Nylon
	Button	Nylon
	Contacts	Stainless Steel Silver Plated
Terminals	Brass Silver Plated	

Through-hole PCB Terminals

TYPE NO.	BUTTON HEIGHT
CST35643T	4.3mm
CST35605T	5.0mm


CST356T

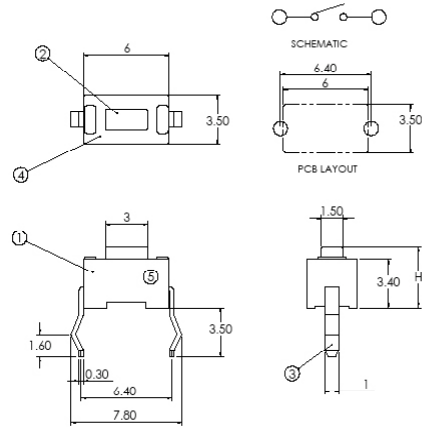

Surface Mount Terminals

TYPE NO.	BUTTON HEIGHT
CST35643S	4.3mm
CST35605S	5.0mm

CST356S

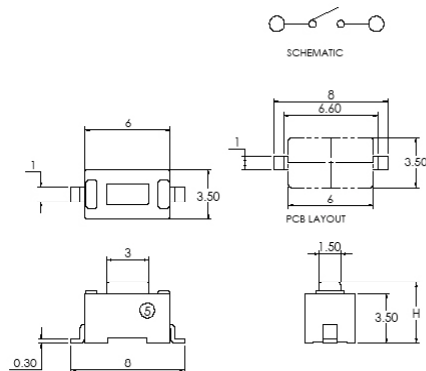

CST356 Series Replaces CB00.5 Series
 Example CST35643T replaces CB00.5-1F
 Example CST35605S replaces CB00.5-5HS