




## STAS 20 grau/grey

Industrial Connectors:Rectangular connectors ST-series:Cable plug

### Product description

Description	Cable plug with strain relief
Type	STAS 20 grau/grey
Order No.	931 265-106
Type of contact	male
Number of contacts	2 + PE
Cable gland	PG 7
Cable diameter	4 mm to 6.5 mm
Conductor size	max. 1.5 mm <sup>2</sup>
Housing Color	grey
Contact bearer color	black

### Drawing

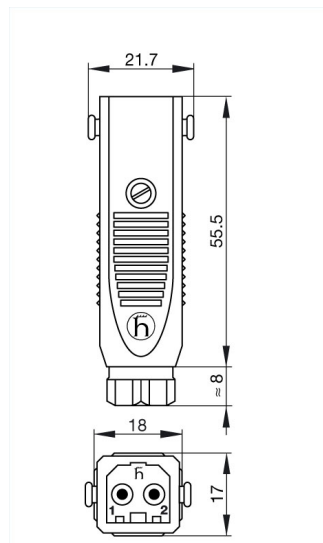

### Technical data

Pin dimensions	2 mm
Rated voltage	250 V AC/DC
Rated current	DC 10 A / AC 16 A
Contact resistance	≤ 5 mOhm
Type of termination	screw

### Material

Contact material	Cu Zn
Contact surface material	Sn
Contact bearer material	PA
Housing material	PA

### Environmental conditions

Protection class (IEC 60529)	IP 54
Pollution severity	3
Temperature range	-30 °C to +90 °C

### Inflammability class

Housing	UL 94 HB
Contact bearer	UL 94 V-1
<b>Approvals</b>	
UL	UL
<b>Packing unit</b>	
Packaging unit	100 pieces
<b>Scope of delivery and accessories</b>	
Accessories to order separately	safety brackets STASI 2, order no. 732 044-000