


GDME GB1

Industrial Connectors:Rectangular connectors GDM-series:Type AEN 175301-803 (DIN 43650) / ISO 4400:Electronic inserts for GDME

Product description	
Description	bridge-type rectifier with protective circuit (varistor)
Type	GDME GB1
Order No.	831 832-001
Standard	DIN EN 175 301-803-A
Construction type	A
Description of Wiring	
Voltage rectifier	bridge-type rectifier
Suppressor	varistor
Drawing	

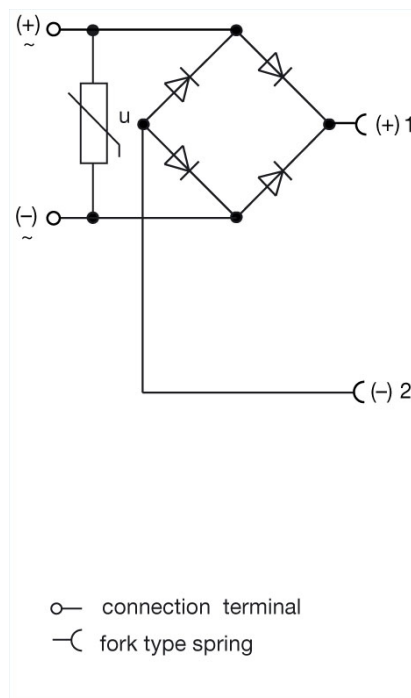

Technical data	
Rated voltage	AC/DC 250 V
Rated current	2 A (SEV 1011 : 1.5 A) AC / 1 A DC
Environmental conditions	
Temperature range	-40 °C to +110 °C
Packing unit	
Packaging unit	50 pieces