




## BU 10

Industrial Connectors:Measuring and Testing Equipment:Sockets:4 mm system

### Product description

Description	Bright metal 4 mm diameter nickel-plated brass socket with solder connection. Length 22 mm.
Type	BU 10
Order No.	930 147 - 000
System	4 mm system
Housing Color	red

### Drawing

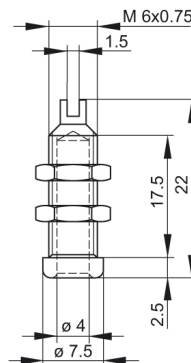

### Technical data

Type of contact	socket
Type of termination	solder
Rated voltage	DC 60 V
Rated current	16 A
Contact resistance	5 mOhm
Mounting	screw

### Material

Contact material	brass
Contact surface material	nickel-plated

### Environmental conditions

Temperature range	-25 °C to +100 °C
-------------------	-------------------

### Inflammability class

Housing	94 V-0
---------	--------