

workbenches TP/TPH/SAP



Designed for use in today's production and assembly environments, this definitive modular system, developed over more than 35 years, provides a high quality working environment. Customise your workstation to your own requirements.



There is a large range of workbench accessories available, see page 11.

1. Workbench TP

Height adjustment with allen-key between 650...900 mm. Frames are of epoxy powder coated steel in grey RAL 7045. The worktops are of 26 mm ESD-laminate.

2. Workbench TPH

Height adjustment with allen-key between 650...900 mm. Workbench with upright profiles and a laminate shelf, height adjustment between 1080...1550 mm, load capacity 50 kg. Construction as TP. There are a large range of workbench accessories available, see page 11.

3. Moveable bench SAP

Construction as TP. Height adjustment with allen key between 650..900 mm. Swivel castors Ø 100 mm of which two are semiconductive and two braked. Load capacity 150 kg. Lower shelf and push handle available separately.

4. Lower shelf AT

For moveable bench. 26 mm ESD-laminate.

5. Handle PUSH

For moveable bench.

No.	Code	Worktop mm	Shelf mm	Load capacity static u.d.l.
1	TP 510 ESD	500 x 1000		150 kg
	TP 710 ESD	700 x 1000		300 kg
	TP 712 ESD	700 x 1200		300 kg
	TP 715 ESD	700 x 1500		300 kg
	TP 718 ESD	700 x 1800		300 kg
	TP 915 ESD	900 x 1500		300 kg
	TP 918 ESD	900 x 1800		300 kg
	2	TPH 712 ESD	700 x 1200	310 x 1200
TPH 715 ESD		700 x 1500	310 x 1500	300 kg
TPH 718 ESD		700 x 1800	310 x 1800	300 kg
TPH 915 ESD		900 x 1500	310 x 1500	300 kg
TPH 918 ESD		900 x 1800	310 x 1800	300 kg
3		SAP 507 ESD	500 x 700	
	SAP 710 ESD	700 x 1000		150 kg
	SAP 715 ESD	700 x 1500		150 kg
4	AT 507 ESD	500 x 700		40 kg
	AT 710 ESD	700 x 1000		40 kg
5	PUSH 50	depth 500		
	PUSH 70	depth 700		



angle extension TP-K/TP-KK



1. Angle extension TP -K

Each standard TP-workbench may also be supplied as an angle extension. Fitted to front angle of main bench. Stock sizes are shown.



2. Corner workbench TP KK

A corner workbench can be used with two TP/TP-K benches (with one H-frame pair) to create a 90 deg. angle setup. This unit consists of a worktop, two side frames and a leg in the middle. Load capacity 150 kg u.d.l. Front side 565 mm.

3. Corner workbench TPH KK

A corner workbench can be used with two TPH benches (with one H-frame pair) to create a 90 deg. angle setup. This unit consists of a worktop and all necessary components. Load capacity 150 kg u.d.l. Front side 565 mm.

No.	Code	Worktop mm	Load capacity*
1	TP 510K ESD	500 x 1000	150 kg
	TP 712K ESD	700 x 1200	150 kg
2	TP 707 KK ESD	1100 x 1100	150 kg
	TP 909 KK ESD	1300 x 1300	150 kg
3	TPH 707 KK ESD	1100 x 1100	150 kg
	TPH 909 KK ESD	1300 x 1300	150 kg

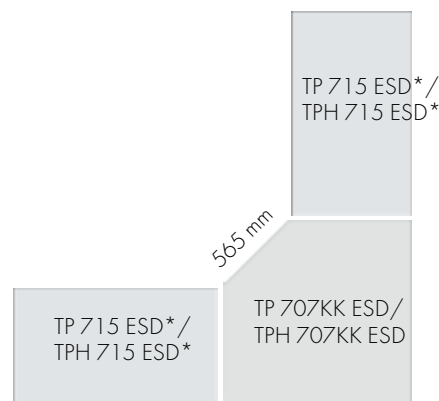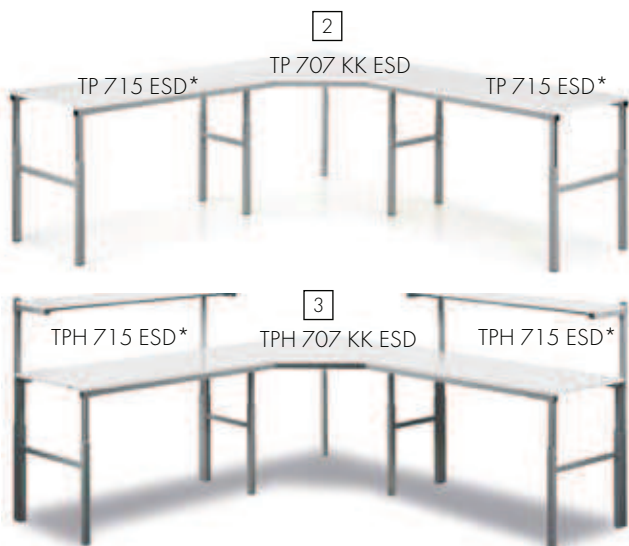

*) Workbench with one H-frame pair ***)Load capacity 150 kg u.d.l.



workbench combinations



Assembly workstation

- 1 pcs workbench TPH 715 ESD
- 1 pcs tool and lighting support KT 150
- 1 pcs extra C-profile SPR 150
- 1 pcs overlight OL 254
- 2 pcs bin rail BP 150 ESD
- 1 pcs power channel TJK 150 SET
- 3 x double socket E1
- 1 x switch E2
- 1 pcs steel cabinet ML 02 ESD



Service workstation

- 1 pcs workbench TPH 715 ESD
- 1 pcs tool and lighting support KT 150
- 1 pcs extra C-profile SPR 150
- 1 pcs overlight OL 254
- 1 pcs perforated panel RL 150
- 1 pcs panel hooks RK 1
- 1 pcs steel cabinet ML 03 ESD



Computer workstation

- 1 pcs workbench TPH 715 ESD
- 1 pcs power channel TJK 150
- 2 x double socket E1
- 1 x switch E2
- 1 x automatic fuse E3
- 1 pcs keyboard shelf NT 500 ESD
- 1 pcs PC holder CPU
- 1 pcs LCD arm MA
- 1 pcs connectores HKC-MH/MA



Universal workstation

- 1 pcs workbench TPH 715 ESD
- 1 pcs steel cabinet ML 01 ESD



Workbench with shelf TPH

Frames are of epoxy powder coated steel in grey RAL 7045. The worktops are of 26 mm ESD-laminate.

Code	Worktop D x W mm	Shelf D x W mm	Load capacity u.d.l.
TPH 712 ESD	700 x 1200	310 x 1200	300 kg
TPH 715 ESD	700 x 1500	310 x 1500	300 kg
TPH 718 ESD	700 x 1800	310 x 1800	300 kg
TPH 915 ESD	900 x 1500	310 x 1500	300 kg
TPH 918 ESD	900 x 1800	310 x 1800	300 kg

accessories for TPH workbench



Accessories are mounted between vertical C-profiles. Steel parts are epoxy powder coated in light grey RAL 7035. The shelves are 26 mm ESD-laminate

1. Metal shelf TH

Adjustment for depth, height and angle. For stacking and picking bins. Load capacity 30 kg. Semiconductive epoxy powder coated steel in light grey RAL 7035.

2. Bin profile BP

Aluminium profile for stacking/picking bins.

3. Auxiliary shelf SH

26 mm ESD-laminate shelf.

4. Perforated panel RL

Robust, perforated steel panel. 9 mm perforations at 38 mm centres. Mount on TPH-benches with connectors RK 1. Can also be attached to a wall with screws (included).

5. Tool and lighting support KT

For suspending power tools and lighting units. Includes one C-profile bar with sliding hook.

6. Cable tidy TPHCT

Mounted between C-profiles below worktop. Perforated epoxy powder coated steel.

7. Swivel arm with tray CKV

Swivel arm with lockable, angle adjustable steel tray. Load 15 kg. Semiconductive epoxy powder coated steel. Mount on C-profile.

8. Cable clip set CC

The clips locate in the 12 mm profile slot.

9. Power channel

May be fitted with a choice of components, ordered separately. 3 m cable is included. All meet with CE requirements. The finished TJK 150 SET and TJK 180 SET include 3 double sockets (E1) and a switch (E2). (Other SETs are also available.)

10. Power panel PRK 5

Outlet panel has 5 Schuco wall sockets, switch and 3 m cable. Mount on upright profile or under the laminate shelf with screws.

11. Upright profiles HKCP

If you mount both perforated panel RL and power channel TJK to TPH benches, you must order an extra-high upright profiles. Height 1470 mm.



No..	Code	Dimensions D x W x H mm	Load capacity	Suitability	
1	TH 120 ESD	145 x 1119	30 kg	TPH 712 ESD	
	TH 150 ESD	145 x 1419	30 kg	TPH 715/915 ESD	
	TH 180 ESD	145 x 1719	30 kg	TPH 718/918 ESD	
2	BP 120 ESD	profil 1115	15 kg	TPH 712 ESD	
	BP 150 ESD	profil 1415	15 kg	TPH 715/915 ESD	
	BP 180 ESD	profil 1715	15 kg	TPH 718/918 ESD	
3	SH 150 ESD	310 x 1500	50 kg	TPH 715/915 ESD	
	SH 180 ESD	310 x 1800	50 kg	TPH 718/918 ESD	
4	RL 120	750 x 1115		TPH 712 ESD	
	RL 150	750 x 1415		TPH 715/915 ESD	
	RL 180	750 x 1715		TPH 718/918 ESD	
	RK 1	Connectors		TPH ESD	
5	KT 120	600 x 1200		TPH 712 ESD	
	KT 150	600 x 1500		TPH 715/915 ESD	
	KT 180	600 x 1800		TPH 718/918 ESD	
	Extra C-profile				
	SPR 150	1500		KT 150	
6	TPHCT 120	45 x 205 x 1115		TPH 712 ESD	
	TPHCT 150	45 x 205 x 1415		TPH 715/915 ESD	
	TPHCT 180	45 x 205 x 1715		TPH 718/918 ESD	
7	CKV 400 ESD	tray 210 x 460	15 kg	TPH ESD	
8	CC 12	5 pcs/set		TPH ESD	
9	TJK 120	profil 1058		TPH 712 ESD	
	TJK 150	profil 1358		TPH 715/915 ESD	
	TJK 180	profil 1658		TPH 718/918 ESD	
	TJK 150 SET	includes 3 x E1, E2		TPH 715/915 ESD	
	TJK 180 SET	includes 3 x E1, E2		TPH 718/918 ESD	
	Components				
	E1	Double socket			
	E2	Switch			
E3	Automatic fuse 10 A				
E4	Automatic fuse /earth leakage switch 10 A/30 mA				
E5	Emergency-stop-switch				
E6	Data connector/shielded for Cat.6				
E7	Data connector/without screen for Cat.5				
E8	Pneumatic, quick coupling 3/8"				
10	PRK 5	length 350			
11	HKCP 147	height 1470			

