

Data sheet

Article Description

Line-intermediate Dimmer Type 8114

250 V ~, 50 Hz, from **20 - 200 W/VA**
L/W/H approx. 96 mm x 41 mm x 29 mm



- **rotary OFF function**
- **with protective conductor connection**
- **fuse holder accessible from the outside.**
for easy replacement of fuse

suitable for

- low voltage halogen lamps
(with magnetic transformers)
- high voltage halogen lamps
- incandescent lamps

Made in Germany


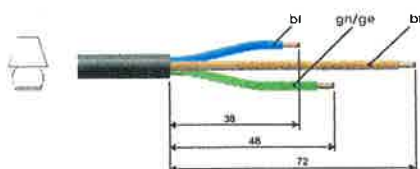


Bild 1 / illustration 1 / figure 1 / foto 1 / figura 1

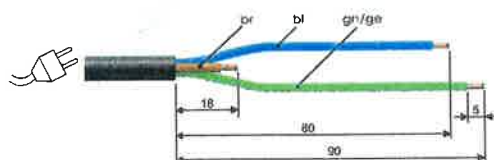

- * - Drehrad nicht aus der Leiterplatte nehmen.
- Do not remove wheel from PCB.
- Wielkje niet uit printplaat neemen.
- Ne sortez pas le rouage de la carte imprimée.
- Non togliere le rotelline dal circuito stampato.

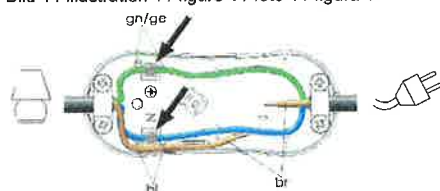


Bild 2 / illustration 2 / figure 2 / foto 2 / figura 2


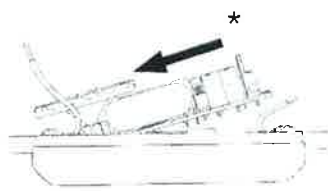


Bild 3 / illustration 3 / figure 3 / foto 3 / figura 3

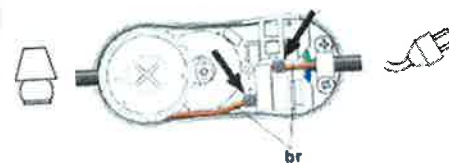

<i>inter BÄR-item</i>	<i>Colour housing</i>	<i>rotating wheel</i>
8114-004.01	black	light grey
8114-008.01	white	light grey
8114-000.01	transparent	light grey
8114-010.01	gold	black

Technical modifications reserved!

Works at 230 V-mains must only be carried out by a specialist!