

Data sheet

LED-Line-intermediate dimmer

Type 8115

leading edge dimmer

230 V ~, 50 Hz, **7 -110 W/VA**,

L/W/H 130 mm x 60 mm x 35 mm

suitable for

- **dimnable LED-lamps**
 - **low voltage halogen lamps (with magnetic transformers)**
 - **high voltage halogen lamps**
 - **incandescent lamps**
- **slider for hand- and foot operation**
 - **arbitrary connection capability (intermediate or end-dimmer)**
 - **without fuse**
 - **On/Off switch separately**



Bild 1 / illustration 1 / figure 1 / foto 1 / figura 1

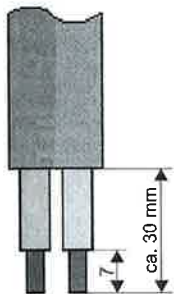


Bild 2 / illustration 2 / figure 2 / foto 2 / figura 2


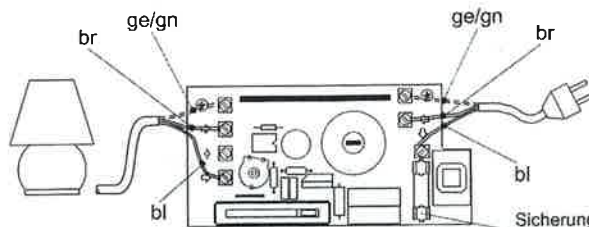


Bild 3 / illustration 3 / figure 3 / foto 3 / figura 3

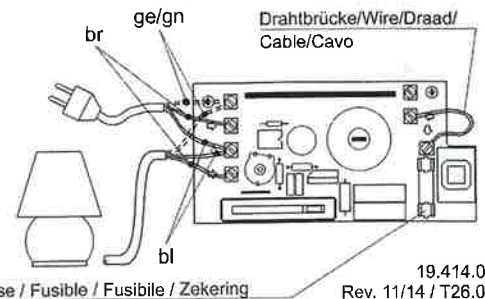

19.414.04
Rev. 11/14 / T26.07

inter BÄR-No.	colour
8115-004.01	black
8115-008.01	white
8115-000.01	transparent
8115-010.01	gold

Technical modifications reserved!
Works at 230 V-mains must only be carried out by a specialist!