

Cover for Holder OG (Clip) 5x20, OG (Halter) 5x20, UH, UHB



Weblinks


[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [Approvals](#), [CE declaration of conformity](#), [RoHS](#), [CHINA-RoHS](#), [e-Shop](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#), [Detailed request for product](#)

Technical Data

| | |
|------------------------------|------------------------------------|
| Fuse-Link | 5 x 20 mm |
| Admissible Ambient Air Temp. | -40 °C to 85 °C |
| Material: Cover | Thermoplastic Transparent UL 94V-0 |
| Storage Conditions | 0 °C to 60 °C, max. 70% r.h. |

Dimensions

26.2 mm

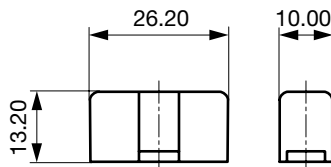

Variants

| Description | Order Number |
|-------------------------|--------------|
| Transparent Cover 1.6 W | 0853.9561 |
| Transparent Cover 2.5 W | 0853.9562 |

Packaging Unit

Plastic Bag (100 pcs.)