 
 
 
 
 
 



48.132

Viewgo monitor arm - desk 132

More comfort and space: two things this entry-level ergonomic monitor arm helps to create. Position your monitors above your desk, at a spot that's just right for you, to regain valuable desk space. Slender yet strong, this monitor arm combines a striking design with a tough steel construction.

- Static height adjustment range of 210 mm
- Independent depth adjustment
- Fitted with cable clips to guide cables tidily
- VESA MIS-D 75 x 75/100 x 100 mm compatible
- Rotate 360°, tilt +90°/-50°, swivel 360°
- Weight capacity max. 4 kg per monitor
- Comes with a desk clamp mount and bolt-through desk mount
- Suitable for desktop thicknesses of 5 up to 40 (clamp) or 60 mm (bolt through)
- Monitor size limit: width 620 - height 900 mm
- Simple height adjustment using a tightening knob
- Hassle-free installation using just one supplied tool
- Supports monitors in portrait and landscape mode
- Unique mechanism enables precise horizontal levelling

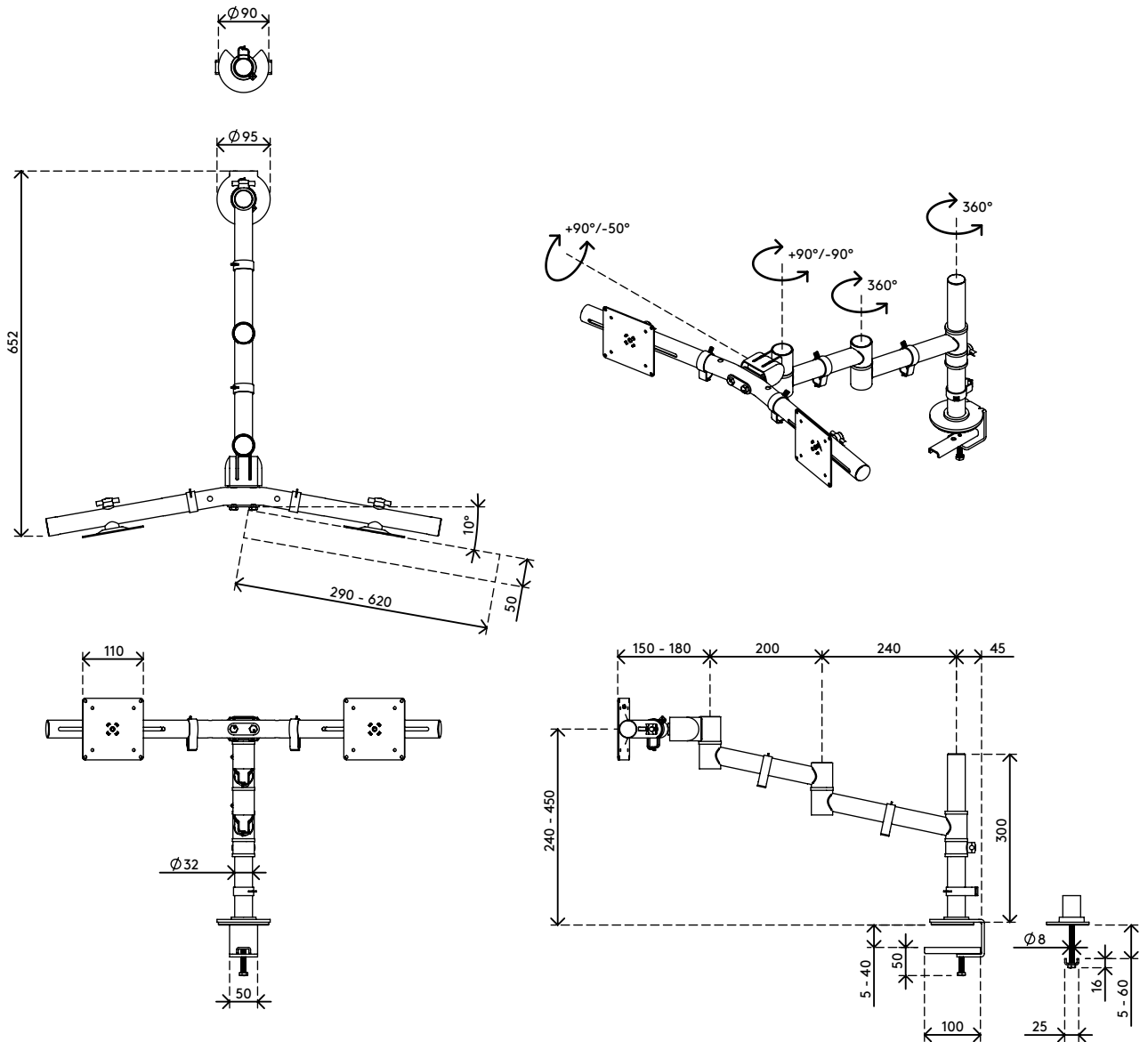

Viewgo monitor arm - desk 132

2015/10/05

48.132

736 x 192 x 130 mm

pcs

silver

4,4 kg

805410481322