

# 6289 General Purpose Single Footswitch


# herga

Technology Ltd

- Versatile, compact footswitch
- Durable and reliable with steel housing for long life and reliability (stainless steel versions available)
- Wide choice of colours and switching functions
- Customer colours and logos available on request
- Special designs to customer specifications
- Protection IPX2 or IPX7 (IPX8 on request)
- Medical versions
- Available as multiple pedal versions
- Non-electric versions possible (see air switch information)



## Outline dimensions

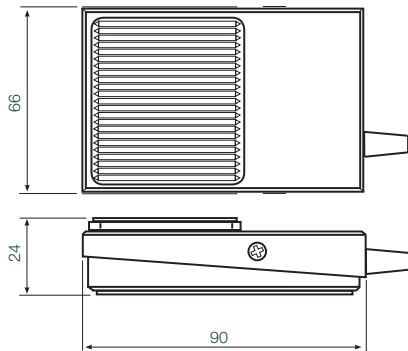

## 6289 - Range options and specifications

		Stock models								
Model part no.		6289-WO	6289-CC	6289-PP	6289-DO	6289-SC	6289-DA	6289-CT	6289-WS	
Depth	mm								90	
Width	mm								66	
Height	mm								24	
Weight	Kg								0.38	
Material	Body	16 SWG mild steel, powder coat grey hammertone							Stainless steel	
	Tread	Polypropylene, black								
	Guard	18 SWG mild steel, powder coat grey hammertone								
No. of poles & action		SPST N/O	SPCO	SPST Latching	DPST N/O	SPST N/O	DPST staggered	SPCO	SPST N/O	
Cable		2 core + earth	3 core + earth	2 core + earth	4 core + earth	2 core + earth	4 core + earth	Terminal block	2 core + earth	
Cable length as standard	m	2	2	2	2	2	2	n/a	2	
Cable O/D	mm	6.8 (nom)	6.8 (nom)	6.8 (nom)	6.8 (nom)	6.8 (nom)	6.8 (nom)	n/a	6.8 (nom)	
Current rating at 250V AC (½ HP)	A	6(1.5)	6(6)	6(3)	3(3)	6(3)	3(3)	6(3)	3(3)	
IP rating of internal switch module		IPX7	IPX2	IPX2	IPX2	IPX2	IPX2	IPX2	IPX7	
Standards		Footswitch: low voltage directive 2006/95/EC, EN 60950; Microswitch: EN 61058-2-1, EN 61058								
Operating temperature	°C								-5 to +40	

Various connection cables are available (up to protection IPX8).  
Low volume surcharge for non-standard models



Herga Technology Ltd - Northern Way - Bury St. Edmunds - Suffolk - IP32 6NN - UK  
sales@herga.com • www.herga.com • +44 (0)1284 701422

Subject to change without notice