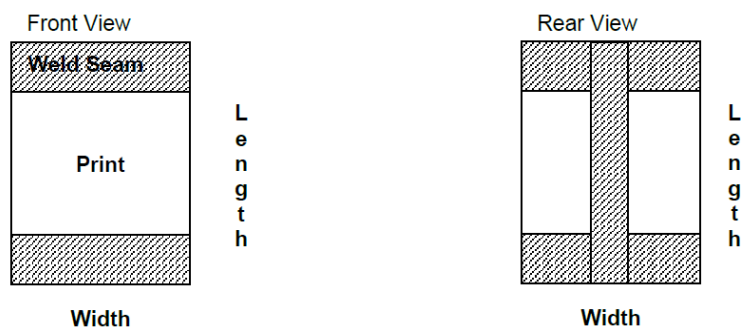


Desiccant 1 unit**20-052-6027**

Tubular Bag Desiccant Bag VA/B- dust-tight

Product specifications:

Material:	Bentonite clay
Appearance:	Grey granules in a white bag
Bag:	Non-woven Type B dust-tight
Size:	width 70 mm / Length 140 mm <i>Tolerance: all Dimensions +/- 10 mm</i>
Print:	According to DIN 55473
Print color:	Blue
Unit weight:	35 grams
Using temperature:	Up to 50°C
Moisture:	Efficient from 15% to 50% HR
Moisture absorption:	5.9 gram/unit of H ₂ O at 20% HR; 6.8 gram/unit @ 40% HR
ESD protection:	Surface resistance (bag) <1011 Ω
Reactivation:	120°C (245°F) during 16 hours
Conservation:	Store away from moisture
Packaging:	According to DIN 55473 40 desiccant bags with 8%-indicator in PE bags 400 desiccant bags in standard carton
Standard compliance:	EN 61340-5-1 MIL-D-3464E