

PAGE 1/1

 ISSUE **17/06/15**

 SERIES **Flexible C/A**

 PART NUMBER **R285425000**

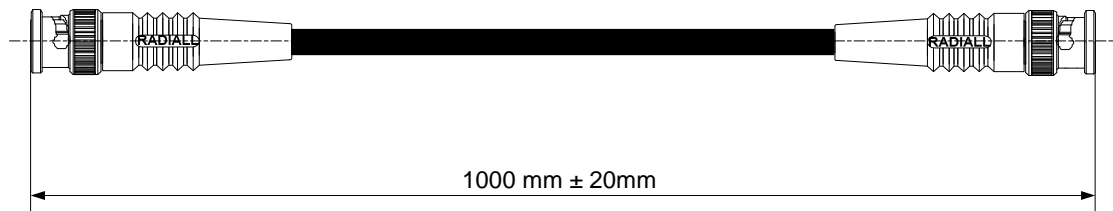
 CUSTOMER : **ALL**

SPECIFICATION :

-

ISSUE : -

DATE: -

All dimensions are in mm
For more details, please see connectors TDS

CONNECTORS DESIGNATION

 Connector 1: **R141082161 + boot
BNC-COM Straight Plug
Nickel plated Brass
Torque wrench : NA**

 Connector 2: **R141082161 + boot
BNC-COM Straight Plug
Nickel plated Brass
Torque wrench : NA**
CABLE DESIGNATION
KX15 Flexible cable 5/50 black
PROTECTIVE JACKET
N/A
OUTER DIAMETER
5,05 mm max
MARKING
N/A
ELECTRICAL CHARACTERISTICS

Characteristic impedance

50 Ohms

Frequency band :

DC - 1 GHz

Dielectric Withstanding Voltage:

1500 Veff mini

Voltage Rating:

500 Vrms maxi

Insulation Resistance

5000 Mohms mini
MECHANICAL CHARACTERISTICS

Min. Static bending radius :

20 mm

Life (Connectors) :

100 Cycles
ENVIRONMENTAL CHARACTERISTICS

Temperature range :

-35°C to +70 °C

In case of difference between the performances announced into the TDS and the customer specification, the TDS is the document of reference for the order.

This document contains proprietary information and such information shall not be disclosed to any third party for any purpose whatsoever or used for manufacturing purposes without prior written agreement from Radiall. The data defined in this document are given as an indication, in the effort to improve our products; we reserve the right to make any changes judged necessary.