


## STAKEI 3 N grau/grey

Industrial Connectors:Rectangular connectors ST-series:Panel-mounted socket

### Product description

Description	Panel-mounted socket, added gasket
Type	STAKEI 3 N grau/grey
Order No.	932 142-106
Type of contact	female
Number of contacts	3 + PE
Conductor size	max. 1.5 mm <sup>2</sup>
Housing Color	grey
Contact bearer color	black

### Drawing

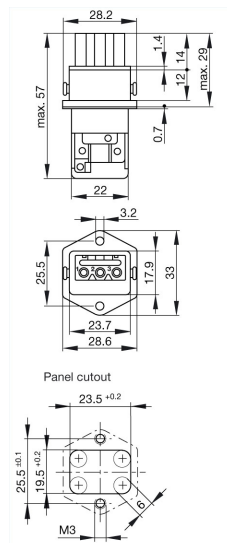

### Technical data

Pin dimensions	2 mm
Rated voltage	DC 250 V / AC 400 V
Rated current	DC 10 A / AC 16 A
Contact resistance	≤ 5 mOhm
Type of termination	screws

### Material

Contact material	Cu Zn
Contact surface material	Sn
Contact bearer material	PA
Housing material	PA

### Environmental conditions

Protection class (IEC 60529)	IP 54
Pollution severity	3
Temperature range	-30 °C to +90 °C

### Inflammability class

Housing	UL 94 HB
---------	----------

Contact bearer	UL 94 V-1
<b>Approvals</b>	
UL	UL
VDE	VDE
SEV	SEV
<b>Packing unit</b>	
Packaging unit	100 pieces
<b>Scope of delivery and accessories</b>	
Accessories to order separately	safety brackets STASI 3, order no. 732 045-001