




STAKAP 3 N grau/grey

Industrial Connectors:Rectangular connectors ST-series:Surface mounted socket

Product description

Description	Surface mounted socket
Type	STAKAP 3 N grau/grey
Order No.	932 513-106
Type of contact	female
Number of contacts	3 + PE
Conductor size	max. 1.5 mm ²
Housing Color	grey
Contact bearer color	black

Drawing

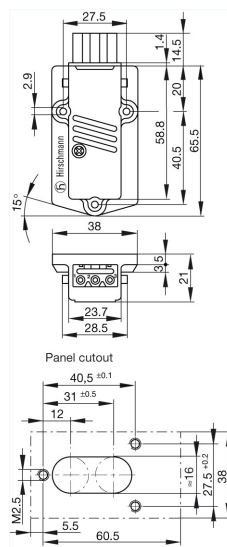

Technical data

Pin dimensions	2 mm
Rated voltage	DC 250 V / AC 400 V
Rated current	DC 10 A / AC 16 A
Contact resistance	≤ 5 mOhm
Type of termination	screws

Material

Contact material	Cu Zn
Contact surface material	Sn
Contact bearer material	PA
Housing material	PA

Environmental conditions

Protection class (IEC 60529)	IP 54
Pollution severity	3
Temperature range	-30 °C to +90 °C

Inflammability class

Housing	UL 94 HB
Contact bearer	UL 94 V-1

Approvals

UL	UL
VDE	VDE
SEV	SEV
Packing unit	
Packaging unit	100 pieces
Scope of delivery and accessories	
Accessories to order separately	safety brackets STASI 3, order no. 732 045-001