




STAS 4 N schwarz/black

Industrial Connectors:Rectangular connectors ST-series:Cable plug

Product description

Description	Cable plug with strain relief
Type	STAS 4 N schwarz/black
Order No.	934 442-100
Type of contact	male
Number of contacts	4 + PE
Cable gland	M 16 x 1,5
Cable diameter	6 mm to 10 mm
Conductor size	max. 1.5 mm ²
Housing Color	black
Contact bearer color	black

Drawing

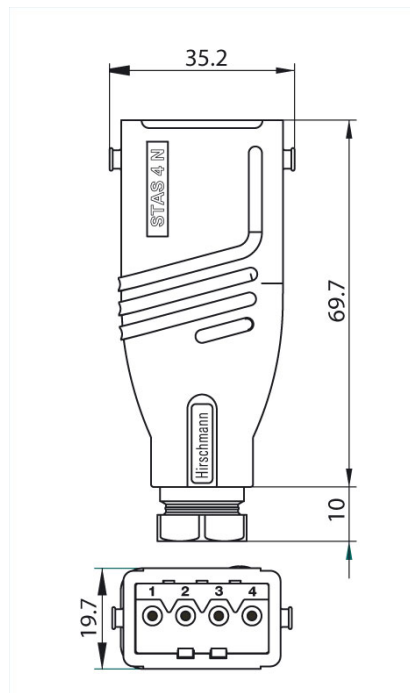

Technical data

Pin dimensions	2 mm
Rated voltage	AC 400 V / DC 250 V
Rated current	DC 10 A / AC 10 A
Contact resistance	≤ 5 mOhm
Type of termination	screw

Material

Contact material	Cu Zn
------------------	-------

Contact surface material	Sn
Contact bearer material	PA
Housing material	PA
Environmental conditions	
Protection class (IEC 60529)	IP 54
Pollution severity	3
Temperature range	-30 °C to +90 °C
Inflammability class	
Housing	UL 94 HB
Contact bearer	UL 94 V-0
Approvals	
UL	UL
VDE	VDE
SEV	SEV
Packing unit	
Packaging unit	100 pieces
Scope of delivery and accessories	
Accessories to order separately	safety brackets STASI 4, order no. 733 449-001