
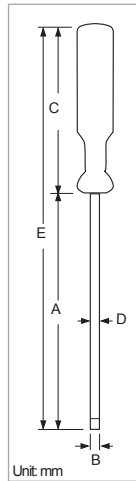


# 891 Series High Quality Line Color Screwdriver

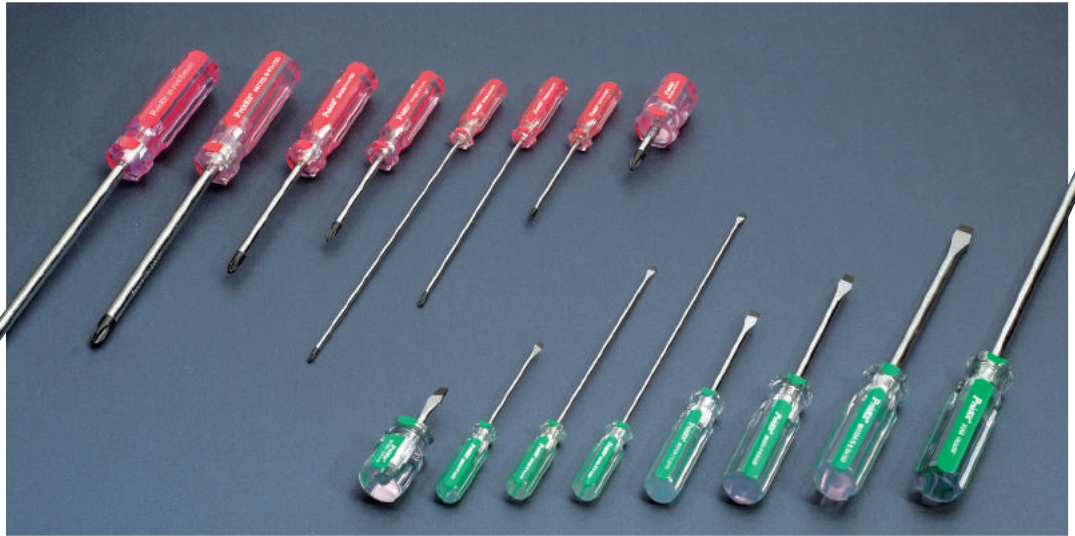

Model No.	A	B	C	D	E
89101A	75	⊖ 3.2	56	3.2	131
89102A	75	⊖ 5.0	80	5.0	155
89105A	100	⊖ 3.2	56	3.2	156
89106A	150	⊖ 3.2	56	3.2	206
89107A	100	⊖ 6.0	90	6.0	190
89110A	100	⊖ 5.0	80	5.0	180
89112A	250	⊖ 5.0	80	5.0	330
89113A	150	⊖ 6.0	90	6.0	240
89114A	200	⊖ 6.0	90	6.0	290

Model No.	A	B	C	D	E
89101B	75	⊕ #0	56	3.2	131
89102B	75	⊕ #1	80	5.0	155
89105B	100	⊕ #0	56	3.2	156
89106B	150	⊕ #0	56	3.2	206
89107B	100	⊕ #2	90	6.0	190
89110B	100	⊕ #1	80	5.0	180
89112B	250	⊕ #1	80	5.0	330
89113B	150	⊕ #2	90	6.0	240
89114B	200	⊕ #2	90	6.0	290

Model No.	A	B	C	D	E
89115A	200	⊖ 5.0	80	5.0	280
89116A	150	⊖ 5.0	80	5.0	230
89117A	250	⊖ 6.0	90	6.0	340
89118A	200	⊖ 3.2	56	3.2	256
89119A	300	⊖ 5.0	80	5.0	380
89120A	38	⊖ 6.0	45	6.0	83
89121A	300	⊖ 6.0	90	6.0	390
89122A	150	⊖ 8.0	100	8.0	250
89123A	200	⊖ 8.0	100	8.0	300

Model No.	A	B	C	D	E
89115B	200	⊕ #1	80	5.0	280
89116B	150	⊕ #1	80	5.0	230
89117B	250	⊕ #2	90	6.0	340
89118B	200	⊕ #0	56	3.2	256
89119B	300	⊕ #1	80	5.0	380
89120B	38	⊕ #2	45	6.0	83
89121B	300	⊕ #2	90	6.0	390
89122B	150	⊕ #3	100	8.0	250
89123B	200	⊕ #3	100	8.0	300

Individual packing: Inner box

## SW-9106 Line Color Screwdriver Set (6 pcs)



Contents	
⊖	89101A
⊖	89102A
⊖	89107A
⊕	89101B
⊕	89102B
⊕	89107B

Individual packing: Blister card


## SW-9109D 10 In 1 Double End Reversible Screwdriver Set



Contents		
1pc PVC handle with 1/4" bits holder, length: 100mm		
6 bits, material: AISI 6150 Cr-V, HRC 52 <sup>±2</sup> °		Length
⊕ #2	⊖ 6.0	110mm
⊕ #2	⊕ #2	110mm
⊕ #2	⊕ #2	65mm
⊕ #2		100mm
⊕ #1		100mm
⊕ #2	⊕ #2	150mm

Individual packing: Blister card

## SD-9701M 20 IN 1 T-handle Driver Sockets & Bits Set

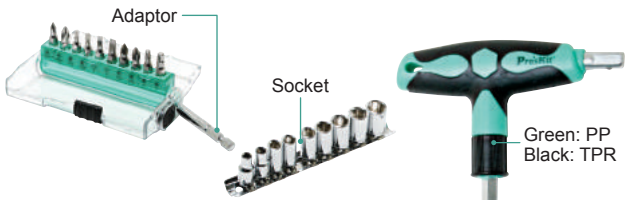

Contents	
TPR non-slip T handle with bits holder (182mm)	
10pcs hex bits: $\phi 1/4"$ x 25mm, Material: SAE 6150 Cr-V steel	
#1, #2	PZ1, PZ2
4.0, 5.0mm	4.0, 5.0mm
9 pcs $\phi 1/4"$ DR. Socket bits, Material: SAE 6150 Cr-V steel	
5, 6, 7, 8, 9, 10, 11, 12, 13mm (3/16", 1/4", 9/32", 5/16", 11/32", 3/8", 7/16", 1/2", 9/16")	
65mm Adaptor Carrying case: 115x55x17mm	

Individual packing: Blister card

Green: PP  
Black: TPR

Magnetized carbon steel bits holder for 1/4" bits

## SD-9816 16-IN-1 Reversible Ratchet Precision Screwdriver Set



- Click-stop ball clamp guarantees a secure hold and daily use comfort
- Reversible blades ensure perfect fit every time.
- Flexible, adjustable blade length.
- Hex retainer design for easy assembling.

Contents	
3 position ratchet handle, length: 155mm	
8pcs double end hex bits : $\phi 1/4"$ x 175mm Material: S2 Alloy steel	
4.0, 5.0	6.0, 7.0
T20, T30	T25, T40
H5.0, H6.0	HB5.0, HB6.0
#1	#2
PZ1	PZ2


Individual packing: Blister card



## SD-2313 30-Pcs Do-It-All Kit



- Triangle magnetic bits storage case with a hanger.
- Magnetic extension handle.
- Compact and versatile set of bits.

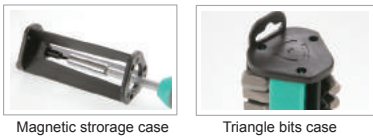

Bits	
TPR non-slip handle with bits holder, 30pcs hex bits: $\phi 1/4"$ x 25mm, Material: SAE 6150 Cr-V steel	
SQ1, SQ2	
#0, #1, #2, #3	
PZ0, PZ1, PZ2, PZ3	
SL3.5, 4.5, 5.5, 6, 8	
H2, 2.5, 3, 4, 5, 6, 8	
T5, T6, T7, T8, T10, T15, T20, T35	


Individual packing: Hanger



## 1PK-SD006 6 in 1 Magnetic Quick Change Screwdriver



- Industrial quality with maximum versatility.
- Shock proof T.P.R + P.P.
- OAL.: 200mm

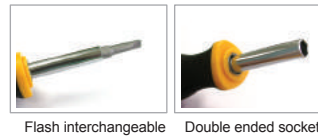

Contents	
Dual color TPR non-slip handle 125mm	
3pcs double end bits and socket:	
8mm socket x115mm	
6mm socket x115mm	
3/16", 1/4" x75mm	
#1, #2 x75mm	

Individual packing: Blister card



## SD-9817 6 In 1 Ratchet Screwdriver Set



- Pivoting head locks in 3 operating positions allowing better control & access to confined areas
- Ergonomic dual color TPR+PP handle with bits storage inside
- Magnetized hex opening holds all standard driver bits, and allows quick removal and replacement
- 3 position ratchet features forward, reverse and locked for efficient work

Contents	
1pce 3-way ratchet screwdriver handle	
6 pcs 1/4" Bits:  4, 5, 6mm  #1, #2, #3	

Individual packing: Blister card




## 8PK-SD010 12-In-1 Ratchet Screwdriver Set



Contents	
Dual color TPR non-slip ratchet handle	
12pcs $\phi 1/4"$ x 30mm bits:	
T6, T7, T8, T9, T10, T15	
#0, #1, #2	
3, 4, 7, 6, 3	

Individual packing: Blister card

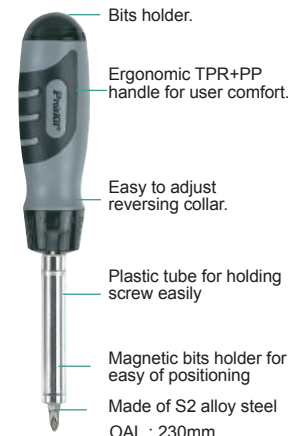

## SD-9316 23 IN 1 High Performance Screwdriver Set




• Ideal for mobile phone, PDA, PC & other applications.



Contents				
H2/H3/H4/H5	PH1/PH0/PH00	4mm		
T15H/T20H/T25H	1/4"			1.5/2.0/2.5
6/8/10				T4/T5/T6/T7
Extension bars: 4mm x 70mm, 1/4" x 70mm				
1pc Anodized aluminum alloy handle				
Carrying case: 130x86x29mm				


Individual packing: Blister card

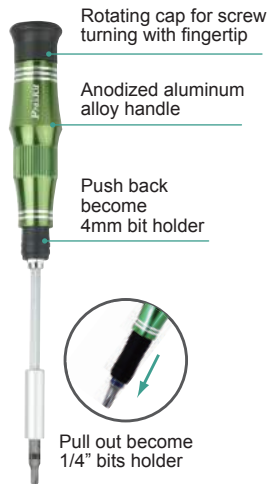

## SD-9315 22 IN 1 Precision Screwdriver Set




• Ideal for mobile phone, PDA, PC & other applications.

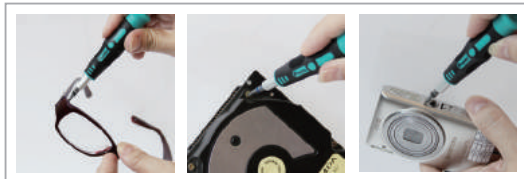

Contents			
2.5/3.0/3.5/4.0/4.5/5	PH1/PH0/PH00/PH000	4mm	
1.0/1.5/2.0/2.5 /3.0	T4/T5/T6/T7/T8		
Extension bar: 4mm x 70mm			
1pc Dual color PP+TPR handle			
Carrying case: 130x86x29mm			


Individual packing: Blister card

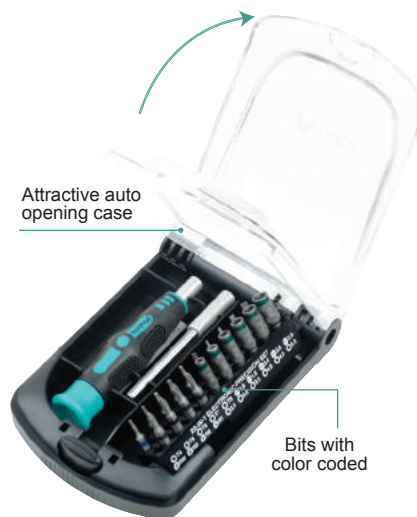

## SD-9812 12-In-1 Reversible Ratchet Precision Screwdriver Set




 Ratchet action with 3 positions: forward, reverse and lock



Contents			
3 position ratchet handle with bits holder : 155~205mm			
6pcs double end bits: ø4 x 30mm, Material: AISI 8660 Cr-Mo-V steel			
T4	T8		
T6	T10		
T7	T15		
1.5	#000		
2.0	#00		
2.5	#0		

Individual packing: Blister card

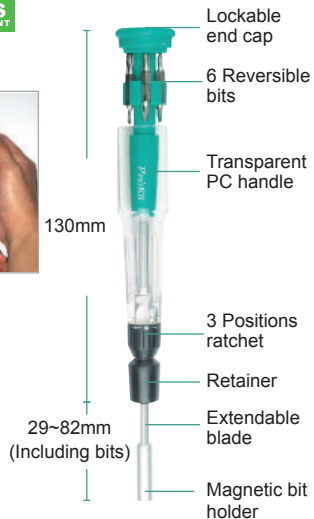

## SD-9814 9 IN 1 Aluminum Handle Precision Screwdriver Set



Contents	
Anodized aluminum alloy steel handle: 110mm	
9pcs hex bits: ø4 x 28mm, Material: AISI 6150 Cr-V steel	
#000, #00, #0, #1	
2.0, 3.0mm	
T4, T5, T6	

Individual packing: Blister card



Comes with 9 Chrome Vanadium driver bits

## SW-0118 15 PCS Precision Screwdriver Set



Rotating cap

Anti-slip TPR handle

Material: AISI 8660 Cr-Mo-V alloy steel

Black tip

Contents	
⊖	1.0x40, 2.0x40, 3.0x40, 3.5x40
⊕	#000x40, #00x40, #0x40
⊖	1.5x40, 2.0x40, 2.5x40, 3.0x40
⊖	T6x40, T8x40, T10x40, T15x40
Carrying case: 262x183x43mm	




- Working length: 40mm
- Overall length: 132mm

Individual packing: Plastic box + Color label

## SD-9829M 18 In 1 Precision Screwdriver Set



- Extended bits design for narrow space use

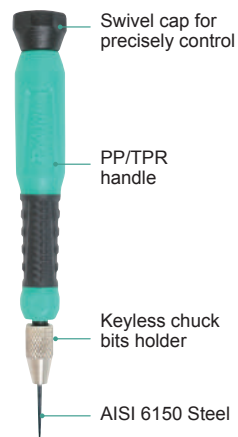

Swivel cap for precisely control

PP/TPR handle

Keyless chuck bits holder

AISI 6150 Steel

Contents	
18pcs precision bits: 46mm, Material: Cr-V	
⊖	1.2 / 1.5 / 2.0 / 2.4
⊕	PH000 / PH00
⊖	T3/T4/T5/T6/T7/T8
⊖	1.27 / 1.5 / 2.0mm
⊖	Needle type bits
Carrying case: 125.5 x 86 x 25mm	

Individual packing: Blister card

## SD-9815 Precision Screwdriver Set



Fast turning swivel cap

Quality steel

S45C Carbon steel

Bit size	A (mm)	B (mm)	OAL (mm)
⊕ #0	29	76	105
⊕ #1	31	81	112
⊖ 1.4mm	18	63	81
⊖ 1.8mm	25	68	93
⊖ 2.4mm	29	75	104
⊖ 3.0mm	31	81	112

Carrying case: 135x85x22mm

Individual packing: Color box

## SD-9819 Precision Screwdriver Set



Fast turning swivel cap

B


A

S45C Carbon steel

Bit size	A (mm)	B (mm)	OAL (mm)
⊕ #0	26	71	97
⊕ #1	28	80	108
⊖ 1.4mm	21	62	83
⊖ 1.8mm	25	66	91
⊖ 2.4mm	26	71	97
⊖ 3.0mm	28	80	108

Individual packing: Color box

## SD-9811 18-IN-1 Precision Screwdriver Set

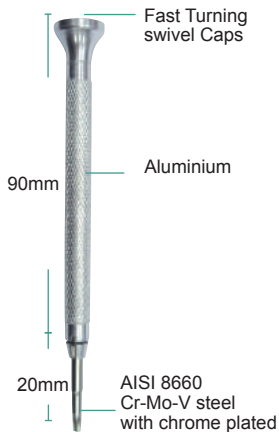

Fast Turning swivel Caps

Aluminium

90mm

AISI 8660 Cr-Mo-V steel with chrome plated



8660Cr-Mo-V steel

Contents		Bit length
Aluminum handle: 90mm		
9pcs double end screwdriver bits: 52mm, Material: AISI 8660 Cr-Mo-V steel		
⊖ 1.5	⊕ #000	52 mm
⊖ 2.0	⊕ #00	52 mm
⊖ 2.5	⊕ #0	52 mm
⊖ 3.0	⊕ #1	52 mm
⊖ T5	⊖ T10	52 mm
⊖ T6	⊖ T8	52 mm
⊖ T7	⊖ T9	52 mm
⊖ H1.5	⊖ H2.5	52 mm
⊖ H2.0	⊖ H1.3	52 mm

Carrying case: 114x136x26mm

Individual packing: Plastic box + color label

## SD-9808N 58-piece Precision Electronic Screwdriver Set



- Non-Magnetic for precision working application.



Soft Touch

123mm

Ergonomic and double structure. Non-slip.

Adjustable length 45-125mm

Contents	
TPR non-slip handle: 123mm	
Extension bar: 115mm	
56Pcs hex bits: $\varnothing 4 \times 28$ mm, Material: AISI 8660 Cr-Mo-V steel	
⊕	#000, #0, #0, #1
⊖	1.0mm, 1.5mm, 2.0mm, 2.5mm, 3.0mm, 3.5mm, 4mm
⊖	T5H, T6H, T7H, T8H, T9H, T10H, T15H, T20H
⊖	T3, T4, T5, T6, T7, T8, T9, T10, T15
⊖	1.5mm, 2mm, 2.5mm, 3mm, 1/16", 5/64", 3/32"
⊖	2mm, 2.3mm, 2.5mm
⊖	0.7mm, 0.9mm, 1.3mm, 1.5mm, 2mm, 2.5mm, 3mm, 4mm 0.028", 0.035", 0.05", 1/16", 5/64", 3/32"
⊕	PZ0, PZ1
⊖	TR1
⊖	2mm
Carrying case: 175x73x39mm	

Individual packing: Shrink pack + Color sleeve

## SD-3502 6 PCS Star Screwdriver Set



Contents		Blade length
	T4	20 mm
	T5H, T6H, T7H, T8H, T9H	20 mm

Carrying case: 121x93x18mm  
Individual packing: Plastic box+Color box

## 8PK-2061 6 PCS Electronic Screwdriver Set



Contents		Blade length
	#00, #0, #1	20 mm
	1.4, 1.8, 2.4	20 mm

Carrying case: 121x93x18mm  
Individual packing: Plastic box+Color box

## 8PK-2062 6 PCS Electronic Screwdriver Set



Contents		Blade length
	1.4, 1.6, 1.8, 2.0, 2.4, 3.0	20 mm

Carrying case: 121x93x18mm  
Individual packing: Plastic box+Color box

## 8PK-2063 5 PCS Electronic Screwdriver Set



Contents		Blade length
	#0-4, #0-3, #00, #0, #1	20 mm

Carrying case: 121x93x18mm  
Individual packing: Plastic box+Color box

## 8PK-5141N 7 PCS Electronic Screwdriver Set



• Material: Blade: AISI 6150 Cr-V steel

Contents		Bit length
6pcs Screwdrivers		
	#1	150 mm
	#0	100 mm
	#0 (Ø 2)	75 mm
	2.4	75 mm
	3.0	100 mm
	4.0	150 mm

1PK-501A Stainless micro cutting plier  
Carrying case: 325x128x21mm  
Individual packing: Plastic box + Color label

## 8PK-509 6 PCS Precision Screwdriver Set



- A 6 piece screwdriver set with 3 flat blades and 3 philips screwdrivers.
- The screwdrivers have long shafts and are ideal for reaching recessed screws in electronic equipment.
- Handles are made from molded plastic and incorporate finger grips.
- Shafts are made from AISI 6150 Cr-V steel

Contents		Bit length
	#0 (Ø 2.4)	75 mm
	#1 (Ø 3.0)	100 mm
	#1 (Ø 3.8)	150mm
	2.4	75mm
	3.0	100mm
	3.8	150mm

Individual packing: Blister card

## 8PK-SD002N 8 PCS Screwdriver Set

### High Torque



• Especially designed for both service and production use.

Contents		Blade length
	#0, #00, #1	60 mm
	2.0, 2.5, 3.0, 3.5, 4.0	60 mm

OAL: 163mm  
Individual packing: Plastic box + Color box

## SD-803 4-In-1 Screwdriver Set



- Two double-ended, reversible tips
- Material: Blade: AISI 6150 Cr-V steel
- HRC: 52°±3°
- Handle: ABS



Offered in 50pcs display pack

Contents		O.A.L (mm)
⊖ 1/16", 1/8"	⊕ #00, #0	131
Display box: 213x123x144mm		
Individual packing: Display box		

## SD-804 5-In-1 Screwdriver Set



- Two double-ended, reversible tips
- Material: Blade: AISI 6150 Cr-V steel
- HRC: 52°±3°
- Handle: ABS



Offered in 50pcs display pack

Contents		O.A.L (mm)
⊖ 1/16", 1/8"	⊕ #00, #0	135
Display box: 213x123x144mm		
Individual packing: Display box		




LED light

## 1PK-034 Series Ceramic Driver



- No electromagnetic induction
- No eddy current loss in high frequency (HF)
- Electrically and thermally insulated
- Non-magnetic • Non-static
- Resistant to acid. (except hydrofluoric)

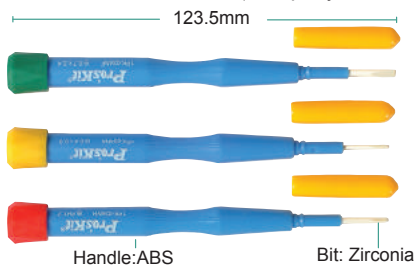

1PK-034NA	⊖ 0.4x0.9mm	1PK-034NE	⊖ 0.4x2.4mm
1PK-034NB	⊖ 0.4x1.2mm	1PK-034NF	⊖ 0.7x2.4mm
1PK-034NC	⊖ 0.4x1.8mm	1PK-034NG	⊕ PH0
1PK-034ND	⊖ 0.4x2.0mm	1PK-034NH	⊕ PH1.7

Individual packing: Display blister

## 908-607 908-607S Alignment Tool



Ideal for handyman and TV technicians, this plastic screwdriver has a steel spring tip. Suitable for trimmers.




Model No.	Material	Blade diameter	Length
908-607S	Tip: Stainless Body: K-glass Handle: PE	⊖ 2.0	150
908-607		⊖ 2.0	200

Individual packing: Bulk


## 1PK-A001 10 PCS Trimming Tool Set



A set of 10 trimming tools with moulded plastic tips, including slotted, hexagonal and square types.

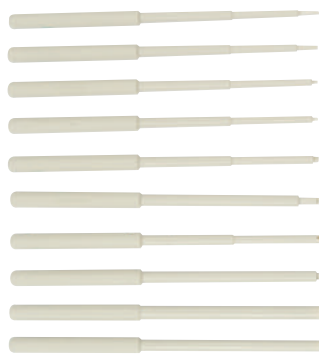

Material	Spec.	OAL.(mm)
PC	As sketch	115

 

Individual packing: Blister card

## 1PK-606A 3 PCS Anti-Static Alignment Tool Kit



- For protection of sensitive components
- Duplex, trimmer and square/hex tool
- Conductive nylon-avoid high voltage

Conductive handle resistivity: 10<sup>6</sup>~10<sup>10</sup>"



Material	Spec.
Conductive nylon	As sketch

Individual packing: Blister card

