


Sheets and accessories

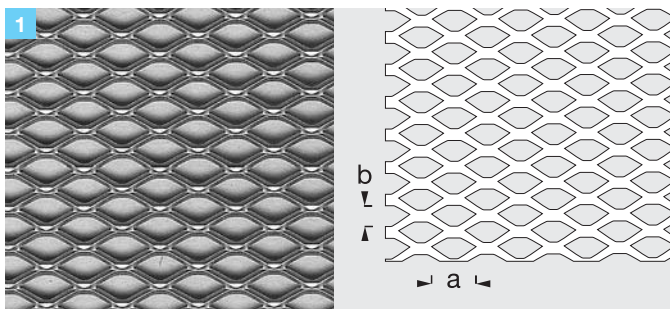

Stretch sheets

Color	Thickness	Dim. a	Dim. b	Packaging	Min.OU	Width	Length	EAN / item no.
1 Stretch metal in uncoated aluminium								
uncoated	1.6 mm	10.0 mm	5.0 mm	sealed	5 pcs.	250 mm	500 mm	4001116374647
uncoated	1.6 mm	10.0 mm	5.0 mm	sealed	5 pcs.	120 mm	1000 mm	4001116374609
uncoated	1.6 mm	10.0 mm	5.0 mm	sealed	5 pcs.	200 mm	1000 mm	4001116374616
uncoated	1.6 mm	10.0 mm	5.0 mm	sealed	5 pcs.	300 mm	1000 mm	4001116374623
uncoated	1.6 mm	10.0 mm	5.0 mm	sealed	5 pcs.	600 mm	1000 mm	4001116374630
uncoated	1,6 mm	10,0 mm	5,0 mm	rolled in a box	1 pc.	1000 mm	2000 mm	4001116374692
1 Stretch metal in anodized aluminium								
brass	1.6 mm	10.0 mm	5.0 mm	sealed	5 pcs.	250 mm	500 mm	4001116374746
brass	1.6 mm	10.0 mm	5.0 mm	sealed	5 pcs.	120 mm	1000 mm	4001116374708
brass	1.6 mm	10.0 mm	5.0 mm	sealed	5 pcs.	200 mm	1000 mm	4001116374715
brass	1.6 mm	10.0 mm	5.0 mm	sealed	5 pcs.	300 mm	1000 mm	4001116374722
brass	1.6 mm	10.0 mm	5.0 mm	sealed	5 pcs.	600 mm	1000 mm	4001116374739
brass	1,6 mm	10,0 mm	5,0 mm	rolled in a box	1 pc.	1000 mm	2000 mm	4001116374791
1 Stretch metal in coated aluminium								
red	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	250 mm	500 mm	4001116374845
red	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	200 mm	1000 mm	4001116374814
red	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	600 mm	1000 mm	4001116374838
blue	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	250 mm	500 mm	4001116374944
blue	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	200 mm	1000 mm	4001116374913
blue	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	600 mm	1000 mm	4001116374937
yellow	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	250 mm	500 mm	4001116375149
yellow	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	200 mm	1000 mm	4001116375118
yellow	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	600 mm	1000 mm	4001116375132
black	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	250 mm	500 mm	4001116375248
black	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	200 mm	1000 mm	4001116375217
black	1,6 mm	10,0 mm	5,0 mm	sealed	2 pcs.	600 mm	1000 mm	4001116375231