


Original Consumables Catalogue 2012

Colour
Mono
MFPs
Fax
Dot Matrix
Media

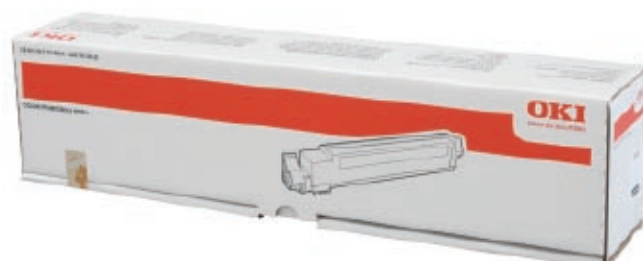

C7000 Series printers

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Unitary packaged product	
					Gross weight (kg)	Gross dimensions (mm) w x d x h
C7100/C7300/C7350/C7500	Black Toner	41963008	5031713923404	10,000*	0.848	310 x 180 x 130
C7100/C7300/C7350/C7500	Cyan Toner	41963007	5031713923398	10,000*	0.848	310 x 180 x 130
C7100/C7300/C7350/C7500	Magenta Toner	41963006	5031713923381	10,000*	0.848	310 x 180 x 130
C7100/C7300/C7350/C7500	Yellow Toner	41963005	5031713923374	10,000*	0.848	310 x 180 x 130
C7100/C7300/C7350/C7500	Toner Rainbow Pack	01101001	5031713014478	10,000***	3.400	500 x 325 x 195
C7100/C7300/C7350/C7500	Black Image Drum	41962808	5031713923480	23,000**	1.714	370 x 160 x 290
C7100/C7300/C7350/C7500	Cyan Image Drum	41962807	5031713923473	23,000**	1.751	370 x 160 x 290
C7100/C7300/C7350/C7500	Magenta Image Drum	41962806	5031713923466	23,000**	1.751	370 x 160 x 290
C7100/C7300/C7350/C7500	Yellow Image Drum	41962805	5031713923459	23,000**	1.751	370 x 160 x 290
C7100/C7300/C7350/C7500	Transfer Belt	41945503	5031713923732	60,000****	3.200	510 x 410 x 235
C7100/C7300/C7350/C7500	Fuser Unit	41945603	5031713923725	60,000	3.000	450 x 220 x 240

NB * At 5% coverage A4 ** Average A4 life based on a typical office environment *** At 5% coverage A4 per colour **** A4 at 3 pages per job

C8000 Series printers

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Unitary packaged product	
					Gross weight (kg)	Gross dimensions (mm) w x d x h
C8600/C8800†	Black Toner	43487712	5031713037743	6,000*	0.720	388 x 70 x 110
C8600/C8800†	Cyan Toner	43487711	5031713037736	6,000*	0.720	388 x 70 x 110
C8600/C8800†	Magenta Toner	43487710	5031713037729	6,000*	0.720	388 x 70 x 110
C8600/C8800†	Yellow Toner	43487709	5031713037712	6,000*	0.720	388 x 70 x 110
C8600/C8800†	Toner Rainbow Kit	43698501	5031713038177	6,000***	2.500	453 x 130 x 230
C8600/C8800	Black Image Drum	43449016	5031713037668	20,000**	1.850	464 x 128 x 120
C8600/C8800	Cyan Image Drum	43449015	5031713037651	20,000**	1.850	464 x 128 x 120
C8600/C8800	Magenta Image Drum	43449014	5031713037644	20,000**	1.850	464 x 128 x 120
C8600/C8800	Yellow Image Drum	43449013	5031713037637	20,000**	1.850	464 x 128 x 120
C8600/C8800	Transfer Belt	43449705	5031713037811	80,000 (A4 LEF)**	4.125	500 x 450 x 230
C8600/C8800	Fuser Unit	43529405	5031713037828	100,000 (A4 LEF)	3.350	487 x 234 x 141

NB * At 5% coverage A4 ** A4 at 3 pages per job *** At 5% coverage A4 per colour

† For the protection of your product, and in order to ensure that you benefit from its full functionality, this model has been designed to operate only with genuine Oki toner cartridges. These can be identified by the Oki trademark. Any other toner cartridge may not operate at all, even if it is described as "compatible" or "refilled". If it does work, your product's performance and print quality may be degraded.

Product compatibility

C Series transfer belts / fuser units / media

Order codes	42158712	43378002	43363412	41945503	43449705	41946003	42931603	44341902	44472202	44846204	42625503	43377103	43377003	42158603	43363203	43853103	41945603	43854903	43529405	41946105	42931703	44289103	44472603	44848805	44848806	09004651	09004618	09004581	09004450	09004452	09002985	09004185	01078301	42937603			
C301/C321/C331									B														F		M		M	M	M	M							
C310/C330									B															F		M		M	M	M	M						
C3100	B										F															M		M	M	M	M						
C3200	B										F															M		M	M	M	M						
C3300		B										F																					M				
C3400/C3450/C3600		B											F													M		M	M	M	M						
C510/C530									B															F		M		M	M	M	M						
C511/C531									B															F		M		M	M	M	M						
C5100/C5300	B												F													M		M	M	M	M						
C5200/C5400	B										F															M		M	M	M	M						
C5250/C5450	B										F															M		M	M	M	M						
C5600/C5700/C5800/C5900			B											F												M		M	M	M	M						
C5650/C5750/C5850/C5950			B											F												M		M	M	M	M						
C610								B															F		M		M	M	M	M							
C710			B														F									M		M	M	M	M						
C711								B																F		M		M	M	M	M						
C7100/C7300/C7350/C7500			B														F									M		M	M	M	M						
C801/C821					B													F								M	M	M	M	M	M						
C810/C830					B													F								M	M	M	M	M	M						
C822										B															F	M	M	M	M	M	M						
C831/C841									B															F		M	M	M	M	M	M						
C8600/C8800					B														F							M	M	M	M	M	M						
C910							B																F			M	M	M	M	M	M						
C9300/C9500							B																F			M	M	M	M	M	M	M	M	S			
C9600/C9650/C9655							B																F			M	M	M	M	M	M	M	M			S	
C9800/C9850							B																F			M	M	M	M	M	M	M	M			S	
MC350		B										F																						M			
MC351/MC352/MC361/MC362									B															F		M		M	M	M	M						
MC360		B											F													M		M	M	M	M						
MC560			B											F												M		M	M	M	M						
MC561/MC562									B															F		M		M	M	M	M						
MC851/MC860/MC861						B														F						M	M	M	M	M	M						
C3520 MFP		B										F																						M			
C3530 MFP		B											F													M		M	M	M	M						
C5510 MFP/C5540 MFP		B										F														M		M	M	M	M						
C5550 MFP			B											F												M		M	M	M	M						
C9800 MFP/C9850 MFP								B															F			M	M	M	M	M	M	M	M			S	

Key: B = Transfer belt F = Fuser M = Media S = Staples

Business Printing Specialists

OKI is a global business-to-business brand dedicated to creating cost effective, professional in-house printing solutions which are designed to increase the efficiency of today's and tomorrow's businesses and their workflows. As pioneers in innovative print technologies from digital LED to High Definition Colour, we have a portfolio of award winning products and solutions enabling businesses to achieve both image focused, vibrant, quality print communications and budget flexibility.

OKI presents a full range of A3 and A4 colour and mono printers and MFPs, for workgroups and businesses of all sizes with superior media-handling capabilities. In addition our fax, POS and dot matrix printers complete our range of print solutions. These best in class products are designed to be easy to use making the job of in-house print easier.



Considering the Environment

OKI is committed to its role as a responsible partner for all its stakeholders:

Shareholders, business partners, end-users, local communities and employees.

As part of the OKI Group's Charter of Corporate Conduct, OKI continually reviews its efforts to provide environmentally sound solutions to its customers:

- OKI products are designed and manufactured with reducing the impact on the environment in mind.
- Increasing the amount of our hardware products and consumables that are recycled is one of our strategic objectives.
- We feel responsible for conducting our business in an environmentally sound manner, contributing to conservation and activities within our local communities.

OKI's Green Leaf symbol, found on all products and packaging, represents our total commitment to collection, recycling and environmental processes.



Simply Unique – 3 Year Warranty

Our devices are manufactured to the highest standards of quality and technology, which has been confirmed by independent tests.

We are so convinced of the high quality of our products that we are offering you an extension of the standard warranty period to 3 years – for free! Simply register your product within 30 days of purchase to be eligible for our unique all inclusive offer. Fully covered by OKI!

For further information please visit your local website.



20 years of LED Technology

OKI pioneered the development of digital LED technology in printers over 20 years ago. This innovation delivers High Definition printing – for more accurate, striking printed documents. Thanks to this digital LED technology, our printers are compact, environmentally friendly and energy efficient, using significantly less raw materials in the manufacturing process and consuming less energy. LED print heads have no moving parts, making our LED printers robust and ultra reliable.



High Definition Colour

High Definition Colour is OKI's own unique collection of market-defining hardware and software technologies. Together, these

components deliver unsurpassed colour printing – simply, intelligently, perfectly.

We pioneered Single-pass Flat Paper Path technology to bring you fast affordable colour printing. In consumables, we created a special Microfine High Definition Toner to ensure your documents are printed in superior quality.

We championed digital LED printing technology: our High Definition LED printheads have no moving parts and deliver pin sharp images.

The combination of the range of media and software solutions we offer means you have much more control of what you want to print, when you want to print – without leaving the office.

ISO Sets the Standard

The range of Original Consumables carrying the ISO Standard continues to grow. ISO/IEC 19752 now incorporates the majority of our mono printers and fax machines. In addition, we continue to expand on this by introducing the ISO/IEC 19798 standards for our latest colour printers. These ISO Standards are the industry-recognised benchmark for measuring toner yields of consumables.

OKI EUROPE LTD.

Blays House, Wick Road
Egham TW20 0HJ
United Kingdom
T +44(0) 20 8219 2190
F +44(0) 20 8219 2199

WWW.OKIPRINTINGSOLUTIONS.COM

Only use genuine Oki Original Consumables to ensure the best quality and performance from your hardware. Non Oki Original products may damage your printer's performance and invalidate your warranty. Specifications subject to change without notice. All trademarks acknowledged.

© 2012 Oki Europe Ltd. Version 1 04/2012.

OKI