


## Original Consumables Catalogue 2012

Colour  
Mono  
MFPs  
Fax  
Dot Matrix  
Media

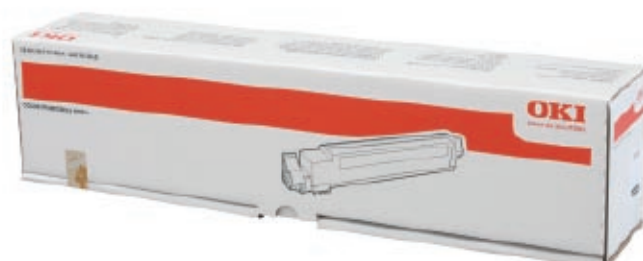

## C9000 Series printers

| Printer model | Consumable         | Order code | Unitary EAN code | Life (pages)        | Unitary packaged product |                                 |
|---------------|--------------------|------------|------------------|---------------------|--------------------------|---------------------------------|
|               |                    |            |                  |                     | Gross weight (kg)        | Gross dimensions (mm) w x d x h |
| C9300/C9500   | Black Toner        | 41963608   | 5031713923565    | 15,000*             | 1.270                    | 462 x 202 x 143                 |
| C9300/C9500   | Cyan Toner         | 41963607   | 5031713923558    | 15,000*             | 1.270                    | 462 x 202 x 143                 |
| C9300/C9500   | Magenta Toner      | 41963606   | 5031713923541    | 15,000*             | 1.270                    | 462 x 202 x 143                 |
| C9300/C9500   | Yellow Toner       | 41963605   | 5031713923534    | 15,000*             | 1.270                    | 462 x 202 x 143                 |
| C9300/C9500   | Toner Rainbow Pack | 01101101   | 5031713015864    | 15,000***           | 4.787                    | 545 x 470 x 220                 |
| C9300/C9500   | Black Image Drum   | 41963408   | 5031713923640    | 30,000**            | 2.394                    | 490 x 180 x 265                 |
| C9300/C9500   | Cyan Image Drum    | 41963407   | 5031713923633    | 30,000**            | 2.394                    | 490 x 180 x 265                 |
| C9300/C9500   | Magenta Image Drum | 41963406   | 5031713923626    | 30,000**            | 2.240                    | 490 x 180 x 265                 |
| C9300/C9500   | Yellow Image Drum  | 41963405   | 5031713923619    | 30,000**            | 2.394                    | 490 x 180 x 265                 |
| C9300/C9500   | Transfer Belt      | 41946003   | 5031713923800    | 80,000 (A4 LEF)**** | 5.000                    | 520 x 470 x 250                 |
| C9300/C9500   | Fuser Unit         | 41946105   | 5031713924159    | 80,000 (A4 LEF)     | 3.600                    | 540 x 160 x 250                 |
| C9300/C9500   | Finisher Staples   | 01078301   | 5031713014317    | N/A                 | 0.290                    | 170 x 75 x 50                   |

NB \* At 5% coverage A4 \*\* Average A4 life based on a typical office environment \*\*\* At 5% coverage A4 per colour \*\*\*\* A4 at 3 pages per job

## C9000 Series printers

| Printer model                 | Consumable         | Order code | Unitary EAN code | Life (pages)          | Unitary packaged product |                                 |
|-------------------------------|--------------------|------------|------------------|-----------------------|--------------------------|---------------------------------|
|                               |                    |            |                  |                       | Gross weight (kg)        | Gross dimensions (mm) w x d x h |
| C9600/C9650/C9800/C9850†      | Black Toner        | 42918916   | 5031713026846    | 15,000*               | 1.000                    | 484 x 102 x 117                 |
| C9600/C9650/C9800/C9850†      | Cyan Toner         | 42918915   | 5031713026839    | 15,000*               | 1.000                    | 484 x 102 x 117                 |
| C9600/C9650/C9800/C9850†      | Magenta Toner      | 42918914   | 5031713026822    | 15,000*               | 1.000                    | 484 x 102 x 117                 |
| C9600/C9650/C9800/C9850†      | Yellow Toner       | 42918913   | 5031713026815    | 15,000*               | 1.000                    | 484 x 102 x 117                 |
| C9600/C9650/C9800/C9850†      | Toner Rainbow Pack | 43112702   | 5031713028895    | 15,000****            | 3.300                    | 483 x 279 x 141                 |
| C9655†                        | Black Toner        | 43837132   | 5031713050926    | 22,500**              | 0.700                    | 484 x 102 x 117                 |
| C9655†                        | Cyan Toner         | 43837131   | 5031713050919    | 20,000**              | 0.700                    | 484 x 102 x 117                 |
| C9655†                        | Magenta Toner      | 43837130   | 5031713050902    | 20,000**              | 0.700                    | 484 x 102 x 117                 |
| C9655†                        | Yellow Toner       | 43837129   | 5031713050896    | 20,000**              | 0.700                    | 484 x 102 x 117                 |
| C9600/C9650/C9655/C9800/C9850 | Black Image Drum   | 42918108   | 5031713026570    | 30,000***             | 2.300                    | 528 x 162 x 200                 |
| C9600/C9650/C9655/C9800/C9850 | Cyan Image Drum    | 42918107   | 5031713026563    | 30,000***             | 2.340                    | 528 x 162 x 200                 |
| C9600/C9650/C9655/C9800/C9850 | Magenta Image Drum | 42918106   | 5031713026556    | 30,000***             | 2.320                    | 528 x 162 x 200                 |
| C9600/C9650/C9655/C9800/C9850 | Yellow Image Drum  | 42918105   | 5031713026549    | 30,000***             | 2.340                    | 528 x 162 x 200                 |
| C9600/C9650/C9655/C9800/C9850 | Transfer Belt      | 42931603   | 5031713026990    | 100,000 (A4 LEF)***** | 4.900                    | 489 x 459 x 199                 |
| C9600/C9650/C9655/C9800/C9850 | Fuser Unit         | 42931703   | 5031713026983    | 100,000 (A4 LEF)      | 3.600                    | 517 x 217 x 141                 |
| C9600/C9650/C9655/C9800/C9850 | Waste Toner System | 42869403   | 5031713027003    | 20,000 - 30,000       | 0.700                    | 575 x 160 x 105                 |
| C9600/C9650/C9655/C9800/C9850 | Staples            | 42937603   | 5031713027010    | N/A                   | 0.550                    | 163 x 64 x 42                   |

NB \* At 5% coverage A4 \*\* Yield compliant with ISO/IEC 19798 \*\*\* Average A4 life based on a typical office environment \*\*\*\* At 5% coverage A4 per colour \*\*\*\*\* A4 at 3 pages per job

† For the protection of your product, and in order to ensure that you benefit from its full functionality, this model has been designed to operate only with genuine Oki toner cartridges.

These can be identified by the Oki trademark. Any other toner cartridge may not operate at all, even if it is described as "compatible" or "refilled". If it does work, your product's performance and print quality may be degraded.

# Product compatibility

## C900 Series toner / image drums

| Order codes | 44036024 | 44036023 | 44036022 | 44036021 | 42869403 | 44035520 | 44035519 | 44035518 | 44035517 |
|-------------|----------|----------|----------|----------|----------|----------|----------|----------|----------|
| C910        | T        | T        | T        | T        | WT       | EP       | EP       | EP       | EP       |

Key: T = Toner WT = Waste toner pack EP = Image drum

## C9000 Series toner / waste toner system

| Order codes             | 41963608 | 41963607 | 41963606 | 41963605 | 42918916 | 42918915 | 42918914 | 42918913 | 43837132 | 43837131 | 43837130 | 43837129 | 01101101 | 43112702 | 42869403 |
|-------------------------|----------|----------|----------|----------|----------|----------|----------|----------|----------|----------|----------|----------|----------|----------|----------|
| C9300/C9500             | T        | T        | T        | T        |          |          |          |          |          |          |          |          | T        |          |          |
| C9600/C9650/C9800/C9850 |          |          |          |          | T        | T        | T        | T        |          |          |          |          |          |          | T WT     |
| C9655                   |          |          |          |          |          |          |          |          | T        | T        | T        | T        |          |          | WT       |
| C9800 MFP/C9850 MFP     |          |          |          |          | T        | T        | T        | T        |          |          |          |          |          | T        | WT       |

Key: T = Toner WT = Waste toner pack

## C9000 Series image drums

| Order codes                   | 41963408 | 41963407 | 41963406 | 41963405 | 42918108 | 42918107 | 42918106 | 42918105 |
|-------------------------------|----------|----------|----------|----------|----------|----------|----------|----------|
| C9300/C9500                   | EP       | EP       | EP       | EP       |          |          |          |          |
| C9600/C9650/C9655/C9800/C9850 |          |          |          |          | EP       | EP       | EP       | EP       |
| C9800 MFP/C9850 MFP           |          |          |          |          | EP       | EP       | EP       | EP       |

Key: EP = Image drum

## Business Printing Specialists

OKI is a global business-to-business brand dedicated to creating cost effective, professional in-house printing solutions which are designed to increase the efficiency of today's and tomorrow's businesses and their workflows. As pioneers in innovative print technologies from digital LED to High Definition Colour, we have a portfolio of award winning products and solutions enabling businesses to achieve both image focused, vibrant, quality print communications and budget flexibility.

OKI presents a full range of A3 and A4 colour and mono printers and MFPs, for workgroups and businesses of all sizes with superior media-handling capabilities. In addition our fax, POS and dot matrix printers complete our range of print solutions. These best in class products are designed to be easy to use making the job of in-house print easier.



### Considering the Environment

OKI is committed to its role as a responsible partner for all its stakeholders:

Shareholders, business partners, end-users, local communities and employees.

As part of the OKI Group's Charter of Corporate Conduct, OKI continually reviews its efforts to provide environmentally sound solutions to its customers:

- OKI products are designed and manufactured with reducing the impact on the environment in mind.
- Increasing the amount of our hardware products and consumables that are recycled is one of our strategic objectives.
- We feel responsible for conducting our business in an environmentally sound manner, contributing to conservation and activities within our local communities.

OKI's Green Leaf symbol, found on all products and packaging, represents our total commitment to collection, recycling and environmental processes.



### Simply Unique – 3 Year Warranty

Our devices are manufactured to the highest standards of quality and technology, which has been confirmed by independent tests.

We are so convinced of the high quality of our products that we are offering you an extension of the standard warranty period to 3 years – for free! Simply register your product within 30 days of purchase to be eligible for our unique all inclusive offer. Fully covered by OKI!

For further information please visit your local website.



### 20 years of LED Technology

OKI pioneered the development of digital LED technology in printers over 20 years ago. This innovation delivers High Definition printing – for more accurate, striking printed documents. Thanks to this digital LED technology, our printers are compact, environmentally friendly and energy efficient, using significantly less raw materials in the manufacturing process and consuming less energy. LED print heads have no moving parts, making our LED printers robust and ultra reliable.



### High Definition Colour

High Definition Colour is OKI's own unique collection of market-defining hardware and software technologies. Together, these

components deliver unsurpassed colour printing – simply, intelligently, perfectly.

We pioneered Single-pass Flat Paper Path technology to bring you fast affordable colour printing. In consumables, we created a special Microfine High Definition Toner to ensure your documents are printed in superior quality.

We championed digital LED printing technology: our High Definition LED printheads have no moving parts and deliver pin sharp images.

The combination of the range of media and software solutions we offer means you have much more control of what you want to print, when you want to print – without leaving the office.

### ISO Sets the Standard

The range of Original Consumables carrying the ISO Standard continues to grow. ISO/IEC 19752 now incorporates the majority of our mono printers and fax machines. In addition, we continue to expand on this by introducing the ISO/IEC 19798 standards for our latest colour printers. These ISO Standards are the industry-recognised benchmark for measuring toner yields of consumables.

#### OKI EUROPE LTD.

Blays House, Wick Road  
Egham TW20 0HJ  
United Kingdom  
T +44(0) 20 8219 2190  
F +44(0) 20 8219 2199

[WWW.OKIPRINTINGSOLUTIONS.COM](http://WWW.OKIPRINTINGSOLUTIONS.COM)

Only use genuine Oki Original Consumables to ensure the best quality and performance from your hardware. Non Oki Original products may damage your printer's performance and invalidate your warranty. Specifications subject to change without notice. All trademarks acknowledged.

© 2012 Oki Europe Ltd. Version 1 04/2012.

# OKI