


Original Consumables Catalogue 2012

Colour
Mono
MFPs
Fax
Dot Matrix
Media

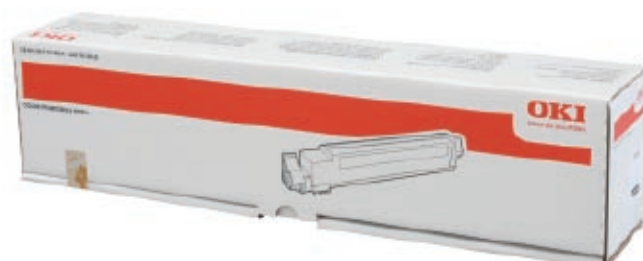

C5000 Series printers

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Unitary packaged product	
					Gross weight (kg)	Gross dimensions (mm) w x d x h
C5600/C5700†	Black Toner	43324408	5031713031260	6,000*	0.520	302 x 113 x 72
C5600/C5700†	Cyan Toner	43381907	5031713031413	2,000*	0.420	302 x 113 x 72
C5600/C5700†	Magenta Toner	43381906	5031713031406	2,000*	0.451	302 x 113 x 72
C5600/C5700†	Yellow Toner	43381905	5031713031390	2,000*	0.420	302 x 113 x 72
C5600/C5700	Black Image Drum	43381708	5031713031482	20,000**	1.306	372 x 149 x 231
C5600/C5700	Cyan Image Drum	43381707	5031713031475	20,000**	1.306	372 x 149 x 231
C5600/C5700	Magenta Image Drum	43381706	5031713031468	20,000**	1.306	372 x 149 x 231
C5600/C5700	Yellow Image Drum	43381705	5031713031451	20,000**	1.306	372 x 149 x 231
C5650/C5750†	Black Toner	43865708	5031713039808	8,000****	0.540	302 x 113 x 72
C5650/C5750†	Cyan Toner	43872307	5031713039792	2,000****	0.420	302 x 113 x 72
C5650/C5750†	Magenta Toner	43872306	5031713039785	2,000****	0.451	302 x 113 x 72
C5650/C5750†	Yellow Toner	43872305	5031713039778	2,000****	0.420	302 x 113 x 72
C5650/C5750	Black Image Drum	43870008	5031713040125	20,000**	1.400	372 x 149 x 231
C5650/C5750	Cyan Image Drum	43870007	5031713040118	20,000**	1.306	372 x 149 x 231
C5650/C5750	Magenta Image Drum	43870006	5031713040101	20,000**	1.306	372 x 149 x 231
C5650/C5750	Yellow Image Drum	43870005	5031713040095	20,000**	1.306	372 x 149 x 231
C5800/C5900†	Black Toner	43324424	5031713031680	6,000*	0.537	302 x 113 x 72
C5800/C5900†	Cyan Toner	43324423	5031713031253	5,000*	0.480	302 x 113 x 72
C5800/C5900†	Magenta Toner	43324422	5031713031246	5,000*	0.480	302 x 113 x 72
C5800/C5900†	Yellow Toner	43324421	5031713031239	5,000*	0.480	302 x 113 x 72
C5800/C5900	Black Image Drum	43381724	5031713031734	20,000**	1.380	372 x 149 x 231
C5800/C5900	Cyan Image Drum	43381723	5031713031727	20,000**	1.306	372 x 149 x 231
C5800/C5900	Magenta Image Drum	43381722	5031713031710	20,000**	1.306	372 x 149 x 231
C5800/C5900	Yellow Image Drum	43381721	5031713031703	20,000**	1.306	372 x 149 x 231
C5850/C5950†	Black Toner	43865724	5031713039884	8,000*	0.480	302 x 113 x 72
C5850/C5950†	Cyan Toner	43865723	5031713039877	6,000*	0.487	302 x 113 x 72
C5850/C5950†	Magenta Toner	43865722	5031713039860	6,000*	0.487	302 x 113 x 72
C5850/C5950†	Yellow Toner	43865721	5031713039853	6,000*	0.487	302 x 113 x 72
C5850/C5950	Black Image Drum	43870024	5031713040200	20,000**	1.306	372 x 149 x 231
C5850/C5950	Cyan Image Drum	43870023	5031713040194	20,000**	1.306	372 x 149 x 231
C5850/C5950	Magenta Image Drum	43870022	5031713040187	20,000**	1.306	372 x 149 x 231
C5850/C5950	Yellow Image Drum	43870021	5031713040170	20,000**	1.306	372 x 149 x 231
C5600/C5700/C5800/C5900	Transfer Belt	43363412	5031713031543	60,000***	2.250	419 x 369 x 223
C5650/C5750/C5850/C5950	Transfer Belt	43363412	5031713031543	60,000***	2.250	419 x 369 x 223
C5600/C5700/C5800/C5900	Fuser Unit	43363203	5031713031536	60,000	2.150	378 x 160 x 258
C5650/C5750/C5850/C5950	Fuser Unit	43853103	5031713039761	60,000	2.150	378 x 160 x 256

NB * At 5% coverage A4 ** Average A4 life based on a typical office environment *** A4 at 3 pages per job **** Yield compliant with ISO/IEC 19798

† For the protection of your product, and in order to ensure that you benefit from its full functionality, this model has been designed to operate only with genuine Oki toner cartridges. These can be identified by the Oki trademark. Any other toner cartridge may not operate at all, even if it is described as "compatible" or "refilled". If it does work, your product's performance and print quality may be degraded.

Product compatibility

C5000 Series / MC560 toner

Order codes	42804508	42804507	42804506	42804505	42127408	42127407	42127406	42127405	42804548	42804547	42804546	42804545	42127457	42127456	42127455	42127454	42403002	42403006	43324408	43381907	43381906	43381905	43865708	43872307	43872306	43872305	43324424	43324423	43324422	43324421	43865724	43865723	43865722	43865721						
C5100/C5300					T	T	T	T									T																							
C5200/C5400	T	T	T	T	T	T	T	T									T																							
C5250/C5450									T	T	T	T	T	T	T	T		T																						
C5600/C5700																			T	T	T	T																		
C5650/C5750																							T	T	T	T														
C5800/C5900																												T	T	T	T									
C5850/C5950																																				T	T	T	T	
C5510 MFP/C5540 MFP									T	T	T	T	T	T	T	T		T																						
C5550 MFP																												T	T	T	T									
MC560																																					T	T	T	T

Key: T = Toner

C5000 Series / MC560 image drums

Order codes	42126608	42126607	42126606	42126605	42126673	42126672	42126671	42126670	43381708	43381707	43381706	43381705	43870008	43870007	43870006	43870005	43381724	43381723	43381722	43381721	43870024	43870023	43870022	43870021	
C5100/C5300	EP	EP	EP	EP																					
C5200/C5400	EP	EP	EP	EP																					
C5250/C5450					EP	EP	EP	EP																	
C5600/C5700									EP	EP	EP	EP													
C5650/C5750													EP	EP	EP	EP									
C5800/C5900																	EP	EP	EP	EP					
C5850/C5950																					EP	EP	EP	EP	
C5510 MFP/C5540 MFP					EP	EP	EP	EP																	
C5550 MFP																	EP	EP	EP	EP					
MC560																					EP	EP	EP	EP	

Key: EP = Image drum

Business Printing Specialists

OKI is a global business-to-business brand dedicated to creating cost effective, professional in-house printing solutions which are designed to increase the efficiency of today's and tomorrow's businesses and their workflows. As pioneers in innovative print technologies from digital LED to High Definition Colour, we have a portfolio of award winning products and solutions enabling businesses to achieve both image focused, vibrant, quality print communications and budget flexibility.

OKI presents a full range of A3 and A4 colour and mono printers and MFPs, for workgroups and businesses of all sizes with superior media-handling capabilities. In addition our fax, POS and dot matrix printers complete our range of print solutions. These best in class products are designed to be easy to use making the job of in-house print easier.



Considering the Environment

OKI is committed to its role as a responsible partner for all its stakeholders:

Shareholders, business partners, end-users, local communities and employees.

As part of the OKI Group's Charter of Corporate Conduct, OKI continually reviews its efforts to provide environmentally sound solutions to its customers:

- OKI products are designed and manufactured with reducing the impact on the environment in mind.
- Increasing the amount of our hardware products and consumables that are recycled is one of our strategic objectives.
- We feel responsible for conducting our business in an environmentally sound manner, contributing to conservation and activities within our local communities.

OKI's Green Leaf symbol, found on all products and packaging, represents our total commitment to collection, recycling and environmental processes.



Simply Unique – 3 Year Warranty

Our devices are manufactured to the highest standards of quality and technology, which has been confirmed by independent tests.

We are so convinced of the high quality of our products that we are offering you an extension of the standard warranty period to 3 years – for free! Simply register your product within 30 days of purchase to be eligible for our unique all inclusive offer. Fully covered by OKI!

For further information please visit your local website.



20 years of LED Technology

OKI pioneered the development of digital LED technology in printers over 20 years ago. This innovation delivers High Definition printing – for more accurate, striking printed documents. Thanks to this digital LED technology, our printers are compact, environmentally friendly and energy efficient, using significantly less raw materials in the manufacturing process and consuming less energy. LED print heads have no moving parts, making our LED printers robust and ultra reliable.



High Definition Colour

High Definition Colour is OKI's own unique collection of market-defining hardware and software technologies. Together, these

components deliver unsurpassed colour printing – simply, intelligently, perfectly.

We pioneered Single-pass Flat Paper Path technology to bring you fast affordable colour printing. In consumables, we created a special Microfine High Definition Toner to ensure your documents are printed in superior quality.

We championed digital LED printing technology: our High Definition LED printheads have no moving parts and deliver pin sharp images.

The combination of the range of media and software solutions we offer means you have much more control of what you want to print, when you want to print – without leaving the office.

ISO Sets the Standard

The range of Original Consumables carrying the ISO Standard continues to grow. ISO/IEC 19752 now incorporates the majority of our mono printers and fax machines. In addition, we continue to expand on this by introducing the ISO/IEC 19798 standards for our latest colour printers. These ISO Standards are the industry-recognised benchmark for measuring toner yields of consumables.

OKI EUROPE LTD.

Blays House, Wick Road
Egham TW20 0HJ
United Kingdom
T +44(0) 20 8219 2190
F +44(0) 20 8219 2199

WWW.OKIPRINTINGSOLUTIONS.COM

Only use genuine Oki Original Consumables to ensure the best quality and performance from your hardware. Non Oki Original products may damage your printer's performance and invalidate your warranty. Specifications subject to change without notice. All trademarks acknowledged.

© 2012 Oki Europe Ltd. Version 1 04/2012.

OKI