



Original Consumables Catalogue

ALIVE WITH COLOUR



OKI Original Consumables

5 Reasons why OKI Original Consumables gives you the best value for money.




Big on colour, small on mono costs

With OKI's LED colour range for the office, it will never cost you more to print mono pages on an OKI colour device than on a standard mono printer. So you can keep printing your black and white documents and colour is available when you want to stand out. We believe that every business deserves great graphics, reliable printing and flexible media capability.

Always the best quality

Using OKI's Original Consumables with OKI's hardware guarantees quality for every print. Third party products aren't designed specifically for OKI's devices, so they can't guarantee the stunning print quality, low cost and reliability you enjoy with OKI's Original Consumables.

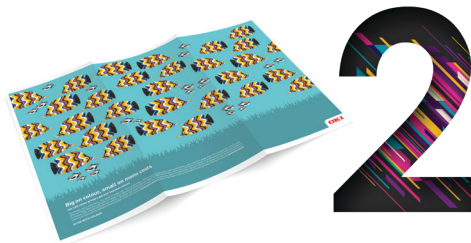

Warranty

To give you complete peace of mind, OKI's hardware comes with a three-year warranty as standard on registration of your device within 30 days of purchase, and providing you continue to use OKI Original Consumables.

Helpful advice when you need it

If you're ever unsure about OKI's products, our dedicated Customer Service Desk and friendly, professional staff are always on hand to help you with any queries you may have. However, we can only provide support for OKI Original Consumables.



Guaranteed toner yields

OKI uses ISO-approved testing methods to accurately determine the declared yield for our original toner cartridges. That means you always get the number of pages promised from your OKI Original Consumables.

Protect your business

OKI Original Consumables are specifically designed and crafted to fit your device perfectly. This precision matching is why only OKI Original Consumables offer guaranteed reliability and print quality.



Keypoint Intelligence Buyers Lab, an industry-leading independent research analyst and testing firm, compared the performance, image quality, reliability and yields of genuine OKI Original Consumables versus three third-party compatible cartridges.*

BLI tested OKI Original Consumables and third-party products used in OKI devices and found the following benefits of OKI Original Consumables:



Better print yields



Higher quality print



Consistent colour and quality



No delivery spillage



No damage to devices

*Visit your local OKI website for further information on BLI Testing.

How to check if your consumables are OKI Original



1) Look for the hologram

You can always tell if a product is an OKI Original Consumable by looking for the hologram on the packaging and making sure you can see numbers 18 and 81 in the holographic 'window'.

2) Check the serial number

Every OKI Original Consumable has a unique serial number. Visit the OKI website for the authentication tool.



Colour pg 4

Mono pg 14

MFPs pg 17

Dot Matrix pg 26

Colour Printers

C800 Series printers

Printer model	Consumable	Order code	Unitary EAN code	Life(pages)	Gross dimensions (mm) w x d x h
C801/C821	Black Toner	44643004	5031713049623	7,000	388 x 70 x 110
C801/C821	Cyan Toner	44643003	5031713049616	7,300	388 x 70 x 110
C801/C821	Magenta Toner	44643002	5031713049609	7,300	388 x 70 x 110
C801/C821	Yellow Toner	44643001	5031713049593	7,300	388 x 70 x 110
C810/C830	Black Toner	44059108	5031713043546	8,000	388 x 70 x 110
C810/C830	Cyan Toner	44059107	5031713043539	8,000	388 x 70 x 110
C810/C830	Magenta Toner	44059106	5031713043522	8,000	388 x 70 x 110
C810/C830	Yellow Toner	44059105	5031713043515	8,000	388 x 70 x 110
C813	Black Toner	46471116	5031713070221	5,000	415 x 138 x 66
C813	Cyan Toner	46471115	5031713070214	5,000	415 x 138 x 66
C813	Magenta Toner	46471114	5031713070207	5,000	415 x 138 x 66
C813	Yellow Toner	46471113	5031713070191	5,000	415 x 138 x 66
C822	Black Toner	44844616	5031713056188	7,000	442 x 70 x 146
C822	Cyan Toner	44844615	5031713056164	7,300	442 x 70 x 146
C822	Magenta Toner	44844614	5031713056140	7,300	442 x 70 x 146
C822	Yellow Toner	44844613	5031713056126	7,300	442 x 70 x 146
C823/C833/C843	Std Cap Black Toner	46471104	5031713067085	7,000	415 x 138 x 66
C823/C833/C843	Std Cap Cyan Toner	46471103	5031713067078	7,000	415 x 138 x 66
C823/C833/C843	Std Cap Magenta Toner	46471102	5031713067061	7,000	415 x 138 x 66
C823/C833/C843	Std Cap Yellow Toner	46471101	5031713067054	7,000	415 x 138 x 66
C823/C833/C843	Std Cap Yellow Toner	46471101	5031713067054	7,000	415 x 138 x 66
C824/C834/C844	Black Toner	47095704	5031713071242	5,000	405 x 65 x 118
C824/C834/C844	Cyan Toner	47095703	5031713071235	5,000	405 x 65 x 118
C824/C834/C844	Magenta Toner	47095702	5031713071228	5,000	405 x 65 x 118
C824/C834/C844	Yellow Toner	47095701	5031713071211	5,000	405 x 65 x 118
C833/C843	High Cap Black Toner	46443104	5031713066842	10,000	415 x 138 x 66
C833/C843	High Cap Cyan Toner	46443103	5031713066835	10,000	415 x 138 x 66
C833/C843	High Cap Magenta Toner	46443102	5031713066828	10,000	415 x 138 x 66
C833/C843	High Cap Yellow Toner	46443101	5031713066811	10,000	415 x 138 x 66
C831/C841	Black Toner	44844508	5031713053828	10,000	442 x 70 x 146
C831/C841	Cyan Toner	44844507	5031713053811	10,000	442 x 70 x 146
C831/C841	Magenta Toner	44844506	5031713053804	10,000	442 x 70 x 146
C831/C841	Yellow Toner	44844505	5031713053798	10,000	442 x 70 x 146
C834/C844	Black Toner	46861308	5031713071129	10,000	405 x 65 x 118
C834/C844	Cyan Toner	46861307	5031713071112	10,000	405 x 65 x 118
C834/C844	Magenta Toner	46861306	5031713071105	10,000	405 x 65 x 118
C834/C844	Yellow Toner	46861305	5031713071099	10,000	405 x 65 x 118
C801/C810/C821/C830	Black Image Drum	44064012	5031713043324	20,000	464 x 128 x 210
C801/C810/C821/C830	Cyan Image Drum	44064011	5031713043317	20,000	464 x 128 x 210
C801/C810/C821/C830	Magenta Image Drum	44064010	5031713043300	20,000	464 x 128 x 210
C801/C810/C821/C830	Yellow Image Drum	44064009	5031713043294	20,000	464 x 128 x 210

NB Toner yields based on ISO/IEC 19798 • Drums average A4 life based on a typical office environment
Transfer belt yield based on 3 pages per job A4 • Std Cap = Standard Capacity • High Cap = High Capacity

Colour Printers

C800 Series printers

Printer model	Consumable	Order code	Unitary EAN code	Life(pages)	Gross dimensions (mm) w x d x h
C813	Black Image Drum	46438024	5031713070184	30,000	457 x 251 x 195
C813	Cyan Image Drum	46438023	5031713070177	30,000	457 x 251 x 195
C813	Magenta Image Drum	46438022	5031713070160	30,000	457 x 251 x 195
C813	Yellow Image Drum	46438021	5031713070153	30,000	457 x 251 x 195
C822/C831/C841	Black Image Drum	44844408	5031713053781	30,000	457 x 190 x 260
C822/C831/C841	Cyan Image Drum	44844407	5031713053774	30,000	457 x 190 x 260
C822/C831/C841	Magenta Image Drum	44844406	5031713053767	30,000	457 x 190 x 260
C822/C831/C841	Yellow Image Drum	44844405	5031713053750	30,000	457 x 190 x 260
C823/C833/C843	Black Image Drum	46438004	5031713066767	30,000	475 x 251 x 195
C823/C833/C843	Cyan Image Drum	46438003	5031713066750	30,000	475 x 251 x 195
C823/C833/C843	Magenta Image Drum	46438002	5031713066743	30,000	475 x 251 x 195
C823/C833/C843	Yellow Image Drum	46438001	5031713066736	30,000	475 x 251 x 195
C824/C834/C844	Black Image Drum	46857508	5031713071044	30,000	475 x 251 x 195
C824/C834/C844	Cyan Image Drum	46857507	5031713071037	30,000	475 x 251 x 195
C824/C834/C844	Magenta Image Drum	46857506	5031713071020	30,000	475 x 251 x 195
C824/C834/C844	Yellow Image Drum	46857505	5031713071013	30,000	475 x 251 x 195
C801/C810/C821/C830	Transfer Belt	43449705	5031713037811	80,000	500 x 450 x 230
C822/C823/C831/C833/C841/C843	Transfer Belt	44846204	5031713053590	80,000	512 x 450 x 226
C824/C834/C844	Transfer Belt	47074503	5031713071594	80,000	505 x 450 x 230
C801/C810/C821/C830	Fuser Unit	43529405	5031713037828	100,000	487 x 234 x 141
C822	Fuser Unit	44848806	5031713056027	100,000	488 x 224 x 165
C823/C831/C833/ C841/C843	Fuser Unit	44848805	5031713053606	100,000	488 x 224 x 165
C824/C834/C844	Fuser Unit	47219604	5031713071617	100,000	490 x 220 x 160

NB Toner yields based on ISO/IEC 19798 • Drums average A4 life based on a typical office environment
Transfer belt yield based on 3 pages per job A4 • Std Cap = Standard Capacity • High Cap = High Capacity

C844




MC700 Series colour MFPs

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Gross dimensions (mm) w x d x h
MC760/MC770/MC780	Std Cap Black Toner	45396304	5031713057710	8,000	302 x 135 x 74
MC760/MC770/MC780	Std Cap Cyan Toner	45396303	5031713057697	6,000	302 x 135 x 74
MC760/MC770/MC780	Std Cap Magenta Toner	45396302	5031713057673	6,000	302 x 135 x 74
MC760/MC770/MC780	Std Cap Yellow Toner	45396301	5031713057659	6,000	302 x 135 x 74
MC770/MC780	High Cap Black Toner	45396204	5031713057635	15,000	302 x 147 x 94
MC770/MC780	High Cap Cyan Toner	45396203	5031713057611	11,500	302 x 135 x 74
MC770/MC780	High Cap Magenta Toner	45396202	5031713057598	11,500	302 x 135 x 74
MC770/MC780	High Cap Yellow Toner	45396201	5031713057574	11,500	302 x 135 x 74
MC760/MC770/MC780	Black Image Drum	45395704	5031713058519	30,000	372 x 149 x 231
MC760/MC770/MC780	Cyan Image Drum	45395703	5031713058496	30,000	372 x 149 x 231
MC760/MC770/MC780	Magenta Image Drum	45395702	5031713058742	30,000	372 x 149 x 231
MC760/MC770/MC780	Yellow Image Drum	45395701	5031713058458	30,000	372 x 149 x 231
MC760/MC770/MC780	Transfer Belt	45381102	5031713058724	60,000	419 x 369 x 223
MC760/MC770/MC780	Fuser Unit	45380003	5031713058731	60,000	387 x 160 x 256
MC760/MC770/MC780	Staples Offline (3000 staples)	45513301	5031713059820	N/A	57 x 57 x 11
MC760/MC770/MC780	Staples Finisher (15000 staples)	42937603	5031713027010	N/A	163 x 64 x 42

NB Toner yields based on ISO/IEC 19798 • Drums average A4 life based on a typical office environment
Transfer belt yield based on 3 pages per job A4 • Std Cap = Standard Capacity High Cap = High Capacity

MC700 Series
CMYK toner

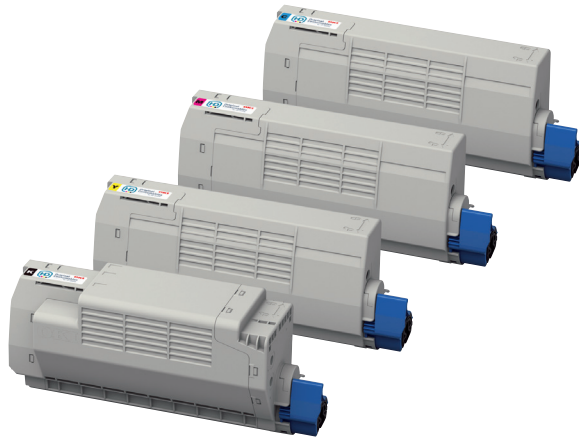

MC851, MC860 and MC861 colour MFPs

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Gross dimensions (mm) w x d x h
MC851/MC861	Black Toner	44059168	5031713052654	7,000	383 x 72 x 110
MC851/MC861	Cyan Toner	44059167	5031713052647	7,300	383 x 72 x 110
MC851/MC861	Magenta Toner	44059166	5031713052630	7,300	383 x 72 x 110
MC851/MC861	Yellow Toner	44059165	5031713052623	7,300	383 x 72 x 110
MC860	Black Toner	44059212	5031713043621	9,500	388 x 70 x 110
MC860	Cyan Toner	44059211	5031713043614	10,000	388 x 70 x 110
MC860	Magenta Toner	44059210	5031713043607	10,000	388 x 70 x 110
MC860	Yellow Toner	44059209	5031713043591	10,000	388 x 70 x 110
MC861	Black Toner	44059256	5031713052616	9,500	383 x 72 x 110
MC861	Cyan Toner	44059255	5031713052609	10,000	383 x 72 x 110
MC861	Magenta Toner	44059254	5031713052593	10,000	383 x 72 x 110
MC861	Yellow Toner	44059253	5031713052586	10,000	383 x 72 x 110
MC851/MC861	Black Image Drum	44064012	5031713043324	20,000	464 x 128 x 210
MC851/MC861	Cyan Image Drum	44064011	5031713043317	20,000	464 x 128 x 210
MC851/MC861	Magenta Image Drum	44064010	5031713043300	20,000	464 x 128 x 210
MC851/MC861	Yellow Image Drum	44064009	5031713043294	20,000	464 x 128 x 210
MC860	Black Image Drum	44064012	5031713043324	20,000	464 x 128 x 210
MC860	Cyan Image Drum	44064011	5031713043317	20,000	464 x 128 x 210
MC860	Magenta Image Drum	44064010	5031713043300	20,000	464 x 128 x 210
MC860	Yellow Image Drum	44064009	5031713043294	20,000	464 x 128 x 210
MC851/MC860/MC861	Transfer Belt	43449705	5031713037811	80,000	500 x 450 x 230
MC851/MC860/MC861	Fuser Unit	43529405	5031713037828	100,000	487 x 234 x 141

NB Toner yields based on ISO/IEC 19798 • Drums average A4 life based on a typical office environment • Transfer belt yield based on 3 pages per job A4

Did you know...
that all OKI Smart MFPs
come with Document
Management Software
SENDYS Explorer, at
no cost?



OKI's SENDYS
EXPLORER

Product compatibility

C600 Series toner / image drums

Order codes	● 44315308	● 44315307	● 44315306	● 44315305	● 46507508	● 46507507	● 46507506	● 46507505	● 44315108	● 44315107	● 44315106	● 44315105	● 46507308	● 46507307	● 46507306	● 46507305
C610	T	T	T	T					EP	EP	EP	EP				
C612					T	T	T	T					EP	EP	EP	EP

Key: T = Toner EP = Image drum

C700 / MC700 Series toner

Order codes	● 44318608	● 44318607	● 44318606	● 44318605	○ 44318657	● 45396304	● 45396303	● 45396302	● 45396301	● 45396204	● 45396203	● 45396202	● 45396201	● 46507616	● 46507615	● 46507614	● 46507613
C710	T	T	T	T													
C711	T	T	T	T													
C711WT		T	T	T	T												
C712														T	T	T	T
MC760						T	T	T	T								
MC770/MC780						T	T	T	T	T	T	T	T				

Key: T = Toner

C700 / MC700 Series image drums

Order codes	● 43913808	● 43913807	● 43913806	● 43913805	● 44318508	● 44318507	● 44318506	● 44318505	○ 44318529	● 45395704	● 45395703	● 45395702	● 45395701	● 46507416	● 46507415	● 46507414	● 46507413
C710	EP	EP	EP	EP													
C711					EP	EP	EP	EP									
C711WT					EP	EP	EP	EP									
C712														EP	EP	EP	EP
MC760										EP	EP	EP	EP				
MC770/MC780										EP	EP	EP	EP				

Key: EP = Image drum

Product compatibility

C800 Series toner

Order codes	● 44059108 ● 44059107 ● 44059106 ● 44059105				● 44643004 ● 44643003 ● 44643002 ● 44643001				● 44844508 ● 44844507 ● 44844506 ● 44844505 ● 44844616				● 44844615 ● 44844614 ● 44844613 ● 46443104 ● 46443103 ● 46443102 ● 46443101				● 46471104 ● 46471103 ● 46471102 ● 46471101				● 47095704 ● 47095703 ● 47095702 ● 47095701				● 46861308 ● 46861307 ● 46861306 ● 46861305							
C801/C821					T	T	T	T																								
C810/C830	T	T	T	T																												
C813																																
C822													T	T	T	T																
C823																					T	T	T	T								
C824/C834/C844																									T	T	T	T	T	T	T	T
C833/C843																	T	T	T	T	T	T	T	T								
C831/C841									T	T	T	T																				

Key: T = Toner

MC800 Series toner

Order codes																					
	● 44059168	● 44059167	● 44059166	● 44059165	● 44059212	● 44059211	● 44059210	● 44059209	● 44059256	● 44059255	● 44059254	● 44059253	● 45862818	● 45862816	● 45862815	● 45862814	● 45862840	● 45862839	● 45862838	● 45862837	
MC851	T	T	T	T																	
MC853																		T	T	T	T
MC860					T	T	T	T													
MC861	T	T	T	T					T	T	T	T									
MC873													T	T	T	T	T	T	T	T	T

Key: T = Toner

C800 / MC800 Series image drums

Order codes	● 44064012	● 44064011	● 44064010	● 44064009	● 44844408	● 44844407	● 44844406	● 44844405	● 44844472	● 44844471	● 44844470	● 44844469	● 46438004	● 46438003	● 46438002	● 46438001	● 46857508	● 46857507	● 46857506	● 46857505
C801/C821	EP	EP	EP	EP																
C810/C830	EP	EP	EP	EP																
C813																				
C822					EP	EP	EP	EP												
C823/C833/C843													EP	EP	EP	EP				
C824/C834/C844																	EP	EP	EP	EP
C831/C841					EP	EP	EP	EP												
MC851	EP	EP	EP	EP																
MC860/MC861	EP	EP	EP	EP																
MC853/MC873									EP	EP	EP	EP								

Key: EP = Image drum

Business Printing Specialists

OKI is a global business-to-business brand dedicated to creating cost effective, professional in-house printing solutions which are designed to increase the efficiency of today's and tomorrow's businesses and their workflows. As pioneers in innovative print technologies from digital LED to High Definition Colour, we have a portfolio of award winning A3 and A4 colour and mono printers and MFPs, for workgroups and businesses of all sizes. This combined with our solutions enables businesses to achieve both image focused, vibrant, professional quality print communications and budget flexibility.

OKI's portfolio also includes precision-engineered large-format printing systems specifically designed for the sign, graphics, CAD and GIS markets that provide industry-leading productivity and image quality. In addition, our POS and dot matrix printers complete our range of printing solution.



Considering the Environment

OKI is committed to its role as a responsible partner for all its stakeholders: Shareholders, business partners, end-users, local communities and employees.

As part of the OKI Group's Charter of Corporate Conduct, OKI continually reviews its efforts to provide environmentally sound solutions to its customers:

- OKI products are designed and manufactured with reducing the impact on the environment in mind.
- Increasing the amount of our hardware products and consumables that are recycled is one of our strategic objectives.
- We feel responsible for conducting our business in an environmentally sound manner, contributing to conservation and activities within our local communities.

OKI's Green Leaf symbol, found on all products and packaging, represents our total commitment to collection, recycling and environmental processes.



3 Year Warranty

Our devices are manufactured to the highest standards of quality and technology, which has been confirmed by independent tests.

We are so convinced of the high quality of our products that we are offering you an extension of the standard warranty period to 3 years – for free! Simply register your product within 30 days of purchase to be eligible for our unique all inclusive offer. Fully covered by OKI! For further information please visit your local website.



20 years of LED Technology

OKI pioneered the development of digital LED technology in printers over 20 years ago. This innovation delivers High Definition printing – for more accurate, striking printed documents. Thanks to this digital LED technology, our printers are compact, environmentally friendly and energy efficient, using significantly less raw materials in the manufacturing process and consuming less energy. LED print heads have no moving parts, making our LED printers robust and ultra reliable.



High Definition Colour

High Definition Colour is OKI's own unique collection of market-defining hardware and software technologies. Together, these components deliver unsurpassed colour printing – simply, intelligently, perfectly.

We pioneered Single-pass Flat Paper Path technology to bring you fast affordable colour printing. In consumables, we created a special Microfine High Definition Toner to ensure your documents are printed in superior quality.

We championed digital LED printing technology: our High Definition LED printheads have no moving parts and deliver pin sharp images.

The combination of the range of media and software solutions we offer means you have much more control of what you want to print, when you want to print – without leaving the office.

OKI EUROPE LTD.

EMEA Head Office
Blays House, Wick Road
Egham TW20 0HJ
United Kingdom
T +44(0) 20 8219 2190
F +44(0) 20 8219 2199
WWW.OKI.COM/EU