



Original Consumables Catalogue

ALIVE WITH COLOUR



OKI Original Consumables

5 Reasons why OKI Original Consumables gives you the best value for money.




Big on colour, small on mono costs

With OKI's LED colour range for the office, it will never cost you more to print mono pages on an OKI colour device than on a standard mono printer. So you can keep printing your black and white documents and colour is available when you want to stand out. We believe that every business deserves great graphics, reliable printing and flexible media capability.

Always the best quality

Using OKI's Original Consumables with OKI's hardware guarantees quality for every print. Third party products aren't designed specifically for OKI's devices, so they can't guarantee the stunning print quality, low cost and reliability you enjoy with OKI's Original Consumables.

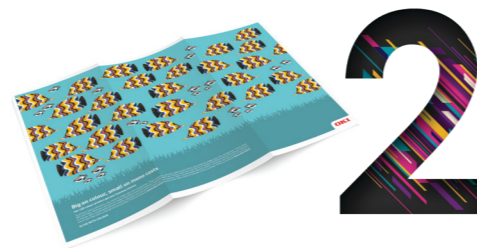

Warranty

To give you complete peace of mind, OKI's hardware comes with a three-year warranty as standard on registration of your device within 30 days of purchase, and providing you continue to use OKI Original Consumables.

Helpful advice when you need it

If you're ever unsure about OKI's products, our dedicated Customer Service Desk and friendly, professional staff are always on hand to help you with any queries you may have. However, we can only provide support for OKI Original Consumables.



Guaranteed toner yields

OKI uses ISO-approved testing methods to accurately determine the declared yield for our original toner cartridges. That means you always get the number of pages promised from your OKI Original Consumables.

Protect your business

OKI Original Consumables are specifically designed and crafted to fit your device perfectly. This precision matching is why only OKI Original Consumables offer guaranteed reliability and print quality.



Keypoint Intelligence Buyers Lab, an industry-leading independent research analyst and testing firm, compared the performance, image quality, reliability and yields of genuine OKI Original Consumables versus three third-party compatible cartridges.*

BLI tested OKI Original Consumables and third-party products used in OKI devices and found the following benefits of OKI Original Consumables:



Better print yields



Higher quality print



Consistent colour and quality



No delivery spillage



No damage to devices

*Visit your local OKI website for further information on BLI Testing.

How to check if your consumables are OKI Original



1) Look for the hologram

You can always tell if a product is an OKI Original Consumable by looking for the hologram on the packaging and making sure you can see numbers 18 and 81 in the holographic 'window'.

2) Check the serial number

Every OKI Original Consumable has a unique serial number. Visit the OKI website for the authentication tool.



Colour pg 4

Mono pg 14

MFPs pg 17

Dot Matrix pg 26

Colour Printers

C600 Series printers

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Gross dimensions (mm) w x d x h
C610	Black Toner	44315308	5031713045861	8,000*	302 x 72 x 113
C610	Cyan Toner	44315307	5031713045854	6,000*	302 x 135 x 74
C610	Magenta Toner	44315306	5031713045847	6,000*	302 x 135 x 74
C610	Yellow Toner	44315305	5031713045830	6,000*	302 x 135 x 74
C612	Black Toner	46507508	5031713068402	8,000	300 x 115 x 70
C612	Cyan Toner	46507507	5031713068396	6,000	300 x 115 x 70
C612	Magenta Toner	46507506	5031713068389	6,000	300 x 115 x 70
C612	Yellow Toner	46507505	5031713068372	6,000	300 x 115 x 70
C610	Black Image Drum	44315108	5031713045946	20,000	372 x 149 x 231
C610	Cyan Image Drum	44315107	5031713045939	20,000	372 x 149 x 231
C610	Magenta Image Drum	44315106	5031713045922	20,000	372 x 149 x 231
C610	Yellow Image Drum	44315105	5031713045915	20,000	372 x 149 x 231
C612	Black Image Drum	46507308	5031713068242	30,000	370 x 233 x 148
C612	Cyan Image Drum	46507307	5031713068235	30,000	370 x 233 x 148
C612	Magenta Image Drum	46507306	5031713068228	30,000	370 x 233 x 148
C612	Yellow Image Drum	46507305	5031713068211	30,000	370 x 233 x 148
C610	Transfer Belt	44341902	5031713045823	60,000	419 x 369 x 223
C612	Transfer Belt	45381102	5031713058724	60,000	417 x 369 x 223
C610/C612	Fuser Unit	44289103	5031713045816	60,000	378 x 160 x 256

NB Toner yields based on ISO/IEC 19798 • Drums average A4 life based on a typical office environment • Transfer belt yield based on 3 pages per job A4
*Toner yield based on 5% coverage

C612dn



Colour Printers

OKI's green initiatives help customers to recycle OKI consumables easily and for free.

C700 Series printers

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Gross dimensions (mm) w x d x h
C710/C711	Black Toner	44318608	5031713045984	11,000	302 x 135 x 74
C710/C711/C711WT	Cyan Toner	44318607	5031713045977	11,500	302 x 135 x 74
C710/C711/C711WT	Magenta Toner	44318606	5031713045960	11,500	302 x 135 x 74
C710/C711/C711WT	Yellow Toner	44318605	5031713045953	11,500	302 x 135 x 74
C711WT	White Toner	44318657	5031713056355	6,000*	302 x 135 x 74
C712	Black Toner	46507616	5031713068525	11,000	300 x 150 x 70
C712	Cyan Toner	46507615	5031713068518	11,500	300 x 150 x 70
C712	Magenta Toner	46507614	5031713068501	11,500	300 x 150 x 70
C712	Yellow Toner	46507613	5031713068495	11,500	300 x 150 x 70
C710	Black Image Drum	43913808	5031713041542	20,000	372 x 149 x 231
C710	Cyan Image Drum	43913807	5031713041535	15,000	372 x 149 x 231
C710	Magenta Image Drum	43913806	5031713041528	15,000	372 x 149 x 231
C710	Yellow Image Drum	43913805	5031713041511	15,000	372 x 149 x 231
C711	Black Image Drum	44318508	5031713046066	20,000	372 x 149 x 231
C711/C711WT	Cyan Image Drum	44318507	5031713046059	20,000	372 x 149 x 231
C711/C711WT	Magenta Image Drum	44318506	5031713046042	20,000	372 x 149 x 231
C711/C711WT	Yellow Image Drum	44318505	5031713046035	20,000	372 x 149 x 231
C711WT	White Image Drum	44318529	5031713056331	6,000	372 x 149 x 231
C712	Black Image Drum	46507416	5031713068327	30,000	370 x 233 x 148
C712	Cyan Image Drum	46507415	5031713068310	30,000	370 x 233 x 148
C712	Magenta Image Drum	46507414	5031713068303	30,000	370 x 233 x 148
C712	Yellow Image Drum	46507413	5031713068297	30,000	370 x 233 x 148
C710	Transfer Belt	43363412	5031713041894	60,000	419 x 369 x 223
C711/C711WT	Transfer Belt	44341902	5031713045823	60,000 CMYK 30,000 WT	419 x 369 x 223
C712	Transfer Belt	45381102	5031713058724	60,000	417 x 369 x 223
C710	Fuser Unit	43854903	5031713041672	60,000	378 x 160 x 256
C711/C711WT/C712	Fuser Unit	44289103	5031713045816	60,000 CMYK 30,000 WT	378 x 160 x 256

NB Toner yields based on ISO/IEC 19798 • Drums average A4 life based on a typical office environment • Transfer belt yield based on 3 pages per job A4
*Toner yield based on 5% coverage

Product compatibility

C600 Series toner / image drums

Order codes	● 44315308	● 44315307	● 44315306	● 44315305	● 46507508	● 46507507	● 46507506	● 46507505	● 44315108	● 44315107	● 44315106	● 44315105	● 46507308	● 46507307	● 46507306	● 46507305
C610	T	T	T	T					EP	EP	EP	EP				
C612					T	T	T	T					EP	EP	EP	EP

Key: T = Toner EP = Image drum

C700 / MC700 Series toner

Order codes	● 44318608	● 44318607	● 44318606	● 44318605	○ 44318657	● 45396304	● 45396303	● 45396302	● 45396301	● 45396204	● 45396203	● 45396202	● 45396201	● 46507616	● 46507615	● 46507614	● 46507613
C710	T	T	T	T													
C711	T	T	T	T													
C711WT		T	T	T	T												
C712															T	T	T
MC760						T	T	T	T								
MC770/MC780						T	T	T	T	T	T	T	T				

Key: T = Toner

C700 / MC700 Series image drums

Order codes	● 43913808	● 43913807	● 43913806	● 43913805	● 44318508	● 44318507	● 44318506	● 44318505	○ 44318529	● 45395704	● 45395703	● 45395702	● 45395701	● 46507416	● 46507415	● 46507414	● 46507413
C710	EP	EP	EP	EP													
C711					EP	EP	EP	EP									
C711WT					EP	EP	EP	EP									
C712														EP	EP	EP	EP
MC760										EP	EP	EP	EP				
MC770/MC780										EP	EP	EP	EP				

Key: EP = Image drum

Product compatibility

C800 Series toner

Order codes	● 44059108	● 44059107	● 44059106	● 44059105	● 44643004	● 44643003	● 44643002	● 44643001	● 44844508	● 44844507	● 44844506	● 44844505	● 44844616	● 44844615	● 44844614	● 44844613	● 46443104	● 46443103	● 46443102	● 46443101	● 46471104	● 46471103	● 46471102	● 46471101	● 47095704	● 47095703	● 47095702	● 47095701	● 46861308	● 46861307	● 46861306	● 46861305		
C801/C821					T	T	T	T																										
C810/C830	T	T	T	T																														
C813																																		
C822													T	T	T	T																		
C823																						T	T	T	T									
C824/C834/C844																																		
C833/C843																		T	T	T	T	T	T	T	T									
C831/C841									T	T	T	T																						

Key: T = Toner

MC800 Series toner

Order codes	● 44059168	● 44059167	● 44059166	● 44059165	● 44059212	● 44059211	● 44059210	● 44059209	● 44059256	● 44059255	● 44059254	● 44059253	● 45862818	● 45862816	● 45862815	● 45862814	● 45862840	● 45862839	● 45862838	● 45862837	
MC851	T	T	T	T																	
MC853																		T	T	T	T
MC860						T	T	T	T												
MC861	T	T	T	T					T	T	T	T									
MC873													T	T	T	T	T	T	T	T	T

Key: T = Toner

C800 / MC800 Series image drums

Order codes	● 44064012	● 44064011	● 44064010	● 44064009	● 44844408	● 44844407	● 44844406	● 44844405	● 44844472	● 44844471	● 44844470	● 44844469	● 46438004	● 46438003	● 46438002	● 46438001	● 46857508	● 46857507	● 46857506	● 46857505	
C801/C821	EP	EP	EP	EP																	
C810/C830	EP	EP	EP	EP																	
C813																					
C822					EP	EP	EP	EP													
C823/C833/C843													EP	EP	EP	EP					
C824/C834/C844																	EP	EP	EP	EP	
C831/C841					EP	EP	EP	EP													
MC851	EP	EP	EP	EP																	
MC860/MC861	EP	EP	EP	EP																	
MC853/MC873									EP	EP	EP	EP									

Key: EP = Image drum

Business Printing Specialists

OKI is a global business-to-business brand dedicated to creating cost effective, professional in-house printing solutions which are designed to increase the efficiency of today's and tomorrow's businesses and their workflows. As pioneers in innovative print technologies from digital LED to High Definition Colour, we have a portfolio of award winning A3 and A4 colour and mono printers and MFPs, for workgroups and businesses of all sizes. This combined with our solutions enables businesses to achieve both image focused, vibrant, professional quality print communications and budget flexibility.

OKI's portfolio also includes precision-engineered large-format printing systems specifically designed for the sign, graphics, CAD and GIS markets that provide industry-leading productivity and image quality. In addition, our POS and dot matrix printers complete our range of printing solution.



Considering the Environment

OKI is committed to its role as a responsible partner for all its stakeholders: Shareholders, business partners, end-users, local communities and employees.

As part of the OKI Group's Charter of Corporate Conduct, OKI continually reviews its efforts to provide environmentally sound solutions to its customers:

- OKI products are designed and manufactured with reducing the impact on the environment in mind.
- Increasing the amount of our hardware products and consumables that are recycled is one of our strategic objectives.
- We feel responsible for conducting our business in an environmentally sound manner, contributing to conservation and activities within our local communities.

OKI's Green Leaf symbol, found on all products and packaging, represents our total commitment to collection, recycling and environmental processes.



3 Year Warranty

Our devices are manufactured to the highest standards of quality and technology, which has been confirmed by independent tests.

We are so convinced of the high quality of our products that we are offering you an extension of the standard warranty period to 3 years – for free! Simply register your product within 30 days of purchase to be eligible for our unique all inclusive offer. Fully covered by OKI! For further information please visit your local website.



20 years of LED Technology

OKI pioneered the development of digital LED technology in printers over 20 years ago. This innovation delivers High Definition printing – for more accurate, striking printed documents. Thanks to this digital LED technology, our printers are compact, environmentally friendly and energy efficient, using significantly less raw materials in the manufacturing process and consuming less energy. LED print heads have no moving parts, making our LED printers robust and ultra reliable.



High Definition Colour

High Definition Colour is OKI's own unique collection of market-defining hardware and software technologies. Together, these components deliver unsurpassed colour printing – simply, intelligently, perfectly.

We pioneered Single-pass Flat Paper Path technology to bring you fast affordable colour printing. In consumables, we created a special Microfine High Definition Toner to ensure your documents are printed in superior quality.

We championed digital LED printing technology: our High Definition LED printheads have no moving parts and deliver pin sharp images.

The combination of the range of media and software solutions we offer means you have much more control of what you want to print, when you want to print – without leaving the office.

OKI EUROPE LTD.

EMEA Head Office
Blays House, Wick Road
Egham TW20 0HJ
United Kingdom
T +44(0) 20 8219 2190
F +44(0) 20 8219 2199
WWW.OKI.COM/EU