



Original Consumables Catalogue

**ALIVE WITH COLOUR**



# OKI Original Consumables

## 5 Reasons why OKI Original Consumables gives you the best value for money.




### Big on colour, small on mono costs

With OKI's LED colour range for the office, it will never cost you more to print mono pages on an OKI colour device than on a standard mono printer. So you can keep printing your black and white documents and colour is available when you want to stand out. We believe that every business deserves great graphics, reliable printing and flexible media capability.

### Always the best quality

Using OKI's Original Consumables with OKI's hardware guarantees quality for every print. Third party products aren't designed specifically for OKI's devices, so they can't guarantee the stunning print quality, low cost and reliability you enjoy with OKI's Original Consumables.

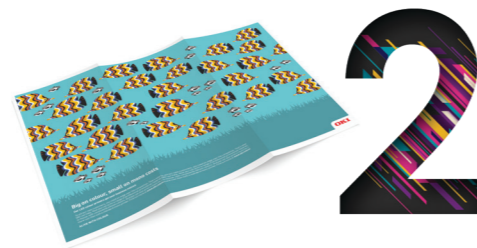

### Warranty

To give you complete peace of mind, OKI's hardware comes with a three-year warranty as standard on registration of your device within 30 days of purchase, and providing you continue to use OKI Original Consumables.

### Helpful advice when you need it

If you're ever unsure about OKI's products, our dedicated Customer Service Desk and friendly, professional staff are always on hand to help you with any queries you may have. However, we can only provide support for OKI Original Consumables.



### Guaranteed toner yields

OKI uses ISO-approved testing methods to accurately determine the declared yield for our original toner cartridges. That means you always get the number of pages promised from your OKI Original Consumables.

# Protect your business

OKI Original Consumables are specifically designed and crafted to fit your device perfectly. This precision matching is why only OKI Original Consumables offer guaranteed reliability and print quality.



Keypoint Intelligence Buyers Lab, an industry-leading independent research analyst and testing firm, compared the performance, image quality, reliability and yields of genuine OKI Original Consumables versus three third-party compatible cartridges.\*

BLI tested OKI Original Consumables and third-party products used in OKI devices and found the following benefits of OKI Original Consumables:



Better print yields



Higher quality print



Consistent colour and quality



No delivery spillage



No damage to devices

\*Visit your local OKI website for further information on BLI Testing.

## How to check if your consumables are OKI Original



### 1) Look for the hologram

You can always tell if a product is an OKI Original Consumable by looking for the hologram on the packaging and making sure you can see numbers 18 and 81 in the holographic 'window'.

### 2) Check the serial number

Every OKI Original Consumable has a unique serial number. Visit the OKI website for the authentication tool.



Colour pg 4

Mono pg 14

MFPs pg 17

Dot Matrix pg 26

# Mono Printers

Did you know... Documents printed with an OKI LED printer, using OKI Original Consumables, have been shown to last up to 25 years without fading.

## B400/B500 Series printers

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Gross dimensions (mm) w x d x h
B401	Standard Capacity Toner Cartridge	44992401	5031713055365	1,500	300 x 80 x 93
B401	High Capacity Toner Cartridge	44992402	5031713055389	2,500	300 x 80 x 93
B410/B430/B440	Standard Capacity Toner Cartridge	43979102	5031713042327	3,500	262 x 47 x 46
B411/B431	Standard Capacity Toner Cartridge	44574702	5031713048688	3,000	300 x 80 x 93
B412/B432/B512	Standard Capacity Toner Cartridge	45807102	5031713063384	3,000	302 x 72 x 93
B412/B432/B512	High Capacity Toner Cartridge	45807106	5031713063407	7,000	302 x 72 x 93
B430/B440	Medium Capacity Toner Cartridge	43979202	5031713042358	7,000	262 x 57 x 71
B431	Medium Capacity Toner Cartridge	44574802	5031713048701	7,000	300 x 80 x 93
B431	High Capacity Toner Cartridge	44917602	5031713054641	12,000	300 x 80 x 93
B432/B512	Extra High Capacity Toner Cartridge	45807111	5031713063421	12,000	302 x 72 x 93
B440	High Capacity Toner Cartridge	43979216	5031713045656	12,000	262 x 113 x 79
B401	Image Drum	44574307	5031713054757	25,000*	315 x 245 x 230
B410/B430/B440	Image Drum	43979002	5031713042570	25,000*	320 x 125 x 145
B411/B412	Image Drum	44574302	5031713048671	25,000	373 x 243 x 224
B431/B432/B512	Image Drum	44574302	5031713048671	25,000	373 x 243 x 224

NB Toner yields based on ISO/IEC 19752 • Drums average A4 life based on a typical office environment • \*Yield based on continuous print

B512dn



# Mono Printers

## B4000 Series printers

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Gross dimensions (mm) w x d x h
B4400/B4600	Standard Capacity Toner Cartridge	43502302	5031713035404	3,000	262 x 47 x 46
B4600	High Capacity Toner Cartridge	43502002	5031713035435	7,000	262 x 57 x 71
B4400/B4600	Image Drum	43501902	5031713035466	25,000	318 x 150 x 123

NB Toner yields based on ISO/IEC 19752 • Drum yields based on continuous print

## B700 and B800 Series printers

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Gross dimensions (mm) w x d x h
B710/B720/B730	Standard Capacity Print Cartridge	01279001	5031713048268	15,000	386 x 241 x 232
B720	High Capacity Print Cartridge	01279101	5031713048275	20,000	386 x 241 x 232
B721/B731	Standard Capacity Print Cartridge	45488802	5031713059752	18,000	326 x 396 x 246
B731	High Capacity Print Cartridge	45439002	5030016390012	36,000	326 x 396 x 246
B721/B731	Maintenance Kit	45435104	5031713059561	200,000	393 x 160 x 269
B730	High Capacity Print Cartridge	01279201	5031713048282	25,000	386 x 241 x 232
B840	Print Cartridge	44661802	5031713051024	20,000	496 x 255 x 286

NB Print cartridge yields based on ISO/IEC 19752 • Maintenance kit average A4 life based on a typical office environment

## B930 printers

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Gross dimensions (mm) w x d x h
B930	Toner Cartridge	01221601	5031713041092	33,000	428 x 141 x 132
B930	Image Drum	01221701	5031713041108	60,000	492 x 196 x 190
B930	Maintenance Kit	01226701	5031713041986	300,000	573 x 205 x 305
B930	Staples	01244301	5031713043386	N/A	127 x 77 x 50

NB Toner yields based on ISO/IEC 19752 • Drum yield based on continuous print

B731dnw



Did you know...  
OKI's ID Card function  
allows you to scan your  
double sided ID card to a  
single page.



**ID CARD  
FUNCTION**

## C9800 Series colour MFPs

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Gross dimensions (mm) w x d x h
C9800 MFP/C9850 MFP	Black Toner	42918916	5031713026846	15,000	484 x 102 x 117
C9800 MFP/C9850 MFP	Cyan Toner	42918915	5031713026839	15,000	484 x 102 x 117
C9800 MFP/C9850 MFP	Magenta Toner	42918914	5031713026860	15,000	484 x 102 x 117
C9800 MFP/C9850 MFP	Yellow Toner	42918913	5031713026815	15,000	484 x 102 x 117
C9800 MFP/C9850 MFP	Toner Rainbow Pack	43112702	5031713028895	15,000	483 x 279 x 141
C9800 MFP/C9850 MFP	Black Image Drum	42918108	5031713026570	30,000	528 x 162 x 200
C9800 MFP/C9850 MFP	Cyan Image Drum	42918107	5031713026563	30,000	528 x 162 x 200
C9800 MFP/C9850 MFP	Magenta Image Drum	42918106	5031713026556	30,000	528 x 162 x 200
C9800 MFP/C9850 MFP	Yellow Image Drum	42918105	5031713026549	30,000	528 x 162 x 200
C9800 MFP/C9850 MFP	Transfer Belt	42931603	5031713026990	100,000 (A4 LEF)	489 x 459 x 199
C9800 MFP/C9850 MFP	Fuser Unit	42931703	5031713026983	100,000 (A4 LEF)	517 x 217 x 141
C9800 MFP/C9850 MFP	Waste Toner System	42869403	5031713027003	30,000	574 x 160 x 110
C9800 MFP/C9850 MFP	Staples	42937603	5031713027010	N/A	163 x 64 x 42

NB Toner yields based on 5% coverage • Drums average A4 life based on a typical office environment • Transfer belt yield based on 3 pages per job A4

## Mono MFPs

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Gross dimensions (mm) w x d x h
MB441/MB451	Standard Capacity Toner Cartridge	44992401	5031713055365	1,500	300 x 80 x 93
MB441/MB451	High Capacity Toner Cartridge	44992402	5031713055389	2,500	300 x 80 x 93
MB460/MB470/MB480	Standard Capacity Toner Cartridge	43979102	5031713042327	3,500	262 x 47 x 46
MB461/MB471/MB491	Standard Capacity Toner Cartridge	44574702	5031713048688	3,000	300 x 80 x 93
MB472/MB492/MB562	Standard Capacity Toner Cartridge	45807102	5031713063384	3,000	302 x 72 x 93
MB472/MB492/MB562	High Capacity Toner Cartridge	45807106	5031713063407	7,000	302 x 72 x 93
MB460/MB470/MB480	Medium Capacity Toner Cartridge	43979202	5031713042358	7,000	262 x 57 x 71
MB461/MB471/MB491	Medium Capacity Toner Cartridge	44574802	5031713048701	7,000	300 x 80 x 93
MB480	High Capacity Toner Cartridge	43979216	5031713045656	12,000	262 x 113 x 79
MB491	High Capacity Toner Cartridge	44917602	5031713054641	12,000	300 x 80 x 93
MB492/MB562	Extra High Capacity Toner Cartridge	45807111	5031713063421	12,000	302 x 72 x 93
MB441/MB451	Image Drum	44574307	5031713054757	25,000	391 x 258 x 236
MB460/MB470/MB480	Image Drum	43979002	5031713042570	25,000*	320 x 125 x 145
MB461/MB471/MB491	Image Drum	44574302	5031713048671	25,000	373 x 243 x 224
MB472/MB492/MB562	Image Drum	44574302	5031713048671	25,000	373 x 243 x 224
MB760/MB770	Standard Capacity Print Cartridge	45488802	5031713059752	18,000	326 x 396 x 246
MB770	High Capacity Print Cartridge	45439002	5030016390012	36,000	326 x 396 x 246
MB760/MB770	Maintenance Kit	45435104	5031713059561	200,000*	393 x 160 x 269
MB760/MB770	Staples Offline (3000 staples)	45513301	5031713059820	N/A	57 x 57 x 11
MB760/MB770	Staples Finisher (15000 staples)	42937603	5031713027010	N/A	163 x 64 x 42

NB Toner yields based on ISO/IEC 19752 • Drums average A4 life based on a typical office environment • \*Yield based on continuous print

## MB700 Series print cartridge



## MB562



# Product compatibility

## B and MB Series mono printers and mono MFPs

Order codes	01101202	01103402	01221601	43502002	43502302	43979102	43979202	43979216	44574702	44574802	44917602	44992401	44992402	45807102	45807106	45807111	01221701	42102802	43501902	43979002	44574302	44574307	01225401	01239901	01240001	01279001	01279101	01279201	09004391	09004447	09004461	09004462	44661802	45488802	45439002	01226701	45435104	01244301	42937603	45513301						
B401											T	T										EP																								
B410				T																		EP																								
B411						T																EP																								
B412															T	T						EP																								
B430					T	T																EP																								
B431							T	T	T													EP																								
B432															T	T	T					EP																								
B440					T	T	T															EP																								
B4100/B4200/B4250	T																				EP																									
B4300/B4350	T	T																			EP																									
B4400				T																	EP																									
B4600				T	T																EP																									
B512															T	T	T				EP																									
B6500																																														
B710																																														
B720																																														
B721																																														
B730																																														
B731																																														
B840																																														
B930			T																		EP																									
MB441/MB451																																														
MB460/MB470					T	T																EP																								
MB461/MB471								T	T													EP																								
MB472																						EP																								
MB480					T	T	T															EP																								
MB491								T	T	T												EP																								
MB492/MB562																						EP																								
MB760																																														
MB770																																														

Key: T = Toner EP = Image drum PC = Print cartridge DV = Developer cartridge MK = Maintenance kit S = Staples

# Product compatibility

## Dot Matrix printers

Order codes	01126301	09002303	09002308	09002309	09002310	09002311	09002315	09002316	09002631	09002966	09004294	40629303	43503601	43571802	43821103	44173405	44173406	
MICROLINE 182/183		R																
MICROLINE 192/193		R																
MICROLINE 280 (elite/eco)		R																
MICROLINE 320/321 (elite)		R																
MICROLINE 320FB					R													
MICROLINE 380/385/386				R														
MICROLINE 390/391 (elite)				R														
MICROLINE 390FB					R													
MICROLINE 393(C)/395(C) BLACK						R												
MICROLINE 520/521 (elite)							R											
MICROLINE 590/591 (elite) BLACK								R										
MICROLINE 1120/1190																		R
MICROLINE 3320/3321		R																
MICROLINE 3390/3391					R													
MICROLINE 3410				R														
MICROLINE 4410																		R
MICROLINE 5100FB																		R
MICROLINE 5520/5521/5590/5591	R																	
MICROLINE 5720																		R
MICROLINE 5721																		R
MICROLINE 5790																		R
MICROLINE 5791																		R
MICROLINE 6300FB																		R
MX 100yrd ribbon (standard)									R									
MX 90m ribbon (Gold Series)										R								
MX 1050/1100/1150/1200											R							

Key: R = Ribbon

## Business Printing Specialists

OKI is a global business-to-business brand dedicated to creating cost effective, professional in-house printing solutions which are designed to increase the efficiency of today's and tomorrow's businesses and their workflows. As pioneers in innovative print technologies from digital LED to High Definition Colour, we have a portfolio of award winning A3 and A4 colour and mono printers and MFPs, for workgroups and businesses of all sizes. This combined with our solutions enables businesses to achieve both image focused, vibrant, professional quality print communications and budget flexibility.

OKI's portfolio also includes precision-engineered large-format printing systems specifically designed for the sign, graphics, CAD and GIS markets that provide industry-leading productivity and image quality. In addition, our POS and dot matrix printers complete our range of printing solution.



### Considering the Environment

OKI is committed to its role as a responsible partner for all its stakeholders: Shareholders, business partners, end-users, local communities and employees.

As part of the OKI Group's Charter of Corporate Conduct, OKI continually reviews its efforts to provide environmentally sound solutions to its customers:

- OKI products are designed and manufactured with reducing the impact on the environment in mind.
- Increasing the amount of our hardware products and consumables that are recycled is one of our strategic objectives.
- We feel responsible for conducting our business in an environmentally sound manner, contributing to conservation and activities within our local communities.

OKI's Green Leaf symbol, found on all products and packaging, represents our total commitment to collection, recycling and environmental processes.



### 3 Year Warranty

Our devices are manufactured to the highest standards of quality and technology, which has been confirmed by independent tests.

We are so convinced of the high quality of our products that we are offering you an extension of the standard warranty period to 3 years – for free! Simply register your product within 30 days of purchase to be eligible for our unique all inclusive offer. Fully covered by OKI! For further information please visit your local website.



### 20 years of LED Technology

OKI pioneered the development of digital LED technology in printers over 20 years ago. This innovation delivers High Definition printing – for more accurate, striking printed documents. Thanks to this digital LED technology, our printers are compact, environmentally friendly and energy efficient, using significantly less raw materials in the manufacturing process and consuming less energy. LED print heads have no moving parts, making our LED printers robust and ultra reliable.



### High Definition Colour

High Definition Colour is OKI's own unique collection of market-defining hardware and software technologies. Together, these components deliver unsurpassed colour printing – simply, intelligently, perfectly.

We pioneered Single-pass Flat Paper Path technology to bring you fast affordable colour printing. In consumables, we created a special Microfine High Definition Toner to ensure your documents are printed in superior quality.

We championed digital LED printing technology: our High Definition LED printheads have no moving parts and deliver pin sharp images.

The combination of the range of media and software solutions we offer means you have much more control of what you want to print, when you want to print – without leaving the office.

### OKI EUROPE LTD.

EMEA Head Office  
Blays House, Wick Road  
Egham TW20 0HJ  
United Kingdom  
T +44(0) 20 8219 2190  
F +44(0) 20 8219 2199  
[WWW.OKI.COM/EU](http://WWW.OKI.COM/EU)