


CP-3006 Series Parallel Action Crimping Tool

For open barrel terminal and solar connectors

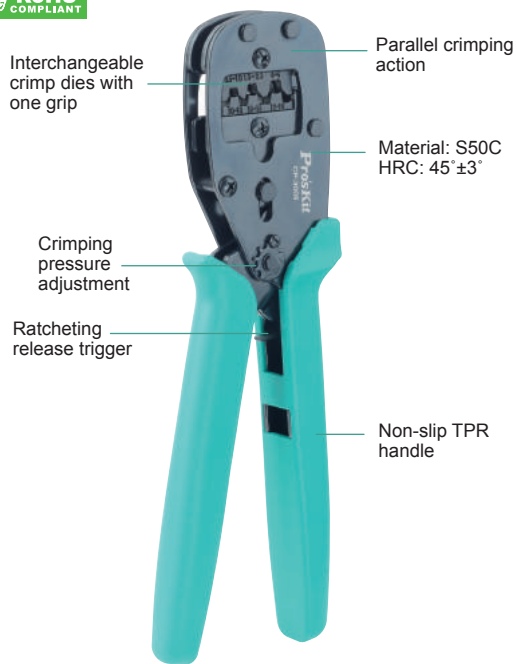


- **Reliable:** Parallel action crimping performance is consistent and accurate
- **Practical:** Safety crimp release helps eliminate rejected terminations due to incorrect positioning.
- **Comfortable:** Ergonomically shaped non-slip TPR handle for comfortable use in all conditions
- **Versatile:** Interchangeable die sets for wide range of applications.



Material		HRC	OAL. (mm)	Individual packing
Body	Handle			
S50C	TPR	45° ±3'	254	Blister card

Model No.	DIE Set	Crimp die profile	Application	Terminals
CP-3006FD2			Non insulated open barrel connectors, commercial type AWG 22-18/16-14/12-10 DIN 0.5-1.0/1.5-2.5/4.0-6.0 mm ² JIS 0.35-0.9/1.25-2.0/3.5-5.5 mm ²	
CP-3006FD18			Pin terminal insulated or non-insulated ferrules, cord end terminals AWG 22/20/18/16/14/12 DIN 0.5/0.75/1.0/1.5/2.5/4.0 mm ² JIS 0.35/0.5/0.9/1.25/2.0/3.5 mm ²	
CP-3006FD36			Non-insulated open barrel connectors & D-SUB V.35 contact pins AWG 30-24/22-18 DIN 0.05-0.25/0.50-1.0 mm ² JIS 0.05-0.25/0.35-0.9 mm ²	
CP-3006FD45			Non-insulated open barrel connectors AWG 22-18/16-14/12-10 DIN 0.5-1.0/1.5-2.5/4.0-6.0 mm ² JIS 0.5-0.9/1.25-2.0/3.5-5.5 mm ²	
CP-3006FD46			Insulated open barrel connectors commercial type AWG 22-18/16-14 DIN 0.5-1.0/1.5-2.5 mm ² JIS 0.5-1.0/1.25-2.0 mm ²	
CP-3006FD47			Insulated open barrel connectors commercial type AWG 20-18/16-14/12-10 DIN 0.5-1.0/1.5-2.5/4.0-6.0 mm ² JIS 0.5-1.0/1.25-2.0/3.5-5.5 mm ²	
CP-3006FS1			For MC 3 solar connector (Multi-Contact) & 2.5/4.0/6.0 mm ² (AWG 14/12/10) solar cable AWG 14/12/10 DIN 2.5/4.0/6.0 mm ²	
CP-3006FS2			For MC 4 solar connector (Multi-Contact) & 2.5/4.0/6.0 mm ² (AWG 14/12/10) solar cable AWG 14/12/10 DIN 2.5/4.0/6.0 mm ²	

Crimping Tool

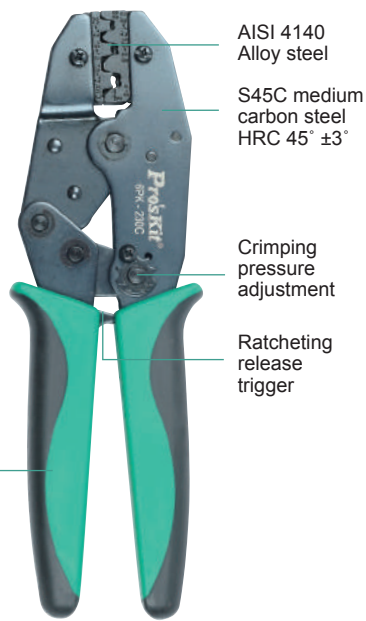

Elastomeric resin fitting exactly and double structure. Non-slip. Green: PP Balck: T.P.R

OAL. (mm)	Individual packing
220	Blister card

Model No.	Description	Crimping die profile	Application	Crimp Size
6PK-230C	Inter-locking & Non-insulated		Non-insulated terminal or open barrel terminal	AWG 20-18/16-14/12-10 DIN 0.5-1.0/1.5-2.5/4.0-6.0 mm ² JIS 0.5-0.9/1.25-2.0/3.5-5.5 mm ²
6PK-301E	Usable for cord end terminals		Pin terminal insulated & non-insulated wire ferrules	AWG 22/20/18/16/14/12 DIN 0.5/0.75/1.0/1.5/2.5/4.0 mm ² JIS 0.35/0.5/0.9/1.25/2.0/3.5 mm ²
6PK-301H	Insulated terminals/color coded nests		Insulated terminals & lugs	AWG 22-18/16-14/12-10 DIN 0.5-1.0/1.5-2.5/4.0-6.0 mm ² JIS 1.25/2.0/3.5-5.5 mm ²
6PK-301N	Non-insulated terminal		Non-insulated terminal & plugs	AWG 20-18/16-14/12-10/8 DIN 1.5/2.5/6.0/10.0 mm ² JIS 1.25/2.0/3.5-5.5/8.0 mm ²
6PK-301R	Vinyl insulated W/O copper sleeve		Vinyl insulated W/O copper sleeve	AWG 22-18/16-14/12-10 DIN 0.5-1.0/1.5-2.5/4.0-6.0 mm ² JIS 1.25/2.0/3.5-5.5 mm ²
6PK-301S	Usable for cord end terminals		Pin terminal insulated & non-insulated wire ferrules	AWG 10/8/6 DIN 6.0/10.0/16.0 mm ² JIS 5.5/8.0/14.0 mm ²
6PK-301U	Non-insulated open barrel connectors & D-SUB V.35		Non-insulated open barrel connectors & D-SUB V.35 terminal	AWG 22/14 DIN 0.5/2.5 mm ² JIS 0.35/2.0 mm ²
6PK-230PA	Coaxial connectors crimping tool		For crimping RG type cables 55, 58, 59, 5, 6, 21, 141, 142, 143, 210, 212, 222, 223, 303, 304, 400 Belden: 8279, 8281, 9231 & 9141	HEX .068", .098", .213", .255", .321" HEX 1.73, 2.49, 5.41, 6.48, 8.15 mm
8PK-301C	Coaxial crimping tool		RG58, RG59, RG62, RG6	HEX .068", .213", .256", .319" HEX 1.73, 5.41, 6.50, 8.10 mm
8PK-301F1	Fiber optic crimping tool		SMA, SRF, SMF fiber optic connectors	SQ .042", HEX .068", RND .133", .162", .195" SQ 1.07, HEX 1.73, RND 3.38, 4.11, 4.95 mm
8PK-301F2	Fiber optic crimping tool		SMA, SMB, FC Biconic and SC & ST fiber optic connectors, RG58, RG174, Belden8218	SQ .042", HEX .068", .151", .178", .213" SQ 1.07, HEX 1.73, 3.84, 4.52, 5.41 mm
CP-301F4	Fiber optic crimping tool		For FC, SC, ST, LC, SMA & MT-RJ fiber optic connectors	HEX .139", .151", .178", RND .134", .190" HEX 3.53, 3.84, 4.52, RND 3.40, 4.83 mm
8PK-301J	Fiber optic crimping tool		RG174, RG179, Belden 8218 fiber optic	SQ .042", HEX .068", .078", .128", .151", .178" SQ 1.07, HEX 1.73, 1.98, 3.25, 3.84, 4.52 mm



For 6PK-230C For 6PK-301N For 6PK-301H For 6PK-301S 6PK-301E For 6PK-301R For 6PK-301U For 6PK-230PA 8PK-301A 8PK-301C For 8PK-301F1 / 8PK-301F2 CP-301F4 / 8PK-301J

CRIMPERS