



# & Inspection Cameras Accessories



# RS 8mm Video Recording Inspection Camera With Extendable/Changeable Lens

RS Stock number **847-8947**



# RS 8mm Video Recording Inspection Camera With Extendable/Changeable Lens

RS Stock number **847-8947**



Professional and high quality video boroscope that makes it easy to inspect hard to reach and hard to see areas and equipment. Smaller 5.5mm Lens available.

Excellent for automotive applications, i.e. internal inspections and reading stamped identifications etc.

- Photo & Video Recordable
- Great Design with up to x4 Zoom Function
- 1/9in VGA CMOS Sensor with 640 x 480 Pixel Resolution
- 2.7in Colour LCD with 960 x 240 Pixel Resolution
- Lens Outer Diameter 8.0mm
- Flexible Gooseneck Outer Diameter 6.5mm
- Water Proof IP67
- Upside Down Screen Function



**Supplied with Rigid carry Case; Hook, Magnet & Mirror accessories**

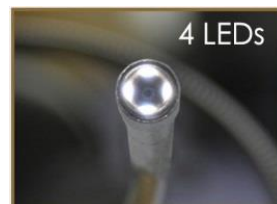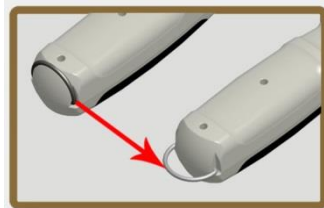

- ▶ Micro SD card : Support Micro SD up to 32GB (not included)
- ▶ Operating Voltage : 4 x 1.5 V AA battery (not included)
- ▶ Current consumption : max. 350 mA
- ▶ Display : 2.7" TFT
- ▶ Resolution : 960 x 240 pixels (monitor), 640 x 480 pixels (camera)
- ▶ Video frame rate : 30 frames / second
- ▶ Video format : AVI
- ▶ Image format : JPG
- ▶ USB Standard : 1.1
- ▶ Camera lighting : 4 white LEDs
- ▶ Camera White balance : automatic
- ▶ Camera Exposure : automatic

- ▶ Camera Field of view : 54°
- ▶ Camera Depth of field : 6 - infinite
- ▶ Operating temperature : 0 to +45 °C
- ▶ Operating humidity : 15 - 85% RH
- ▶ Storage temperature : -10 to +50 °C
- ▶ Storage humidity : 15 - 85% RH
- ▶ Gooseneck length : 88 cm ± 2 cm
- ▶ Camera ø : 8.0 mm
- ▶ Min. bending radius : 45 mm
- ▶ Total length of device : 120 ± 2 cm
- ▶ Weight : approx. 335 g





# RS 8mm Video Inspection Camera

RS Stock number **847-8956**



# RS 8mm Video Inspection Camera

RS Stock number **847-8956**

Professional and high quality video boroscope that makes it easy to inspect hard to reach and hard to see areas and equipment.

Excellent for automotive applications, i.e. internal inspections and reading stamped identifications etc.



- Great Design with up to x2 Zoom Function
- 1/9in VGA CMOS Sensor with 640 x 480 Pixel Resolution
- 2.31in Colour LCD with 960 x 240 Pixel Resolution
- Lens Outer Diameter 8.0mm
- Flexible Gooseneck Outer Diameter 6.5mm
- Water Proof IP67
- Upside Down Screen Function

**Supplied with Rigid carry Case; Hook, Magnet & Mirror accessories**



- ▶ Operating Voltage : 4 x 1.5 V AA battery (not included)
- ▶ Current consumption : max. 250 mA
- ▶ Display : 2.31" TFT LCD
- ▶ Resolution : 960 x 240 pixels (monitor), 640 x 480 pixels (camera)
- ▶ Camera lighting : 4 white LEDs
- ▶ Camera White balance : automatic
- ▶ Camera Exposure : automatic
- ▶ Camera Field of view : 54°
- ▶ Camera Depth of View: > 3 cm


- ▶ Operating temperature : 0 to +45 °C
- ▶ Operating humidity : 15 - 85% RH
- ▶ Storage temperature : -10 to +50 °C
- ▶ Storage humidity : 15 - 85% RH
- ▶ Gooseneck length : 88 cm ± 2 cm
- ▶ Camera  $\varnothing$ : 8.0 mm
- ▶ Min. bending radius : 45 mm
- ▶ Total length of device : 120 ± 2 cm
- ▶ Weight : approx. 315 g



# RS Video Inspection Camera Accessories

## 5.5mm Diameter screw on Hook, Magnet and Mirror

RS Stock number **847-8953**

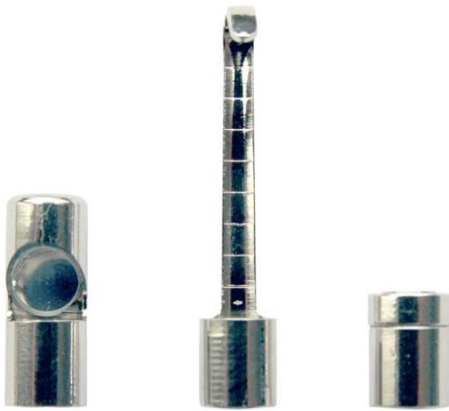

Material:  
Steel

Accessories:  
1pc - Hook  
1pc - Mirror for viewing blind angles  
1pc - Magnet for picking up fasteners etc


For 5.5mm lens

## 5.5mm Camera Lens

RS Stock number **847-8959**



- Camera sensor resolution: 640 x 480 pixels
- Built with 4 LEDs
- PE covered flexible camera cable is waterproof rated IP67
- Min bending radius 45mm
- Camera exposure: Automatic
- Camera field of view: 54°
- Camera depth of field: 3cm – infinite
- Operating temperature: 0 ~ 45°C
- Operating humidity: 15 ~ 85% RH
- Storage temperature: -10 ~ 50°C
- Storage humidity: 15 ~ 85% RH
- Camera cable length: 88 +/- 2cm

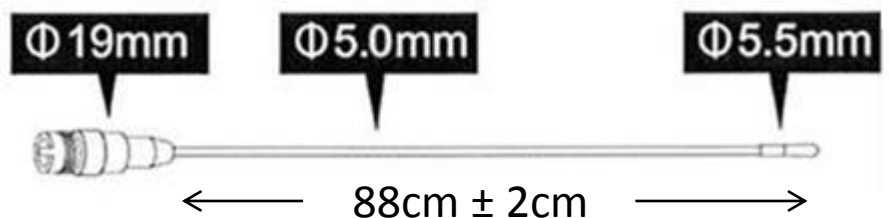

# IP67 Inspection DVR Torch

RS Stock number **877-3396**





# IP67 Inspection DVR Torch

RS Stock number **877-3396**

## Specification

- 1.5" TFT LCD resolution 480x240
- Video display with stills and video recording
- Supports microSDHC card (class 4 or above) (max. 32GB)
- Powered by embedded rechargeable Li-ion Battery 3.7 V / 4400 mAh
- Powered by 3 Super Bright LED's
- 8hrs to full charge with supplied wall charger
- The whole unit is waterproof to IP67
- High Power LED x 3 PCS
- Depth of view: 60 cm

- Image resolution:  
5M(2592\*1944), 3M(2048\*1536), 1M(1280\*720), VGA(640\*480)
- Video resolution:  
1280\*720(HD), 640\*480(VGA), Frame Rate: 30 fps

Power Led lighting over 307.80 lumens

- Operating Temperature 0°C (0%) to 50°C (RH60%)
- Storage Temperature -10°C (0%) to 50°C (RH90%)

USB-mini USB cable included to charge battery



Using enclosed USB cable to copy recorded videos and pictures to PC. (Stop shooting video first)

