


Original Consumables Catalogue 2012

Colour
Mono
MFPs
Fax
Dot Matrix
Media

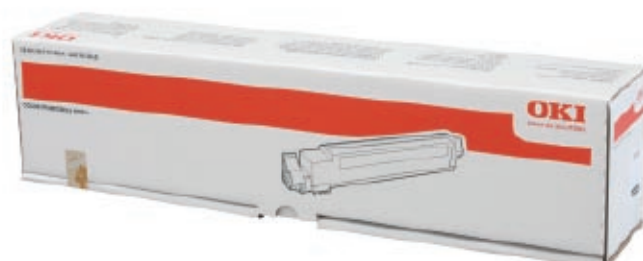

Fax

- OKIs Original Consumables are designed exclusively for use with OKI fax products
- Low melt formulation for high resolution, high speed printing
- User-friendly design for clean and fast replacement

OKIFAX 170



Digital LED fax

Printer model	Consumable	Order code	Unitary EAN code	Life (pages)	Unitary packaged product	
					Gross weight (kg)	Gross dimensions (mm) w x d x h
OKIFAX 160	Print Cartridge	01234101	5031713042945	2,400***	0.990	345 x 155 x 145
OKIFAX 170	Print Cartridge	01290801	5031713049814	2,000***	1.000	300 x 110 x 180
OKIFAX 1000/1050	Toner Cartridge	09002395	5031713651000	2,500*	0.148	260 x 55 x 45
OKIFAX 1000/1050	Image Drum	09001042	5031713652007	20,000**	1.060	300 x 145 x 120
OKIFAX 2200/2350	Toner Cartridge	09002395	5031713651000	2,500*	0.148	260 x 55 x 45
OKIFAX 2200/2350	Image Drum	09001042	5031713652007	20,000**	1.060	300 x 145 x 120
OKIFAX 2400/2450/2600	Toner Cartridge	09002395	5031713651000	2,500*	0.148	260 x 55 x 45
OKIFAX 2400/2450/2600	Image Drum	09001042	5031713652007	20,000**	1.060	300 x 145 x 120
OKIFAX 2510	Std Cap Print Cartridge	09004447	5031713928997	2,200***	1.200	350 x 215 x 160
OKIFAX 2510	High Cap Print Cartridge	09004391	5031713928546	4,000***	1.200	350 x 215 x 160
OKIFAX 4510	Print Cartridge	09004097	5031713926092	5,000*	1.028	350 x 150 x 145
OKIFAX 4515	Print Cartridge	09004245	5031713926443	3,300***	1.110	345 x 155 x 145
OKIFAX 4500/4550/4580	Toner Cartridge	00079801	5031713451839	1,875*	0.108	260 x 55 x 45
OKIFAX 4500/4550/4580	Image Drum	40709902	5031713451792	10,000**	0.810	320 x 115 x 95
OKIFAX 5200/5400/5500	Toner Cartridge	09002395	5031713651000	2,500*	0.148	260 x 55 x 45
OKIFAX 5200/5400/5500	Image Drum	09001042	5031713652007	20,000**	1.060	300 x 145 x 120
OKIFAX 5650/5680	Toner Cartridge	09002395	5031713651000	2,500*	0.148	260 x 55 x 45
OKIFAX 5650/5680	Image Drum	09001042	5031713652007	20,000**	1.060	300 x 145 x 120
OKIFAX 5700/5750/5900/5950	Toner Cartridge	40815604	5031713002024	3,000*	0.192	262 x 55 x 45
OKIFAX 5700/5750/5900/5950	Image Drum	01008201	5031713007111	20,000**	1.113	300 x 145 x 120
OKIFAX 5780/5980	Toner Cartridge	01074705	5031713014225	3,500*	0.250	262 x 69 x 48
OKIFAX 5780/5980	Image Drum	01008201	5031713007111	20,000**	1.113	300 x 145 x 120

NB * At 4% coverage A4 ** Continuous print *** Yield compliant with ISO/IEC 19752 Std Cap = Standard Capacity High Cap = High Capacity

Product compatibility

Fax and MFPs

Order codes	00079801	01074705	09002701	09002989	09002395	40815604	01008201	09001042	09002700	09002990	40709902	01234101	01290801	09004097	09004245	09004391	09004447
OKIFAX 160												PC					
OKIFAX 170													PC				
OKIFAX 1000/1050/2200					T			EP									
OKIFAX 2350/2400/2450/2600					T			EP									
OKIFAX 2510															PC	PC	
OKIFAX 4500/4550/4580	T									EP							
OKIFAX 4510													PC				
OKIFAX 4515														PC			
OKIFAX 5200/5200 Plus					T			EP									
OKIFAX 5400/5500/5500 Plus					T			EP									
OKIFAX 5650/5680					T			EP									
OKIFAX 5700/5900						T	EP										
OKIFAX 5750/5950						T	EP										
OKIFAX 5780/5980		T					EP										
OKIOFFICE 84/86/87	T									EP							
OKIOFFICE 120			T					EP									
OKIOFFICE 1200/1600				T					EP								
OKIOFFICE 2530															PC	PC	

Key: T = Toner EP = Image drum PC = Print cartridge R = Ribbon I = Ink cartridge

Business Printing Specialists

OKI is a global business-to-business brand dedicated to creating cost effective, professional in-house printing solutions which are designed to increase the efficiency of today's and tomorrow's businesses and their workflows. As pioneers in innovative print technologies from digital LED to High Definition Colour, we have a portfolio of award winning products and solutions enabling businesses to achieve both image focused, vibrant, quality print communications and budget flexibility.

OKI presents a full range of A3 and A4 colour and mono printers and MFPs, for workgroups and businesses of all sizes with superior media-handling capabilities. In addition our fax, POS and dot matrix printers complete our range of print solutions. These best in class products are designed to be easy to use making the job of in-house print easier.



Considering the Environment

OKI is committed to its role as a responsible partner for all its stakeholders:

Shareholders, business partners, end-users, local communities and employees.

As part of the OKI Group's Charter of Corporate Conduct, OKI continually reviews its efforts to provide environmentally sound solutions to its customers:

- OKI products are designed and manufactured with reducing the impact on the environment in mind.
- Increasing the amount of our hardware products and consumables that are recycled is one of our strategic objectives.
- We feel responsible for conducting our business in an environmentally sound manner, contributing to conservation and activities within our local communities.

OKI's Green Leaf symbol, found on all products and packaging, represents our total commitment to collection, recycling and environmental processes.



Simply Unique – 3 Year Warranty

Our devices are manufactured to the highest standards of quality and technology, which has been confirmed by independent tests.

We are so convinced of the high quality of our products that we are offering you an extension of the standard warranty period to 3 years – for free! Simply register your product within 30 days of purchase to be eligible for our unique all inclusive offer. Fully covered by OKI!

For further information please visit your local website.



20 years of LED Technology

OKI pioneered the development of digital LED technology in printers over 20 years ago. This innovation delivers High Definition printing – for more accurate, striking printed documents. Thanks to this digital LED technology, our printers are compact, environmentally friendly and energy efficient, using significantly less raw materials in the manufacturing process and consuming less energy. LED print heads have no moving parts, making our LED printers robust and ultra reliable.



High Definition Colour

High Definition Colour is OKI's own unique collection of market-defining hardware and software technologies. Together, these

components deliver unsurpassed colour printing – simply, intelligently, perfectly.

We pioneered Single-pass Flat Paper Path technology to bring you fast affordable colour printing. In consumables, we created a special Microfine High Definition Toner to ensure your documents are printed in superior quality.

We championed digital LED printing technology: our High Definition LED printheads have no moving parts and deliver pin sharp images.

The combination of the range of media and software solutions we offer means you have much more control of what you want to print, when you want to print – without leaving the office.

ISO Sets the Standard

The range of Original Consumables carrying the ISO Standard continues to grow. ISO/IEC 19752 now incorporates the majority of our mono printers and fax machines. In addition, we continue to expand on this by introducing the ISO/IEC 19798 standards for our latest colour printers. These ISO Standards are the industry-recognised benchmark for measuring toner yields of consumables.

OKI EUROPE LTD.

Blays House, Wick Road
Egham TW20 0HJ
United Kingdom
T +44(0) 20 8219 2190
F +44(0) 20 8219 2199

WWW.OKIPRINTINGSOLUTIONS.COM

Only use genuine Oki Original Consumables to ensure the best quality and performance from your hardware. Non Oki Original products may damage your printer's performance and invalidate your warranty. Specifications subject to change without notice. All trademarks acknowledged.

© 2012 Oki Europe Ltd. Version 1 04/2012.

OKI