

WMP

65 watt pencil provides fast heat-up and good thermal recovery

65W, 24V



Short tip-to-grip
37mm / 1.46"
Built-in heating element

WMP TWMP Pencil, NT1 tip

WMPSET
T0052917999
WMP pencil, NT1 tip, WDH20 stand



NT SERIES TIPS

			A		B		C	
Type	Catalog number		in	mm	in	mm	in	mm
Micro	NT1		0.010	0.25			0.291	7.40
Micro	NT1S		0.010	0.25			0.333	8.45
Bent Round	NT1X		0.016	0.40	0.063	1.60	0.321	8.15
Round	NT4		0.047	1.20			0.390	9.90
Chisel	NT6		0.063	1.60	0.016	0.40	0.372	9.45
	NTA		0.063	1.60	0.016	0.40	0.331	8.40
	NTB		0.094	2.40	0.031	0.80	0.289	7.35
	NTC		0.126	3.20	0.031	0.80	0.305	7.75
	NTD		0.157	4.00	0.031	0.80	0.305	7.75
	NTH		0.031	0.80	0.016	0.40	0.331	8.40
	NTK		0.047	1.20	0.016	0.40	0.331	8.40
Fine Chisel	NT1SC		0.130	3.30			0.325	18.00
Bent Chisel	NTAX		0.075	1.90	0.028	0.70	0.325	18.00
Gull wing for drag soldering	NTGW		0.106	2.70	0.047	1.20	1.142	29.00

Tip removal tool T0058751710

WSP150

For jobs with extremely high heat requirements and large heat sinks.

150W, 24V



Effective heat transfer
High power and quick response

WSP150 T0052917099

WSP150SET
T0052918999
WSP150, LHTF tip, WDH30 stand



Catalog number	Order number	Style	A	B
LHTD	T0054445299	Chisel	0.197" (5.0 mm)	0.79" (2.0 mm)
LHTE	T0054445199	Chisel	0.276" (7.0 mm)	0.79" (2.0 mm)
LHTF	T0054445099	Chisel	0.366" (9.3 mm)	0.79" (2.0 mm)
LHTD45	T0054445699	Sloped 45°	0.197" (5.0 mm)	-
LHTDX	T0054446299	Chisel bent	0.199"(5.0mm)	0.79" (2.0 mm)
LHTEX	T0054446199	Chisel bent	0.276"(7.0mm)	0.79" (2.0 mm)
LHTFX	T0054446099	Chisel bent	0.354"(9.0mm)	0.79" (2.0 mm)



WHP200

Order number: WHP200
120V, 50/60Hz, 200W infrared
150°F - 750°F (50°C - 400°C)
4.72" x 2.36" (120mm x 60mm)
ESD safe



WHP1000

Order number: WHP1000
120V, 50/60Hz, 850W infrared
150°F - 570°F (50°C - 300°C)
6.0" x 8.75" (150mm x 220mm)
ESD safe




WHP3000

Order number: WHP3000
120V, 50/60Hz, 200-600W infrared
150°F - 750°F (50°C - 400°C)
ESD safe



WHP80

Order number: T0052702899
Hot plate 3.2" x 2"
80W, 24V
150°F - 400°F (50°C - 200°C)
3.15" x 1.97" (80mm x 50mm)

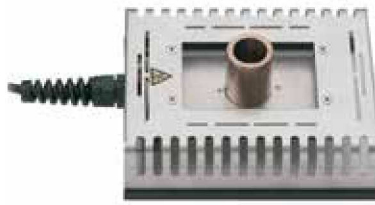

WSB80

Order number: T0052704099
80W, solder bath, 24V
150°F - 850°F (50°C - 450°C)
0.79" x 0.98" (20mm x 25mm)



WSB150

Order number: T0052704299
150W, solder bath, 24V
150°F - 850°F (50°C - 450°C)
2.28" x 1.30" x 0.748"
(58mm x 33mm x 19mm)



TIPLET REMOVAL PLIERS

Order number: T0058765801
Ergonomically shaped handles
prevent hand fatigue, DX/XDS/XDSL
tiplets are easy to change



WVP

Order number: T0052918499
Vacuum pick-up pen
WR3M only

AIR FILTERS FOR WR2/WR3M/WR3ME (3/pk)

Order number:
T0058759725

AIR FILTERS FOR WR2/WR3M/WR3ME (3/PK)

Order number:
T0058759726