


Zero Smog® TL

The next level in removing dangerous gases and particles

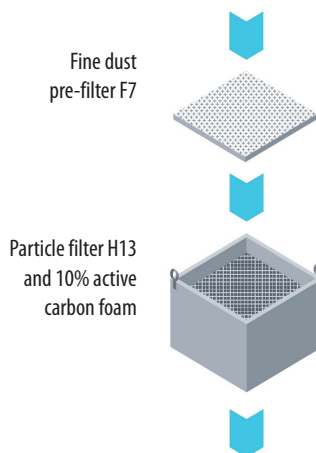

Features and Benefits

- > Extraction unit for up to 2 workplaces
- > Low noise levels
- > Portable, for placement under or next to the bench
- > Easy filter replacement
- > Audio-visual filter change alarm
- > Quick and simple installation with Easy-Click system
- > Variable speed setting
- > Active carbon foam filter for effective gas cleaning
- > Maintenance-free, brushless EC blower
- > Easily operated

Technical Data

Dimensions (L x W x H)	335 x 330 x 445 mm
Weight	9 kg
Voltage	120 V, 60 Hz
Noise level	< 50 db (A)
Electrical power	120 W
Max. blower vacuum	3,000 Pa
Max. blower capacity	190 m³/h
Pre-filter	F7 fine dust filter
Compact filter	Particle filter H13 + 10% carbon foam gas filter
Particle filter MPPS	>99.95%

Zero Smog® TL

- > Zero Smog® TL fume extraction unit
- > H13 particle filter and gas filter (10% active carbon foam filter)
- > F7 pre-filter

Order No. **ZEROSMOGTL**

Zero Smog® TL Kit 1 with Funnel Nozzle

- > Zero Smog® TL fume extraction unit
- > Stop valve with bench mounting brackets
- > Flexible, adjustable extraction arm, 1 m, ø 60 mm
- > Extraction hose, flexible, 3 m, ø 60 mm
- > ALFA funnel nozzle
- > Remote switch

Order No. 120 V **ZEROSMOGTLKIT1**

Filter Set H13

- > H13 particle filter and gas filter (10% active carbon foam filter) and ten F7 pre-filters

Order No. **T0058762858**

Fine dust prefilter F7 (10)

Order No. **T0058762857**

Remote switch

- > Cable length 2m

Order No. **FT91000033**

