

Expressive Quality. Impressive Technology

Performing well beyond the expectations for a DSLR camera in its class, the EOS 750D is apt for demanding users who want to move on a notch higher, while the professional-look EOS 760D – with Top LCD Panel and Quick Control Dial – is ideal for those keen on greater control as they ascend in their photographic journey.

24.2
MEGA
PIXELS
CMOS

24.2 MP CMOS IMAGE CLARITY

A 24.2-Megapixel APS-C sensor that delivers stunning image quality for finely detailed and natural looking images.



DIGIC 6 SPEEDY IMAGE PROCESSING

In collaboration with the CMOS sensor, a super speed processor enables unsurpassed quality for stills and moving images.

ISO
12800

ISO12800 (EXPANDABLE TO 25600)

High ISO speed and range virtually eliminates noise and exacts enviable quality even in low light situations.

Up to
5.0
Frames
Per Sec

5 FRAMES PER SECOND CONTINUOUS SHOOTING

Never miss an important moment with this high-speed capture of moving objects.

COMPATIBLE EOS ACCESSORIES

A breathtaking range of options, including the MG-EF magnifier frame, battery pack (LP-E17), battery charger (LC-E17), power adapter kit, remote controllers, external speedlites and over 70 EF lenses to complement your performance output and versatility.



SHOOT BIG, SHOW BIG

When the camera and the Connect Station CS100 are touched together, images can be imported wirelessly to the device. Quality images shot can now be shared with immense pleasure on a large-screen TV!



SPECIFICATIONS FOR EOS 760D & 750D

Imaging Sensor	Approx. 24.2 MP APS-C CMOS sensor
Image Processor	DIGIC 6
Viewfinder	Approx. 95%, 0.82x magnification
AF points	19 (All cross-type, center Dual cross-type)
ISO Range	100-12800 (Expandable to 25600)
Metering	63-zone 7560-pixel RGB plus IR metering sensor
Anti-flicker	Available
Shutter Speed	1/4000 sec. to 30 sec.
Continuous Shooting Speed	Max. approx. 5.0 shots/sec.
AF in Live View	Hybrid CMOS AF III System
Servo AF in Live View	Only available for EOS 760D
Electronic Level	Only available for EOS 760D
Creative Filter	Grainy B/W, Soft focus, Fish-eye effect, Art bold effect, Water painting effect, Toy camera effect, Miniature effect
Movie Recording format	MP4
Movie Recording size and frame rate	Full HD (1920x1080) : 29.97p/25.00p/23.98p HD (1280x720) : 59.94p/50.00p/29.97p/25.00p VGA (640x480) : 29.97p/25.00p
HDR Movie	Only available for EOS 760D
Movie Digital Zoom	Only available for EOS 760D
Built-in Microphones	Stereo
LCD Monitor	Vari-angle 3.0 inch, 1.04 million dots TFT, Touch Panel
Electronic Level	In LCD monitor and view finder (Only available for EOS 760D)
Top LCD Panel	Only available for EOS 760D
Quick Control Dial	Only available for EOS 760D
Touch screen technology	Capacitive sensing
Built-in Flash	Retractable, auto pop-up flash
Wi-Fi & NFC	Built-in
Storage	SD/SDHC/SDXC Card
Dimensions and Weight	
EOS 760D	Dimensions (W x H x D): Approx. 131.9 x 100.9 x 77.8 mm Weight: Approx. 520 g (Body only)
EOS 750D	Dimensions (W x H x D): Approx. 131.9 x 100.7 x 77.8 mm Weight: Approx. 510 g (Body only)

Canon Imaging Asia | YouTube Canon Asia | www.canon-asia.com/snapshot

LOCALIZED MANUAL Available* *Insist on an original warranty by your local sales office.*
South and Southeast Asia Regional Headquarters: Canon Singapore Pte. Ltd.
1 Harbourfront Avenue #04-01 Keppel Bay Tower Singapore 098632

* Specifications are subject to change without notice. Images are simulated.
^ Localized manual available for Malaysia, Thailand, Vietnam and Indonesia only. www.canon-asia.com

EOS
DIGITAL

Canon
Delighting You Always



EOS 760D

EOS 750D



24.2
MEGA
PIXELS
CMOS

Cross-type
AF
19

Up to
5.0
Frames
Per Sec

HDR
Movie

Vari angle LCD

Wi-Fi / NFC

Wi-Fi / NFC

Made in
JAPAN

*Only available for EOS 760D. **Battery Grip sold separately.




PURSUE WHAT YOU LOVE, AND EXPRESS YOUR
CREATIVITY WITH CLARITY



KEEPING QUALITY IN CONSTANT FOCUS Cross-type AF
19 AF

Beyond typical DSLRs, the EOS 760D & EOS 750D have high-performance 19-point All Cross AF, equal to the EOS 70D. This ensures the subject is always in focus, even in unpredictable situations. And with a new color detection technology that detects skin tones to enhance focusing accuracy of people, fast continuous shooting is inevitable.

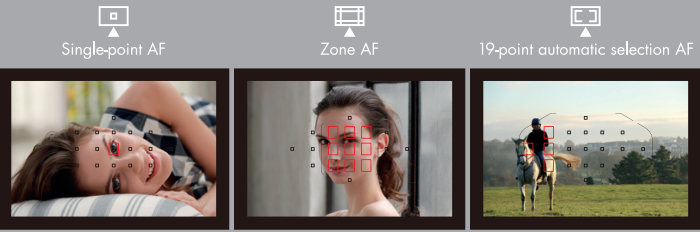

3 selection modes of focus to maximize focus performance

Exclusively for

EOS 760D For the Professional Look & Control

- Professional-looking body
- Top LCD Panel
- Quick Control Dial
- Intelligent Viewfinder
- NEW! Advance functions for Movie, HDR Movie & Movie Digital Zoom

Features that serious photographers and camera purists love:

Top LCD Panel to elevate it a notch higher

First of its kind in its class. Check shooting settings quickly, facilitate quality photography and enhance your own image

Quick Control Dial with Multi-Function lock switch

Part of the EOS identity, now introduced into an entry-level camera. Change settings or search for images effortlessly

FIRST FOR EOS

CRISP MOVIE QUALITY, MINIMAL OVEREXPOSURE **HDR Movie**

The HDR Movies feature helps reduce overexposure in bright scenes. For example, when shooting against a very bright sky, your images will otherwise appear very white.

IMAGE SHOT AT 60 FPS

STANDARD EXPOSURE UNDEREXPOSURE STANDARD EXPOSURE UNDEREXPOSURE

30 FPS

720 1280

HDR Movies feature intelligently combines an image of standard exposure with an underexposed image into a single frame to generate HDR movies with reduced overexposure.

HIGH IMAGE QUALITY



High megapixel resolution, a speedier processor and a new 7,560-pixel RGB + IR light-metering sensor make quality details and color rendition flawless and inevitable. Combine this with an intelligent EOS Scene analysis system and an impressive range of shooting scenarios is easily achieved.

OTHER INTERESTING FEATURES

- Creative Filters:** Experiment with 7 filter effects – like fisheye and monochrome – while shooting stills or movies to achieve unique images
- Special Scene Modes:** Choose from an array to befit the situation – including Kids, Food, Candlelight, Night Portrait, Handheld Night Scene, HDR Backlight control modes

NEW

FASTER AUTO FOCUSING Hybrid CMOS **AF III**

This innovative new Hybrid CMOS AF III was created to optimize focusing. In Live View, using face-detection AF via the LCD touchscreen, fast and accurate autofocussing for still images is easily achieved. Shift focus and subject tracking during video recording mode is also seamless.

MOVIE MAKING FUN

- Video Snapshot:** Short scene snippets can be strung together – in your preferred sequence – without the need for editing. Create original movies with ease
- Movie Digital Zoom:** Digitally zoom in to subjects (3-10x) during movie shooting. Available for the EOS 760D only
- MP4/Light IPB Recording:** Versatile movie compression formats for easy playback and sharing on smartphones, tablets & social media

Approx. 24.2 megapixels CMOS sensor

Hybrid CMOS **AF III**

Pixels dedicated to phase-difference AF

Responsive LiveView LCD screen

DIGIC 6

STM lens (recommended)