


## b. PolyPropylene Straps

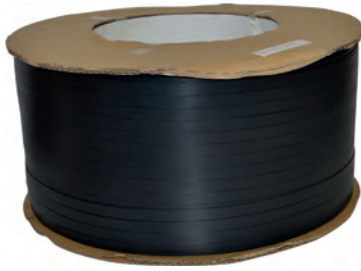

Compatible with most conventional strapping machines

Designed for automatic packing of ESD sensitive items.

### Technical Data

- Dimensions: 12 mm x 0.5 mm – roll of 1500 m
- Surface resistance:  $< 1 \times 10^9 \Omega$
- Stretch resistance: 1430 kg/mm<sup>2</sup>
- Breaking point: 125 %
- Electrostatic characteristics: Dissipative PolyPropylene

### Dimensions available

Dimensions mm	Reference
12 x 0.5	70-101-0001

## c. Dissipative straps



- Other dimensions available on request.

Static dissipative straps are especially designed to safe pack ESD sensitive items.

### Technical Data

- Surface resistance:  $R_{pp} < 1 \times 10^{11} \Omega$
- Material: Velcro coated nylon strap
- Colour: Black

### Dimensions available

Dimensions mm	Reference
25,4 x 915	70-101-0002
25,4 x 508	70-101-0003

## 3.2. Waste Bag



Pink antistatic PE waste bag.

### Dimensions available

Features	Dimensions mm W x H x Gussted	Thickness mm	Reference
50 x 15 litre bags	300 x 600 x (100 + 100)	25 +/-10%	41-095-0005
10 x 40 litre bags	450 x 750 x (180 + 180)	23 +/-10%	41-095-0007
10 x 120 litre bags	680 x 1180 x (150 + 150)	23 +/-10%	41-095-0010
10 x 180 litre bags	800 x 1300 x (200 + 200)	28 +/-10%	41-095-0013