

LABELS

MULTIPURPOSE



Multipurpose Labels from Avery Zweckform offer you the perfect label for every need and every application. Perfect suitability for inkjet-, laser- and colour-laser printers. The perfect solution for all kinds of requirements!



LABEL REMOVER


Art No	Description	Content
3590	For easy and residue-free removing of paper labels and adhesive residues on most materials	150 ml

RECYCLED MULTIPURPOSE LABELS for all A4 printers

- Off-white labels made from 100% recycled paper, certified with the eco-label „Blauer Engel“
- Chlorine-free label paper
- Water-based environmentally friendly adhesive
- Guaranteed jam-free printing – no adhesive residues in the printer
- Trouble-free printing for laser printers tested and certified by TÜV SÜD



	Art No	Format mm (B x H)	Description	Colour	Labels/ Pack	A4Sheet/ Pack	Printers I L K CL
1	LR3666	38 x 21,2	Numbering of objects	white	6500	100	• • • •
2	LR3475	70 x 36	For updates, e.g. on promotional material	white	2400	100	• • • •
3	LR3424	105 x 48	Labelling of plastic pockets	white	1200	100	• • • •
4	LR3483	105 x 148	For operating instructions, telephone list etc.	white	400	100	• • • •
5	LR3655	210 x 148	As content labels, e.g. moving boxes	white	200	100	• • • •
6	LR3478	210 x 297	For clean labelling of binders, folders	white	100	100	• • • •

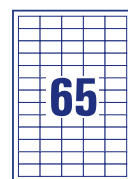

1 38 x 21,2
LR3666



2 70 x 36
LR3475



3 105 x 48
LR3424



4 105 x 148
LR3483



5 210 x 148
LR3655



6 210 x 297
LR3478

all measurements in mm



= Blauer Engel, 100% recycled paper



= Innovative QuickPEEL™ feature

WHITE MULTIPURPOSE LABELS, PERMANENT ADHESIVE

for all A4 printers

- Guaranteed jam-free printing - no adhesive residues in the printer
- Trouble-free printing for laser printers tested and certified by TÜV SÜD
- 100% compatible with all standard printers & copiers
- Pin-sharp image - top anchorage and no smudging
- Reliably strong adhesion on paper, cardboard, glass and plastic.
Perfectly suitable e.g. for letters, parcels, folders, binders or transparencies.



Art No	Format mm (B x H)	Description	Colour	Labels/ Pack	A4Sheet/ Pack	Printers I L K CL
permanent adhesive						
1	38 x 21,2	Numbering of products	white	1625	25	• • • •
1	38 x 21,2	Numbering of products	white	6500	100	• • • •
1	38 x 21,2	Numbering of products	white	650	10	• • • •
1	38 x 21,2	Numbering of products	white	13000	200	• • • •
2	48 x 21	For corrections and comments in documents	white	5200	100	• • • •
3	48,5 x 16,9	For corrections and comments in documents	white	6400	100	• • • •
3	48,5 x 16,9	For corrections and comments in documents	white	12800	200	• • • •
4	48,5 x 25,4	For corrections and comments in documents	white	400	10	• • • •
4	48,5 x 25,4	For corrections and comments in documents	white	1000	25	• • • •
4	48,5 x 25,4	For corrections and comments in documents	white	4000	100	• • • •
4	48,5 x 25,4	For corrections and comments in documents	white	8000	200	• • • •
5	52,5 x 21,2	For corrections and comments in documents	white	5600	100	• • • •
6	52,5 x 29,7	For property labelling	white	4000	100	• • • •
6	52,5 x 29,7	For property labelling	white	8000	200	• • • •
7	64 x 36	For property labelling	white	525	25	• • • •
7	64 x 36	For property labelling	white	2100	100	• • • •
8	64 x 45	For property labelling	white	450	25	• • • •
8	64 x 45	For property labelling	white	1800	100	• • • •
9	64 x 50	For property labelling	white	1500	100	• • • •
10	64,6 x 33,8	For property labelling	white	600	25	• • • •
10	64,6 x 33,8	For property labelling	white	2400	100	• • • •
10	64,6 x 33,8	For property labelling	white	240	10	• • • •
10	64,6 x 33,8	For property labelling	white	4800	200	• • • •
11	70 x 16,9	For labelling trays and drawers	white	5100	100	• • • •
12	70 x 25,4	For labelling trays and drawers	white	3300	100	• • • •
13	70 x 29,7	For labelling trays and drawers	white	3000	100	• • • •
14	70 x 32	For labelling trays and drawers	white	2700	100	• • • •
15	70 x 33,8	For labelling trays and drawers	white	2400	100	• • • •
16	70 x 35	For updates, e.g. on promotional material	white	2400	100	• • • •

all measurements in mm

1	38 x 21,2	6121	3666	3666-10	3666-200
2	48 x 21	3650			
3	48,5 x 16,9	3667	3667-200		
4	48,5 x 25,4	6126	4780	3657	3657-200
5	52,5 x 21,2	3668			
6	52,5 x 29,7	3651	3651-200		
7	64 x 36	6170	3670		
8	64 x 45	6171	3671		
9	64 x 50	3672			
10	64,6 x 33,8	6172	3658-10	3658	3658-200
11	70 x 16,9	3420			
12	70 x 25,4	3421			
13	70 x 29,7	3489			
14	70 x 32	3479			
15	70 x 33,8	3664			
16	70 x 35	3422			

Printer: I = Inkjet printer L = Laser printer K = Copier CL = Colour laser printer



= Paper from responsibly managed forests

Printing Tip FREE Templates & Software
avery-zweckform.eu/print

Haven't found your product number?
Please see our search directory page 122.

LABELS

MULTIPURPOSE



WHITE MULTIPURPOSE LABELS, PERMANENT ADHESIVE for all A4 printers

	Art No	Format mm (B x H)	Description	Colour	Labels/ Pack	A4 Sheet/ Pack	Printers I L K CL
permanent adhesive							
1	6122	70 x 36	For updates, e.g. on promotional material	white	240	10	• • • • •
1	3490	70 x 36	For updates, e.g. on promotional material	white	600	25	• • • • •
1	3475	70 x 36	For updates, e.g. on promotional material	white	2400	100	• • • • •
1	3475-200	70 x 36	For updates, e.g. on promotional material	white	4800	200	• • • • •
2	6173	70 x 37	For updates, e.g. on promotional material	white	600	25	• • • • •
2	3474	70 x 37	For updates, e.g. on promotional material	white	2400	100	• • • • •
2	3474-10	70 x 37	For updates, e.g. on promotional material	white	240	10	• • • • •
2	3474-200	70 x 37	For updates, e.g. on promotional material	white	4800	200	• • • • •
3	3481	70 x 41	For organising school/study documents	white	2100	100	• • • • •
4	6174	70 x 42,3	For organising school/study documents	white	525	25	• • • • •
4	3652	70 x 42,3	For organising school/study documents	white	2100	100	• • • • •
4	3652-10	70 x 42,3	For organising school/study documents	white	210	10	• • • • •
4	3652-200	70 x 42,3	For organising school/study documents	white	4200	200	• • • • •
5	3669	70 x 50,8	As book labels	white	1500	100	• • • • •
5	3669-200	70 x 50,8	As book labels	white	3000	200	• • • • •
6	3661	70 x 67,7	For identification, e.g. of copies	white	1200	100	• • • • •
7	3678	97 x 37	For labelling trays and drawers	white	1400	100	• • • • •
8	6123	97 x 42,3	As name label	white	120	10	• • • • •
8	4781	97 x 42,3	As name label	white	300	25	• • • • •
8	3659	97 x 42,3	As name label	white	1200	100	• • • • •
8	3659-200	97 x 42,3	As name label	white	2400	200	• • • • •
9	3679	97 x 55	For labelling trays and drawers	white	1000	100	• • • • •
10	4782	97 x 67,7	For labelling documents and files	white	200	25	• • • • •
10	3660	97 x 67,7	For labelling documents and files	white	800	100	• • • • •
10	3660-200	97 x 67,7	For labelling documents and files	white	1600	200	• • • • •
11	3665	105 x 33,8	Numbering of products	white	1600	100	• • • • •
12	3423	105 x 35	Numbering of products	white	1600	100	• • • • •

1 70 x 36
6122, 3490
3475
3475-200

2 70 x 37
6173
3474
3474-10
3474-200

3 70 x 41
3481

4 70 x 42,3
6174
3652
3652-10
3652-200

5 70 x 50,8
3669
3669-200

6 70 x 67,7
3661

7 97 x 37
3678

8 97 x 42,3
6123, 4781
3659
3659-200

9 97 x 55
3679

 
 
10 97 x 67,7
4782
3660
3660-200

11 105 x 33,8
3665

12 105 x 35
3423

all measurements in mm

Printing Tip FREE Templates & Software
avery-zweckform.eu/print





WHITE MULTIPURPOSE LABELS, PERMANENT ADHESIVE

for all A4 printers

Art No	Format mm (B x H)	Description	Colour	Labels/Pack	A4 Sheet/Pack	Printers I L K CL
permanent adhesive						
1	105 x 37	Numbering of products	white	1600	100	• • • •
1	105 x 37	Numbering of products	white	3200	200	• • • •
2	105 x 41	For content labelling, e.g. stock supplies	white	1400	100	• • • •
3	105 x 42,3	For content labelling, e.g. stock supplies	white	1400	100	• • • •
3	105 x 42,3	For content labelling, e.g. stock supplies	white	2800	200	• • • •
4	105 x 48	For labelling plastic pockets	white	300	25	• • • •
4	105 x 48	For labelling plastic pockets	white	1200	100	• • • •
4	105 x 48	For labelling plastic pockets	white	2400	200	• • • •
5	105 x 57	For labelling plastic pockets	white	1000	100	• • • •
6	105 x 70	For print approvals	white	800	100	• • • •
7	105 x 74	For print approvals	white	800	100	• • • •
7	105 x 74	For print approvals	white	1600	200	• • • •
8	105 x 148	As operating instructions, telephone list etc	white	40	10	• • • •
8	105 x 148	As operating instructions, telephone list etc	white	100	25	• • • •
8	105 x 148	As operating instructions, telephone list etc	white	400	100	• • • •
8	105 x 148	As operating instructions, telephone list etc	white	800	200	• • • •
9	200 x 297	As content labels, e.g. on folders	white	100	100	• • • •
10	210 x 148	As content labels, e.g. on moving boxes	white	50	25	• • • •
10	210 x 148	As content labels, e.g. on moving boxes	white	200	100	• • • •
10	210 x 148	As content labels, e.g. on moving boxes	white	20	10	• • • •
10	210 x 148	As content labels, e.g. on moving boxes	white	400	200	• • • •
11	210 x 297	For clean labelling of binders, folders	white	10	10	• • • •
11	210 x 297	For clean labelling of binders, folders	white	25	25	• • • •
11	210 x 297	For clean labelling of binders, folders	white	100	100	• • • •
11	210 x 297	For clean labelling of binders, folders	white	200	200	• • • •



all measurements in mm

1 105 x 37 3484 3484-200	2 105 x 41 3477	3 105 x 42,3 3653 3653-200	4 105 x 48 6175 3424 3424-200	5 105 x 57 3425	6 105 x 70 3426	7 105 x 74 3427 3427-200
8 105 x 148 6124, 6120 3483 3483-200	9 200 x 297 3418	10 210 x 148 6176 3655 3655-10 3655-200	11 210 x 297 6125, 6119 3478 3478-200			

Printer: I = Inkjet printer L = Laser printer K = Copier CL = Colour laser printer

LABELS

MULTIPURPOSE



MULTIPURPOSE LABELS ON A5 SHEETS

for all A4 printers

- Guaranteed jam-free printing - no adhesive residues in the printer
 - Trouble-free printing for laser printers tested and certified by TÜV SÜD
 - 100% compatible with all standard printers & copiers
 - Pin-sharp image - top anchorage and no smudging
 - Reliably strong adhesion on paper, cardboard, glass and plastic.
- Perfectly suitable e.g. for letters, parcels, folders, binders or transparencies..

	Art No	Format mm (B x H)	Description	Colour	Labels/Pack	A5 Sheet/Pack	Printers I L K CL
1	6131	70 x 36	For labelling documents	white	2400	200	• • • •
2	6132	97 x 42,3	For letters and envelopes	white	1200	200	• • • •
3	6133	105 x 74	For mailing parcels and packages	white	800	200	• • • •
4	6134	105 x 148	For mailing parcels and packages	white	400	200	• • • •
5	6135	210 x 148	For mailing parcels and packages	white	200	200	• • • •

ANNA'S TIP!



Labelling filing trays.

Label your filing documents in a clearly structured way. To achieve this we recommend removable labels. The positive effect: you can try different ways until you have found the perfect system working best for you. You can also easily change or adapt categories and classifications any time you want.

Removable labels will help you with that.



1 70 x 36
6131



2 97 x 42,3
6132



3 105 x 74
6133



4 105 x 148
6134



5 210 x 148
6135

all measurements in mm



= Paper from responsibly managed forests



= Innovative QuickPEEL™ feature

WHITE MULTIPURPOSE REMOVABLE LABELS

for all A4 printers

- Reliable adhesion to most standard surfaces. Easy to remove without leaving any residues
- Ideal for temporary labelling
- Guaranteed jam-free printing - no adhesive residues in the printer
- Trouble-free printing for laser printers tested and certified by TÜV SÜD



Art No	Format mm (B x H)	Description	Colour	Labels/ Pack	A4Sheet/ Pack	Printers I L K CL
removable						
1	L4730REV-25 17,8 x 10	Ideal for pricing	white	6750	25	• • • •
2	L4731REV-25 25,4 x 10	Ideal for pricing	white	4725	25	• • • •
3	L4732REV-10 35,6 x 16,9	Ideal for pricing and product labelling	white	800	10	• • • •
3	L4732REV-25 35,6 x 16,9	Ideal for pricing and product labelling	white	2000	25	• • • •
3	L4732REV-100 35,6 x 16,9	Ideal for pricing and product labelling	white	8000	100	• • • •
4	L4736REV-10 45,7 x 21,2	For labelling spices etc.	white	480	10	• • • •
4	L4736REV-25 45,7 x 21,2	For labelling spices etc.	white	1200	25	• • • •
4	L4736REV-100 45,7 x 21,2	For labelling spices etc.	white	4800	100	• • • •
5	L4737REV-10 63,5 x 29,6	Company labels for brochures etc.	white	270	10	• • • •
5	L4737REV-25 63,5 x 29,6	Company labels for brochures etc.	white	675	25	• • • •
5	L4737REV-100 63,5 x 29,6	Company labels for brochures etc.	white	2700	100	• • • •
6	L6023REV-25 63,5 x 38,1	Company labels for brochures etc.	white	525	25	• • • •
7	L6025REV-25 63,5 x 46,6	Product labels for small print runs	white	450	25	• • • •
8	L6031REV-25 96 x 16,9	For labelling shelves	white	800	25	• • • •
9	L4744REV-25 96 x 50,8	For labelling slide boxes	white	250	25	• • • •
10	L4745REV-25 96 x 63,5	For labelling slide boxes	white	200	25	• • • •
11	L4743REV-25 99,1 x 42,3	For labelling slide bottles	white	300	25	• • • •
11	L4743REV-100 99,1 x 42,3	For labelling slide bottles	white	1200	100	• • • •
12	L4733REV-25 99,1 x 139	Postcard format	white	100	25	• • • •
13	L4734REV-25 199,6 x 143,5	For labelling pallets	white	50	25	• • • •
13	L4734REV-100 199,6 x 143,5	For labelling pallets	white	200	100	• • • •
14	L4735REV-25 210 x 297	For customised cutting	white	25	25	• • • •
14	L4735REV-100 210 x 297	For customised cutting	white	100	100	• • • •

1 17,8 x 10 L4730REV-25	2 25,4 x 10 L4731REV-25	3 35,6 x 16,9 L4732REV-10 L4732REV-25 L4732REV-100	4 45,7 x 21,2 L4736REV-10 L4736REV-25 L4736REV-100	5 63,5 x 29,6 L4737REV-10 L4737REV-25 L4737REV-100	6 63,5 x 38,1 L6023REV-25	7 63,5 x 46,6 L6025REV-25
8 96 x 16,9 L6031REV-25	9 96 x 50,8 L4744REV-25	10 96 x 63,5 L4745REV-25	11 99,1 x 42,3 L4743REV-25 L4743REV-100	12 99,1 x 139 L4733REV-25	13 199,6 x 143,5 L4734REV-25 L4734REV-100	14 210 x 297 L4735REV-25 L4735REV-100


all measurements in mm

Printer: I = Inkjet printer L = Laser printer K = Copier CL = Colour laser printer

Printing Tip FREE Templates & Software
avery-zweckform.eu/print

LABELS

MULTIPURPOSE

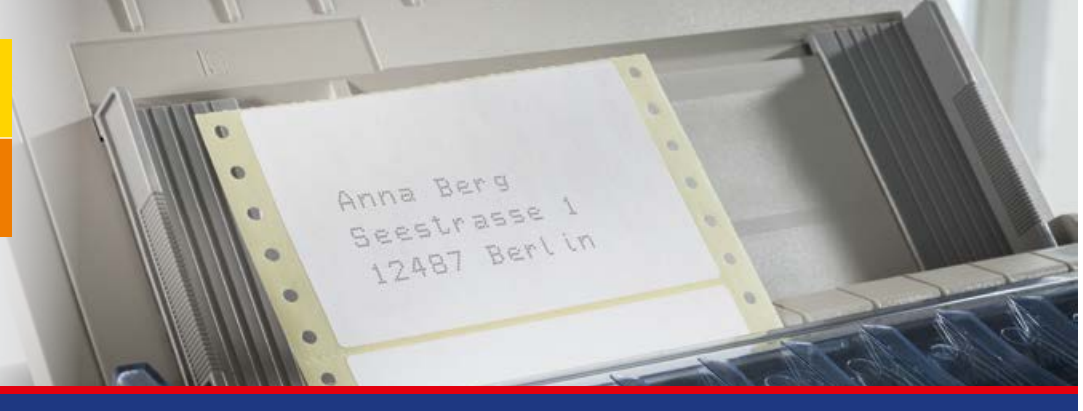

COMPUTER LABELS for matrix printers

- Guaranteed jam-free printing - no adhesive residues in the printer
- Continuous fan-folds for smooth feeding
- Chlorine-free bleaching with solvent-free adhesive



Art No	Format mm (B x H)	Strips	Description	Labels/ Pack
permanent adhesive				
1 3604	25,4 x 14,5	■■■	For labelling goods and products	1800
2 3605	40,6 x 14,5	■■		1200
3 3606	48,0 x 18,7	■		900
4 3610	88,9 x 23	■		2000
4 5101	88,9 x 23	■		6000
5 3611	88,9 x 35,7	■		1000
5 3635	88,9 x 35,7	■		2000
5 3615	88,9 x 35,7	■		4000
6 5103	88,9 x 48,4	■		3000

1 25,4 x 14,5 mm
■■■ 3604


4 88,9 x 23 mm
■ 3610/5101

2 40,6 x 14,5 mm
■■ 3605

5 88,9 x 35,7 mm
■ 3611/3635/3615


3 48,0 x 18,7 mm
■ 3606

6 88,9 x 48,4 mm
■ 5103

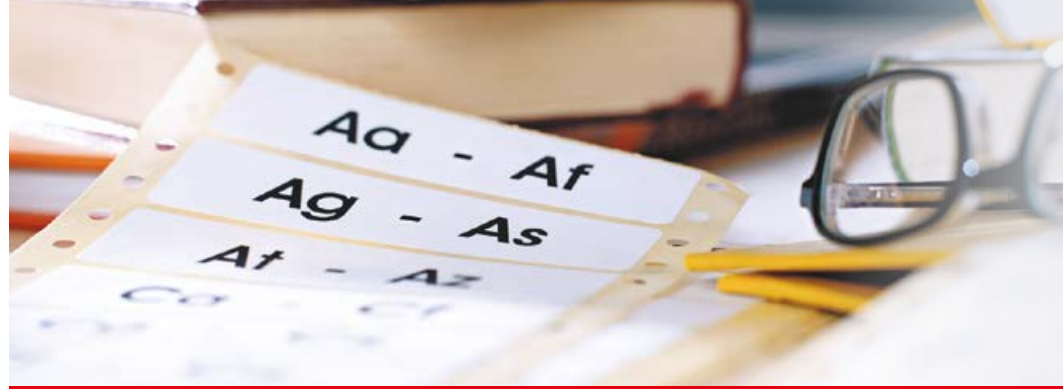

COMPUTER LABELS for matrix printers

Art No	Format mm (B x H)	Strips	Description	Labels/ Pack
permanent adhesive				
1 5106	101,6 x 35,7	■		4000
2 3617	101,6 x 48,4	■		2000
3 5120	101,6 x 73,8	■	Perforation after each label	2000
4 5114	139,7 x 99,2	■	Perforation after each label	1500

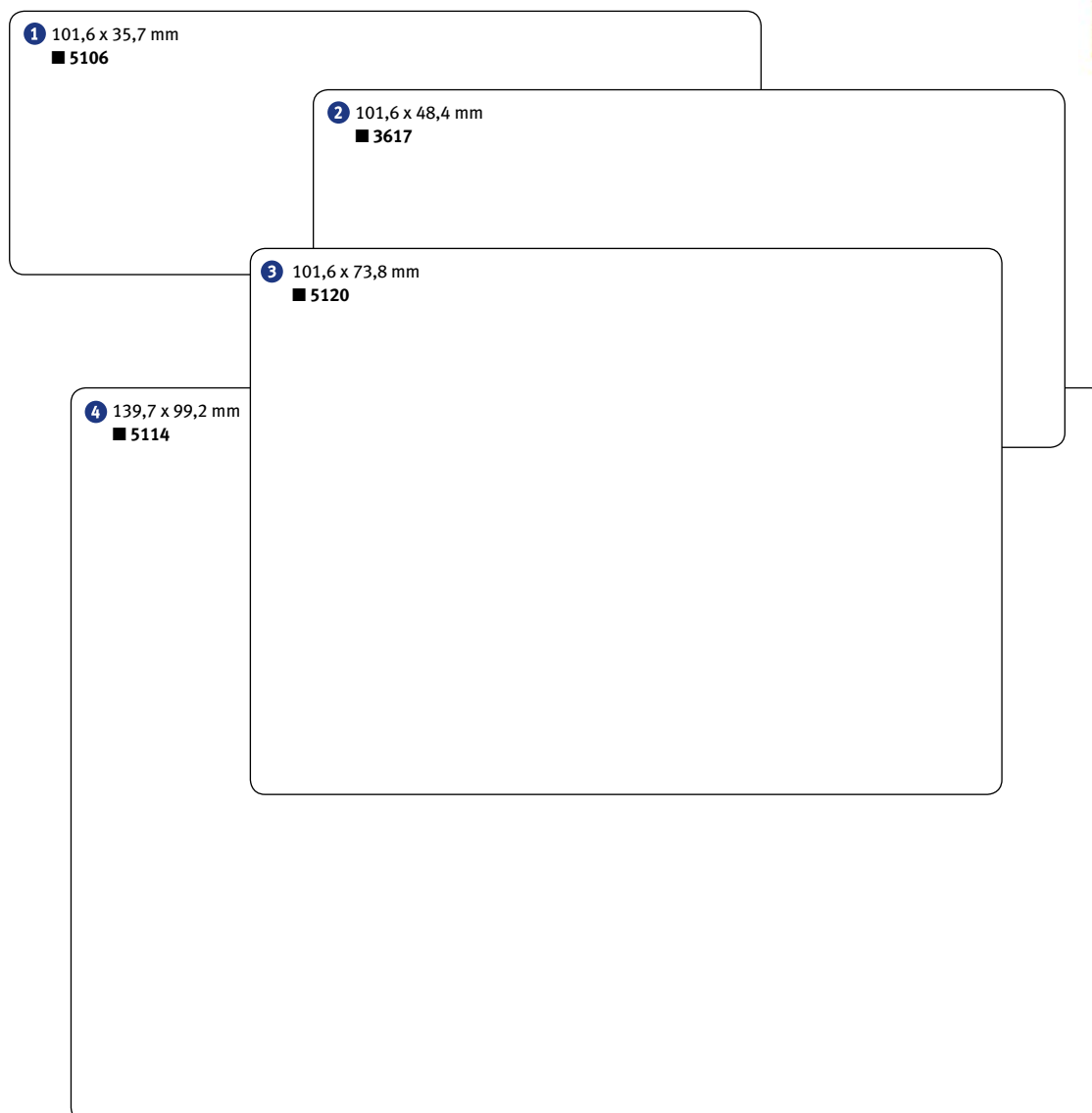


LABELS

MULTIPURPOSE



WHITE MULTIPURPOSE LABELS, PERMANENT ADHESIVE for handwriting

- Ideal for a quick and easy use
- No printer, simply label with a pen
- Chlorine-free bleaching
- Formats available in small packs (30xx-numbers) and flat packs (33xx-numbers)

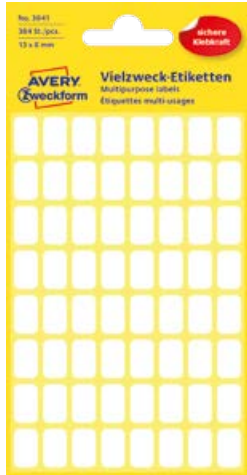

Small Pack



Flat Pack



	Small Pack		Flat Pack		Format	Colour
	Art No	Labels/Pack	Art No	Labels/Pack	mm (B x H)	
permanent adhesive						
1	3041	384	3306	3712	13 x 8	○ white
2	3072	294	3311	2646	16 x 9	○ white
3	3042	216	3312	1800	18 x 12	○ white
4	3073	234	3317	2184	20 x 8	○ white
5	3043	120	3318	1200	22 x 18	○ white
6	3074	96	3319	960	29 x 18	○ white
7	3044	132	3320	1144	32 x 10	○ white
8	3075	60	3321	560	32 x 23	○ white
9			3322	1976	37 x 5	○ white
10	3076	90	3323	928	38 x 14	○ white
11	3077	72	3324	648	38 x 18	○ white
12	3045	63	3325	522	38 x 24	○ white
13	3078	40	3326	384	38 x 29	○ white
14	3086	64	3336	672	50 x 14	○ white
15	3079	48	3327	486	50 x 19	○ white
16	3087	24	3337	224	54 x 35	○ white
17			3340	392	62 x 19	○ white
18	3084	18	3334	174	66 x 38	○ white
19	3080	36	3328	324	76 x 19	○ white
20	3081	18	3329	192	76 x 39	○ white
21			3362	224	77 x 31	○ white
22	3046	8			77 x 59	○ white
23			3330	112	80 x 54	○ white
24	3047	6	3331	84	98 x 51	○ white
25			3338	252	105 x 13	○ white

WHITE MULTIPURPOSE LABELS, REMOVABLE for handwriting

- Ideal for labelling and marking
- Reliable adhesion and removable without leaving any residues

	Art No	Format	Colour	Flat Pack
		mm (B x H)		Labels/Pack
removable				
NEW 1	3395	13 x 8	○ white	3712
NEW 3	3396	18 x 12	○ white	1800
NEW 7	3397	32 x 10	○ white	1144
NEW 10	3398	38 x 14	○ white	928
NEW 12	3399	38 x 24	○ white	522

Packing Unit (PU):
PU Small Pack = 10
PU Flat Pack = 1



1 13 x 8 mm 3041/3306/3395




2 16 x 9 mm 3072/3311




3 18 x 12 mm 3042/3312/3396




4 20 x 8 mm 3073/3317

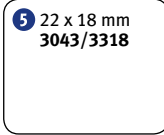


5 22 x 18 mm 3043/3318

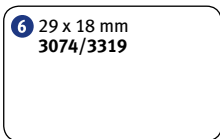


6 29 x 18 mm 3074/3319

 


7 32 x 10 mm 3044/3320/3397

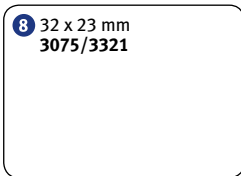


8 32 x 23 mm 3075/3321

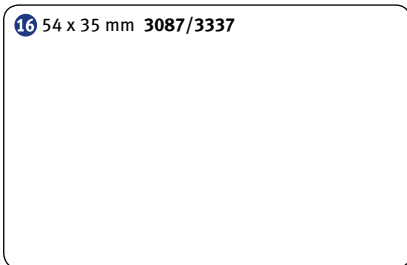


16 54 x 35 mm 3087/3337

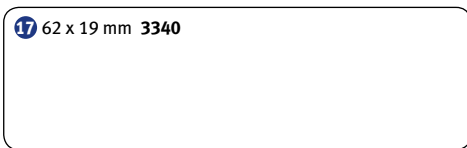


17 62 x 19 mm 3340

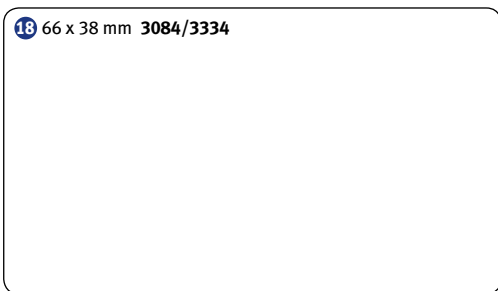


18 66 x 38 mm 3084/3334

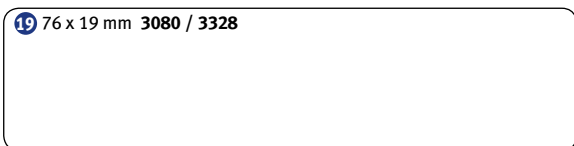


19 76 x 19 mm 3080 / 3328

 


9 37 x 5 mm 3322

 


10 38 x 14 mm 3076/3323/3398

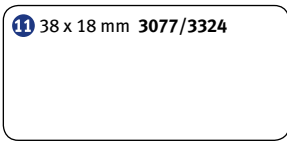


11 38 x 18 mm 3077/3324

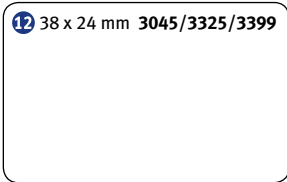


12 38 x 24 mm 3045/3325/3399

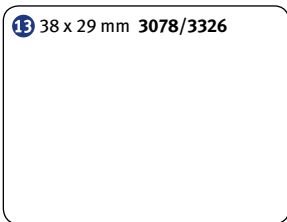


13 38 x 29 mm 3078/3326

 


14 50 x 14 mm 3086/3336

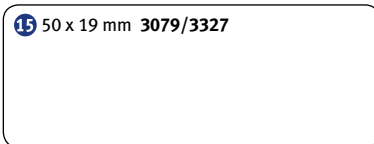


15 50 x 19 mm 3079/3327

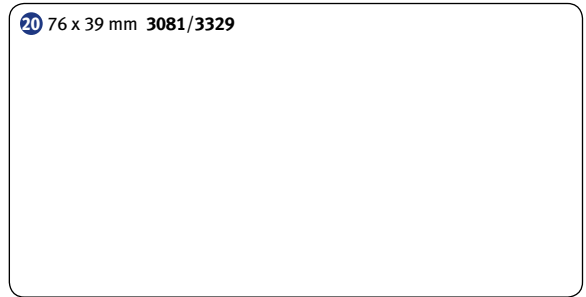


20 76 x 39 mm 3081/3329

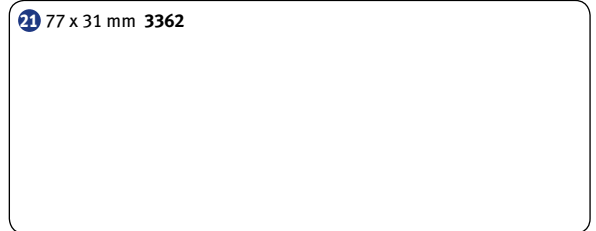


21 77 x 31 mm 3362

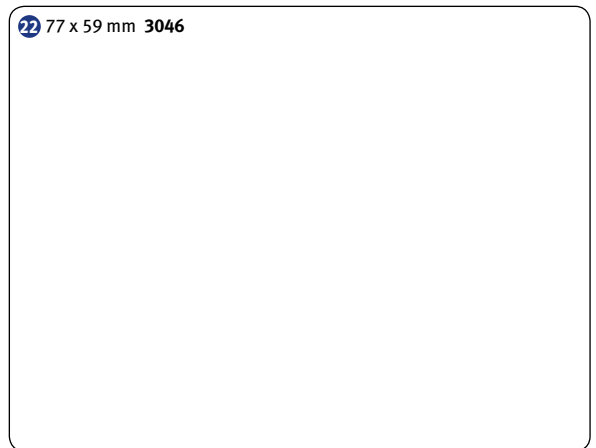

22 77 x 59 mm 3046

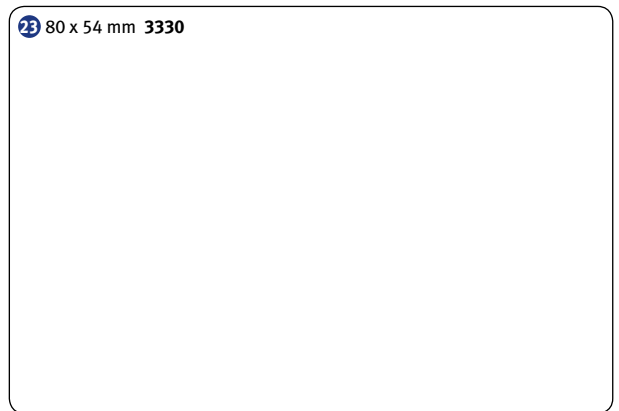

23 80 x 54 mm 3330

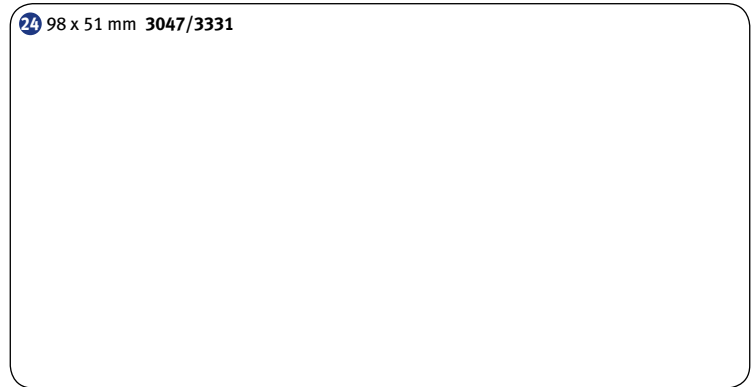

24 98 x 51 mm 3047/3331



25 105 x 13 mm 3338