


MGate Series



Industrial Protocol Gateways

Find an MGate Solution

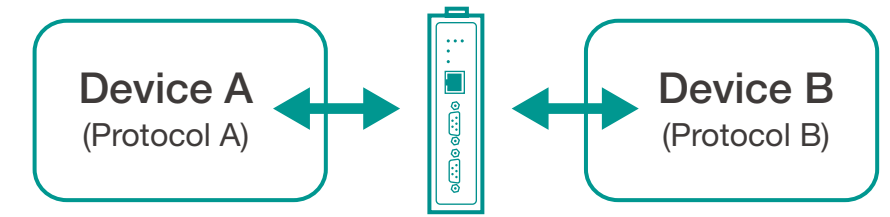

Device A / Device B	Modbus RTU/ASCII Sever	Modbus RTU/ASCII Client	PROFIBUS Slave	PROFIBUS Master	CANopen/J1939	DNP3 Serial Outstation	DNP3 Serial Master	DF1	IEC 60870-5-101 Slave	IEC 60870-5-101 Master	Modbus TCP Server	Modbus TCP Client	EtherNet/IP Adapter	EtherNet/IP Scanner	PROFINET Controller	DNP3 TCP Outstation	DNP3 TCP Client	IEC 60870-5-104 Server	IEC 60870-5-104 Client	MQTT Broker	BACnet/IP Client	IEC 61850 MMS Client	Azure/AWS
Modbus RTU/ASCII Sever	-	1) MB3000	-	4101, 5111	5118	-	-	-	-	-	5105	MB3000, 5109, 5105	5105	5105, 5135/5435	5103, 5134	-	5109	-	5114	5105	5217	5119	AIG-101
Modbus RTU/ASCII Sever	1) MB3000	-	-	4101, 5111	5118	-	-	-	-	-	MB3000, 5109, 5105	5105, 5109	5105	5105	5103	5109	5109	5114	-	-	-	-	-
PROFIBUS Slave	-	-	-	-	-	-	-	-	-	-	5101	5101	-	-	5102	-	-	-	-	-	-	-	-
PROFIBUS Master	4101, 5111	4101, 5111	-	-	-	-	-	-	-	-	5111	5111	-	5111	5111	-	-	-	-	-	-	-	-
CANopen/J1939	5118	5118	-	-	-	-	-	-	-	-	5118	5121, 5118	5118	5122, 5118	5123, 5118	-	-	-	-	-	-	-	-
DNP3 Serial Outstation	-	-	-	-	-	-	-	-	-	-	-	5109	-	-	-	-	5109	-	-	-	-	-	5119
DNP3 Serial Master	-	-	-	-	-	-	-	-	-	-	5109	5109	-	-	-	5109	-	-	-	-	-	-	-
DF1	-	-	-	-	-	-	-	-	-	-	-	-	EIP3000	EIP3000	-	-	-	-	-	-	-	-	-
IEC 60870-5-101 Slave	-	-	-	-	-	-	-	-	-	-	-	5114	-	-	-	-	-	-	5114	-	-	-	5119
IEC 60870-5-101 Master	-	-	-	-	-	-	-	-	-	-	5114	-	-	-	-	-	-	5114	-	-	-	-	-
Modbus TCP Server	5105	MB3000, 5109, 5105	5101	5111	5118	-	5109	-	-	5114	-	-	5105	5105, 5135/5435	5103, 5134	-	5109	-	5114	5105	5217	5119	AIG-101
Modbus TCP Client	MB3000, 5109, 5105	5105, 5109	5101	5111	5121, 5118	5109	5109	-	5114	-	-	5109	5105	5105	5103	5109	5109	5114	-	-	-	-	-
EtherNet/IP Adapter	5105	5105	-	-	5118	-	-	EIP3000	-	-	5105	5105	-	-	-	-	-	-	-	-	5105	-	-
EtherNet/IP Scanner	5105, 5135/5435	5105	-	5111	5122, 5118	-	-	EIP3000	-	-	5105, 5135/5435	5105	-	-	5103	-	-	-	-	-	-	-	-
PROFINET Controller	5103, 5134	5103	5102	5111	5123, 5118	-	-	-	-	-	5103, 5134	5103	-	5103	-	-	-	-	-	-	-	-	-
DNP3 TCP Outstation	-	5109	-	-	-	-	5109	-	-	-	-	5109	-	-	-	-	-	-	-	-	-	-	5119
DNP3 TCP Client	5109	5109	-	-	-	5109	-	-	-	-	5109	5109	-	-	-	-	-	-	-	-	-	-	-
IEC 60870-5-104 Server	-	5114	-	-	-	-	-	-	-	5114	-	5114	-	-	-	-	-	-	-	-	-	-	5119
IEC 60870-5-104 Client	5114	-	-	-	-	-	-	-	5114	-	5114	-	-	-	-	-	-	-	-	-	-	-	-
MQTT Broker	5105	-	-	-	-	-	-	-	-	-	5105	-	5105	-	-	-	-	-	-	-	-	-	-
BACnet/IP Client	5217	-	-	-	-	-	-	-	-	-	5217	-	-	-	-	-	-	-	-	-	-	-	-
IEC 61850 MMS Client	5119	-	-	-	-	5119	-	-	5119	-	5119	-	-	-	-	5119	-	5119	-	-	-	-	-
Azure/AWS	AIG-101	-	-	-	-	-	-	-	-	-	AIG-101	-	-	-	-	-	-	-	-	-	-	-	-

1) Applies only to the MB3270/3660.



MGate MB3000 MGate MB3660 MGate 5101-PBM-MN MGate 5102-PBM-PN MGate 5103/5105/5109/5114 MGate 5111 MGate 5217 MGate 5118 MGate 5119 MGate 5134 MGate 5135/5435 MGate 5121/5122/5123 AIG-101