


Connect your networks in confidence with RND. This new range offers improved performance and faster speeds, less interference and greater bandwidths. Perfect for the office, home office and server rooms that need reliable and constant internet connection, day after day. Great quality and low prices combined.

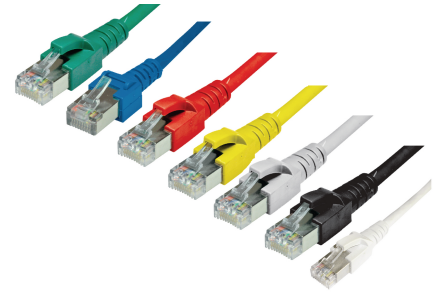

CAT 5e S/FTP Patch Cables

Features

- Prepared cable with screened RJ45 plug on both ends
- Connection cable for a structured building cabling
- Contact settings 1:1 in accordance with EIA/TIA568
- Complete screening aluminium laminated foil with additional braided shield



Technical Specification

Art. No.	Type	Cable Type	Jacket Colour	Length	Shielding	Version
30229375	RND 765-00168	CAT5e	Grey	1 m	SF/UTP	1:1
30229376	RND 765-00169	CAT5e	Grey	2 m	SF/UTP	1:1
30229377	RND 765-00170	CAT5e	Grey	3 m	SF/UTP	1:1
30229378	RND 765-00171	CAT5e	Grey	5 m	SF/UTP	1:1
30229379	RND 765-00172	CAT5e	Grey	7 m	SF/UTP	1:1
30229380	RND 765-00173	CAT5e	Grey	10 m	SF/UTP	1:1
30229381	RND 765-00174	CAT5e	Grey	15 m	SF/UTP	1:1
30229422	RND 765-00175	CAT5e	Grey	20 m	SF/UTP	1:1



CAT 5e UTP Patch Cables

Features

- Prepared cable with screened RJ45 plug on both ends
- Connection cable for a structured building cabling
- Contact settings 1:1 in accordance with EIA/TIA568
- Construction: internal line 8 wires




Technical Specification

Art. No.	Type	Cable Type	Jacket Colour	Length	Shielding	Version
30229423	RND 765-00176	CAT5e	Grey	500 mm	UTP	1:1
30229424	RND 765-00177	CAT5e	Grey	1 m	UTP	1:1
30229425	RND 765-00178	CAT5e	Grey	2 m	UTP	1:1
30229426	RND 765-00179	CAT5e	Grey	3 m	UTP	1:1
30229427	RND 765-00180	CAT5e	Grey	5 m	UTP	1:1

Features

- Patch cable for networking connections between device
- Prepared unshielded Twisted Pair cable with RJ-45 connectors on both ends
- Durable due to moulded kink protection
- Flexible cable, suitable for narrow bending

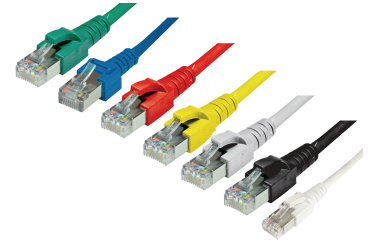

Technical Specification


Art. No.	Type	Cable Type	Jacket Colour	Length	Shielding	Version
30229428	RND 765-00181	CAT 6	Black	500 mm	S/FTP	1:1
30229429	RND 765-00182	CAT 6	Black	1 m	S/FTP	1:1
30229430	RND 765-00183	CAT 6	Black	1.5 m	S/FTP	1:1
30229431	RND 765-00184	CAT 6	Black	2 m	S/FTP	1:1
30229432	RND 765-00185	CAT 6	Black	3 m	S/FTP	1:1
30229433	RND 765-00186	CAT 6	Black	5 m	S/FTP	1:1
30229434	RND 765-00187	CAT 6	Black	7 m	S/FTP	1:1
30229435	RND 765-00188	CAT 6	Black	10 m	S/FTP	1:1
30229436	RND 765-00189	CAT 6	Blue	500 mm	S/FTP	1:1
30229437	RND 765-00190	CAT 6	Blue	1 m	S/FTP	1:1
30229438	RND 765-00191	CAT 6	Blue	1.5 m	S/FTP	1:1
30229439	RND 765-00192	CAT 6	Blue	2 m	S/FTP	1:1
30229440	RND 765-00193	CAT 6	Blue	3 m	S/FTP	1:1
30229441	RND 765-00194	CAT 6	Blue	5 m	S/FTP	1:1
30229442	RND 765-00195	CAT 6	Blue	7 m	S/FTP	1:1
30229443	RND 765-00196	CAT 6	Blue	10 m	S/FTP	1:1
30229444	RND 765-00197	CAT 6	Green	500 mm	S/FTP	1:1
30229445	RND 765-00198	CAT 6	Green	1 m	S/FTP	1:1
30229446	RND 765-00199	CAT 6	Green	1.5 m	S/FTP	1:1
30229447	RND 765-00200	CAT 6	Green	2 m	S/FTP	1:1
30229448	RND 765-00201	CAT 6	Green	3 m	S/FTP	1:1
30229449	RND 765-00202	CAT 6	Green	5 m	S/FTP	1:1
30229450	RND 765-00203	CAT 6	Green	7 m	S/FTP	1:1
30229451	RND 765-00204	CAT 6	Green	10 m	S/FTP	1:1
30229452	RND 765-00205	CAT 6	Grey	500 mm	S/FTP	1:1
30229453	RND 765-00206	CAT 6	Grey	1 m	S/FTP	1:1
30229454	RND 765-00207	CAT 6	Grey	1.5 m	S/FTP	1:1
30229455	RND 765-00208	CAT 6	Grey	2 m	S/FTP	1:1
30229456	RND 765-00209	CAT 6	Grey	3 m	S/FTP	1:1
30229457	RND 765-00210	CAT 6	Grey	5 m	S/FTP	1:1
30229458	RND 765-00211	CAT 6	Grey	7 m	S/FTP	1:1
30229459	RND 765-00212	CAT 6	Grey	10 m	S/FTP	1:1

Technical Specification

Art. No.	Type	Cable Type	Jacket Colour	Length	Shielding	Version
30229460	RND 765-00213	CAT 6	Red	500 mm	S/FTP	1:1
30229461	RND 765-00214	CAT 6	Red	1 m	S/FTP	1:1
30229462	RND 765-00215	CAT 6	Red	1.5 m	S/FTP	1:1
30229463	RND 765-00216	CAT 6	Red	2 m	S/FTP	1:1
30229464	RND 765-00217	CAT 6	Red	3 m	S/FTP	1:1
30229465	RND 765-00218	CAT 6	Red	5 m	S/FTP	1:1
30229466	RND 765-00219	CAT 6	Red	7 m	S/FTP	1:1
30229467	RND 765-00220	CAT 6	Red	10 m	S/FTP	1:1
30229468	RND 765-00221	CAT 6	White	500 mm	S/FTP	1:1
30229469	RND 765-00222	CAT 6	White	1 m	S/FTP	1:1
30229470	RND 765-00223	CAT 6	White	1.5 m	S/FTP	1:1
30229471	RND 765-00224	CAT 6	White	2 m	S/FTP	1:1
30229472	RND 765-00225	CAT 6	White	3 m	S/FTP	1:1
30229473	RND 765-00226	CAT 6	White	5 m	S/FTP	1:1
30229474	RND 765-00227	CAT 6	White	7 m	S/FTP	1:1
30229475	RND 765-00228	CAT 6	White	10 m	S/FTP	1:1
30229476	RND 765-00229	CAT 6	Yellow	500 mm	S/FTP	1:1
30229477	RND 765-00230	CAT 6	Yellow	1 m	S/FTP	1:1
30229478	RND 765-00231	CAT 6	Yellow	1.5 m	S/FTP	1:1
30229479	RND 765-00232	CAT 6	Yellow	2 m	S/FTP	1:1
30229480	RND 765-00233	CAT 6	Yellow	3 m	S/FTP	1:1
30229481	RND 765-00234	CAT 6	Yellow	5 m	S/FTP	1:1
30229482	RND 765-00235	CAT 6	Yellow	7 m	S/FTP	1:1
30229483	RND 765-00236	CAT 6	Yellow	10 m	S/FTP	1:1

Features

- Patch cable for networking connections between device
- Prepared unshielded Twisted Pair cable with RJ-45 connectors on both ends
- Durable due to moulded kink protection
- Flexible cable, suitable for narrow bending

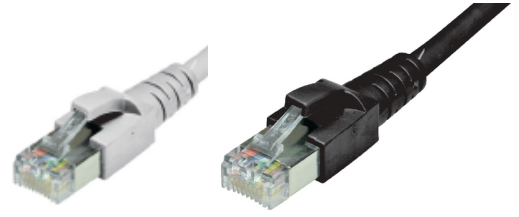

Technical Specification

Art. No.	Type	Cable Type	Jacket Colour	Length	Shielding	Version
30229484	RND 765-00237	CAT 6	Black	500 mm	UTP	1:1
30229485	RND 765-00238	CAT 6	Black	1 m	UTP	1:1
30229486	RND 765-00239	CAT 6	Black	1.5 m	UTP	1:1
30229487	RND 765-00240	CAT 6	Black	2 m	UTP	1:1
30229488	RND 765-00241	CAT 6	Black	3 m	UTP	1:1
30229489	RND 765-00242	CAT 6	Black	5 m	UTP	1:1
30229490	RND 765-00243	CAT 6	Black	7 m	UTP	1:1
30229491	RND 765-00244	CAT 6	Grey	10 m	UTP	1:1
30229492	RND 765-00245	CAT 6	Grey	500 mm	UTP	1:1
30229493	RND 765-00246	CAT 6	Grey	1 m	UTP	1:1
30229494	RND 765-00247	CAT 6	Grey	1.5 m	UTP	1:1
30229495	RND 765-00248	CAT 6	Grey	2 m	UTP	1:1
30229496	RND 765-00249	CAT 6	Grey	3 m	UTP	1:1
30229497	RND 765-00250	CAT 6	Grey	5 m	UTP	1:1