


Konfektionierte Kabel

Ready Made Cables

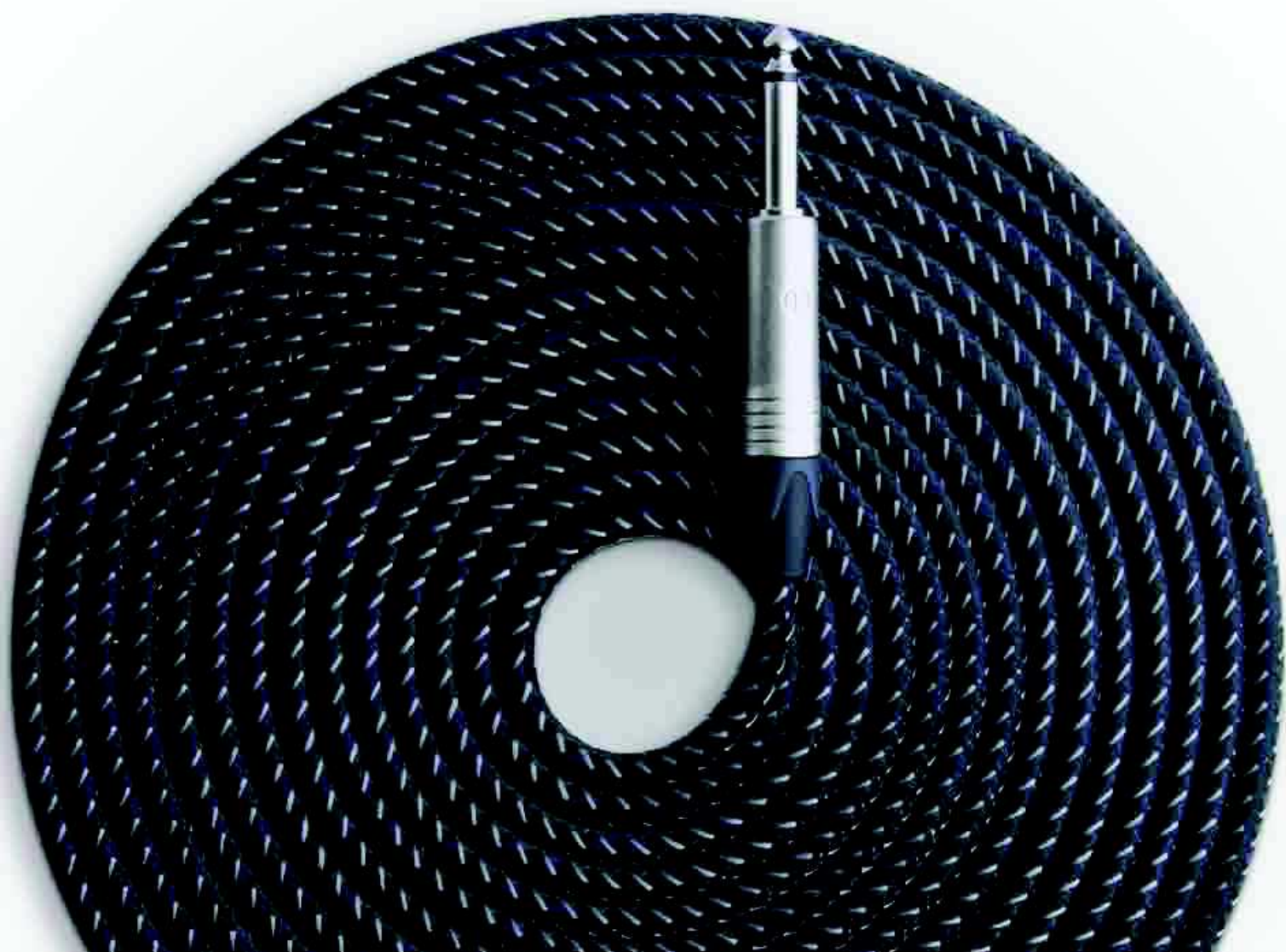

Auch der Stecker entscheidet Also the plug is essential!

Unser Angebot an konfektionierten Kabeln ist in Form, Funktion, Flexibilität und Preisgestaltung so vielfältig, dass jeder hier die für ihn perfekte Lösung finden kann. Wobei die Experten natürlich wissen: Auch das beste Kabel kann nur so gut sein, wie der Stecker, der an ihm hängt. Deswegen vertrauen wir bei CORDIAL auf die Top-Qualitätsstecker unserer Partner NEUTRIK® und REAN®. Denn sie sind auf unsere Kabel abgestimmt und gewährleisten somit schönste Klangerlebnisse bei optimaler Zugentlastung.

We can offer you such a great variety of ready-made cables regarding form, function, flexibility and price that everybody will find the suitable product meeting his expectations. Experts, though, know that a cable is only as good as its plug and that is why we at CORDIAL rely on top-quality cables made by our partners NEUTRIK® and REAN®. Customized to our standards their products assure a prime sound combined with optimal cable relief.



NEUTRIK AG
Die renommierten Stecker-Hersteller
aus Liechtenstein sind führend in der
Musikbranche und Kooperationspartner
der CORDIAL GmbH.

NEUTRIK AG
The renowned, Liechtenstein-based
manufacturer of connectors is a
leading player in the music business
and CORDIAL's co-op partner.



REAN
ist eine Marke der NEUTRIK AG und
stellt besondere Steckerverbindungen
für CORDIAL her.

REAN
is a NEUTRIK AG brand and manufactures
special connectors for CORDIAL.

CCM FM

intro



Stage/Home

Produktinformation Specification		
Kabel Cable	CMN 220	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	REAN	
Stecker Plug	XLR-female XLR-male	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.50	●	CCM 0.5 FM
1.00	●	CCM 1 FM
1.50	●	CCM 1.5 FM
2.50	●	CCM 2.5 FM
5.00	●	CCM 5 FM
7.50	●	CCM 7.5 FM
10.00	●	CCM 10 FM
20.00	●	CCM 20 FM

CCM FP

intro



Stage/Home
Sample Application:
Unbalanced Cabeling in Racks

Produktinformation Specification		
Kabel Cable	CMN 220	
Belegung Cable Assign	FP	
Steckermarke Plug Brand	REAN	
Stecker Plug	XLR-female Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
5.00	●	CCM 5 FP
7.50	●	CCM 7.5 FP
10.00	●	CCM 10 FP

CCM MP

intro



Stage/Home
Sample Application:
Unbalanced Cabeling in Racks

Produktinformation Specification		
Kabel Cable	CMN 220	
Belegung Cable Assign	MP	
Steckermarke Plug Brand	REAN	
Stecker Plug	XLR-male Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
5.00	●	CCM 5 MP
7.50	●	CCM 7.5 MP
10.00	●	CCM 10 MP

CFM FM

intro



Stage/DJ

Produktinformation Specification		
Kabel Cable	CME 220	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	XLR-female XLR-male	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.50	●	CFM 0.5 FM
1.00	●	CFM 1 FM
1.50	●	CFM 1.5 FM
2.50	●	CFM 2.5 FM
5.00	●	CFM 5 FM
7.50	●	CFM 7.5 FM
10.00	●	CFM 10 FM
20.00	●	CFM 20 FM

CIM FM

intro



Stage/DJ

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	XLR-female XLR-male	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.50	●	CIM 0.5 FM
1.00	●	CIM 1 FM
1.50	●	CIM 1.5 FM
2.50	●	CIM 2.5 FM
5.00	●	CIM 5 FM
7.50	●	CIM 7.5 FM
10.00	●	CIM 10 FM
20.00	●	CIM 20 FM

CIM FP

intro



Stage/DJ
Sample Application:
DJ Mic to Mixer

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	FP	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	XLR-female Plug 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
5.00	●	CIM 5 FP
7.50	●	CIM 7.5 FP
10.00	●	CIM 10 FP

CIM MP

intro



Stage/DJ
Sample Application:
Booth Monitor Out to Amp

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	MP	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	XLR-male Plug 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
5.00	●	CIM 5 MP
7.50	●	CIM 7.5 MP
10.00	●	CIM 10 MP

CXM FM

peak



Stage/Studio

Produktinformation Specification		
Kabel Cable	CME 220	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR-female XLR-male	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
5.00	●	CXM 5 FM
10.00	●	CXM 10 FM

CPM FM

peak



Stage/Studio

Produktinformation Specification		
Kabel Cable	CMK 222	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR-female XLR-male	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.00	●	CPM 1 FM
1.50	●	CPM 1.5 FM
2.50	●	CPM 2.5 FM
3.00	●	CPM 3 FM
5.00	● ● ●	CPM 5 FM
6.00	●	CPM 6 FM
7.50	●	CPM 7.5 FM
10.00	● ● ●	CPM 10 FM
15.00	●	CPM 15 FM
20.00	●	CPM 20 FM

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CPM FM-FLEX

peak



Stage/Studio
Best Handling

Produktinformation Specification		
Kabel Cable	CMFLEX 222	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR-female XLR-male	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.00	●	CPM 1 FM-FLEX
1.50	●	CPM 1.5 FM-FLEX
2.50	●	CPM 2.5 FM-FLEX
3.00	●	CPM 3 FM-FLEX
5.00	●	CPM 5 FM-FLEX
6.00	●	CPM 6 FM-FLEX
7.50	●	CPM 7.5 FM-FLEX
10.00	●	CPM 10 FM-FLEX
15.00	●	CPM 15 FM-FLEX
20.00	●	CPM 20 FM-FLEX

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CPM FP

peak



Stage/Studio
Sample Application:
Mics to Unbalanced Inputs

Produktinformation Specification			
Kabel Cable	CMK 222		
Belegung Cable Assign	FP		
Steckermarke Plug Brand	NEUTRIK		
Stecker Plug	XLR-female Plug 6.3 mm mono		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
2.50	●	CPM 2.5 FP	
5.00	●	CPM 5 FP	
7.50	●	CPM 7.5 FP	
10.00	●	CPM 10 FP	

CPM MP

peak



Stage/Studio
Sample Application:
Unbalanced Aux to EQ

Produktinformation Specification			
Kabel Cable	CMK 222		
Belegung Cable Assign	MP		
Steckermarke Plug Brand	NEUTRIK		
Stecker Plug	XLR-male Plug 6.3 mm mono		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
2.50	●	CPM 2.5 MP	
5.00	●	CPM 5 MP	
10.00	●	CPM 10 MP	

CPM CONV-FM

peak



Stage
Sample Application:
Gender Changer + Y-Split

Produktinformation Specification			
Kabel Cable	CPK 220		
Belegung Cable Assign	CONV_FM		
Steckermarke Plug Brand	NEUTRIK		
Stecker Plug	XLR-female/male (convertCON) XLR-male and XLR-female		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
0.15	●	CPM 0.15 CONV-FM	

CPM CONV-FMV

peak



Stage
Cover plug if not in use

Produktinformation Specification			
Kabel Cable	CMK 209		
Belegung Cable Assign	CONV_FMV		
Steckermarke Plug Brand	NEUTRIK		
Stecker Plug	XLR-female/male (convertCON) XLR-male, XLR-female, Plug 6.3 mm stereo		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
0.15	●	CPM 0.15 CONV-FMV	

CPP FF

peak



Stage/Studio
Sample Application:
Gender Changer

Produktinformation Specification			
Kabel Cable	CPK 220		
Belegung Cable Assign	FF		
Steckermarke Plug Brand	NEUTRIK		
Stecker Plug	XLR-female XLR-female		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
0.15	●	CPP 0.15 FF	

CPP MM

peak



Stage/Studio
Sample Application:
Gender Changer

Produktinformation Specification	
Kabel Cable	CPK 220
Belegung Cable Assign	MM
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-male XLR-male
Länge Length	Farbe Colour
0.15	●
Bestell-Nr. Part No.	
CPP 0.15 MM	

CPM FW-BAL

peak



Studio
Sample Application:
Balanced Special Patch

Produktinformation Specification	
Kabel Cable	CMK 209
Belegung Cable Assign	FV
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-female Plug 3.5 mm stereo
Länge Length	Farbe Colour
1.50	●
3.00	●
Bestell-Nr. Part No.	
CPM 1.5 FW-BAL	
CPM 3 FW-BAL	

CPM FW-UNB

peak



Home
Sample Application:
Connecting mics
to sound cards

Produktinformation Specification	
Kabel Cable	CMK 209
Belegung Cable Assign	FW UNB
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-female Plug 3.5 mm stereo
Länge Length	Farbe Colour
1.50	●
3.00	●
Bestell-Nr. Part No.	
CPM 1.5 FW-UNB	
CPM 3 FW-UNB	

CXM FM-SNOW

encore



Stage/Installation

Produktinformation Specification	
Kabel Cable	CMK 222
Belegung Cable Assign	FM
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-female XLR-male
Länge Length	Farbe Colour
1.00	○
2.50	○
5.00	○
10.00	○
Bestell-Nr. Part No.	
CXM 1 FM-SNOW	
CXM 2.5 FM-SNOW	
CXM 5 FM-SNOW	
CXM 10 FM-SNOW	

CXM FM-VINTAGE

encore



Stage

Produktinformation Specification	
Kabel Cable	-
Belegung Cable Assign	FM
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-female XLR-male
Länge Length	Farbe Colour
5.00	⊘
10.00	⊘
Bestell-Nr. Part No.	
CXM 5 FM-VINTAGE	
CXM 10 FM-VINTAGE	

CSM FM-CRYSTAL

encore



Stage

Produktinformation Specification		
Kabel Cable	CMK CRYSTAL 250	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR-female contacts gold XLR-male contacts gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
5.00	☼	CSM 5 FM-CRYSTAL
10.00	☼	CSM 10 FM-CRYSTAL

CRM CONV-CONV

encore



Stage
Sample Application:
Gender Changer

Produktinformation Specification		
Kabel Cable	CMK ROAD 250	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR-female/male (convertCON) XLR-female/male (convertCON)	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.15	●	CRM 0.15 CONV-CONV

CRM FM-BLACK

encore



Stage/Installation
Ultra Rugged

Produktinformation Specification		
Kabel Cable	CMK ROAD 250	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR-female XLR-male	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.00	●	CRM 1 FM-BLACK
1.50	●	CRM 1.5 FM-BLACK
2.50	●	CRM 2.5 FM-BLACK
5.00	●	CRM 5 FM-BLACK
7.50	●	CRM 7.5 FM-BLACK
10.00	●	CRM 10 FM-BLACK
20.00	●	CRM 20 FM-BLACK

CSM FM-GOLD

encore



Studio
Best sound for recording

Produktinformation Specification		
Kabel Cable	CMTOP 222	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR-female contacts gold XLR-male contacts gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
5.00	●	CSM 5 FM-GOLD
10.00	●	CSM 10 FM-GOLD

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CFM VV

intro



Stage/Studio
Sample Application:
Short Balanced Patch Cable

Produktinformation Specification		
Kabel Cable	CMN 220	
Belegung Cable Assign	VV	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 6.3 mm stereo gold Plug 6.3 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CFM 0.3 VV
0.60	●	CFM 0.6 VV
0.90	●	CFM 0.9 VV
1.50	●	CFM 1.5 VV
3.00	●	CFM 3 VV
6.00	●	CFM 6 VV
9.00	●	CFM 9 VV

CFM FV

intro



Stage/Studio
Sample Application:
Short Balanced Patch Cable

Produktinformation Specification		
Kabel Cable	CMN 220	
Belegung Cable Assign	FV	
Steckermarke Plug Brand	REAN	
Stecker Plug	XLR-female Plug 6.3 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CFM 0.3 FV
0.60	●	CFM 0.6 FV
1.50	●	CFM 1.5 FV
3.00	●	CFM 3 FV
6.00	●	CFM 6 FV
9.00	●	CFM 9 FV

CFM MV

intro



Stage/Studio
Sample Application:
Balanced Patch Cable

Produktinformation Specification		
Kabel Cable	CMN 220	
Belegung Cable Assign	MV	
Steckermarke Plug Brand	REAN	
Stecker Plug	XLR-male Plug 6.3 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CFM 0.3 MV
0.60	●	CFM 0.6 MV
1.50	●	CFM 1.5 MV
3.00	●	CFM 3 MV
6.00	●	CFM 6 MV
9.00	●	CFM 9 MV

CFM VK

intro



Home
Sample Application:
Headphone Extension

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	VK	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 6.3 mm stereo gold Jack 6.3 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CFM 3 VK
5.00	●	CFM 5 VK
7.50	●	CFM 7.5 VK
10.00	●	CFM 10 VK

CFM VK-SNOW

intro



Home
Sample Application:
Headphone Extension

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	VK	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 6.3 mm stereo gold Jack 6.3 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	○	CFM 3 VK-SNOW
5.00	○	CFM 5 VK-SNOW

CFM KM

intro



Stage/Studio
Sample Application:
Combining Inserts

Produktinformation | Specification

Kabel Cable	intro cable 1	
Belegung Cable Assign	KM	
Steckermarke Plug Brand	REAN	
Stecker Plug	XLR-male Jack 6.3 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.15	●	CFM 0.15 KM

CFM KF

intro



Stage/Studio
Sample Application:
Combining Inserts

Produktinformation | Specification

Kabel Cable	intro cable 1	
Belegung Cable Assign	KF	
Steckermarke Plug Brand	REAN	
Stecker Plug	XLR-female Jack 6.3 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.15	●	CFM 0.15 KF

CFM VY

intro



Home
Sample Application:
Headphone Extension

Produktinformation | Specification

Kabel Cable	intro cable 2	
Belegung Cable Assign	VK	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 6.3 mm stereo gold Jack 3.5 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.15	●	CFM 0.15 VY
3.00	●	CFM 3 VY

CFM WK

intro



Home
Sample Application:
Headphone Extension

Produktinformation | Specification

Kabel Cable	intro cable 2	
Belegung Cable Assign	VK	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold Jack 6.3 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.15	●	CFM 0.15 WK
3.00	●	CFM 3 WK

CFM WV

intro



Stage/Studio

Produktinformation | Specification

Kabel Cable	intro cable 1	
Belegung Cable Assign	VV	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 6.3 mm stereo gold Plug 3.5 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.5	●	CFM 1.5 WV
3.00	●	CFM 3 WV

CFM WW

intro



Home
Sample Application:
MP3 Player to Car Hifi

Produktinformation | Specification

Kabel Cable	intro cable 2	
Belegung Cable Assign	VV	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold Plug 3.5 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.60	●	CFS 0.6 WW
0.90	●	CFS 0.9 WW
1.50	●	CFS 1.5 WW
3.00	●	CFS 3 WW

CFS WW-SNOW intro



Home
Sample Application:
MP3 Player to Car Hifi

Produktinformation Specification		
Kabel Cable	intro cable 2	
Belegung Cable Assign	VV	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold Plug 3.5 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.60	○	CFS 0.6 WW-SNOW
0.90	○	CFS 0.9 WW-SNOW
1.50	○	CFS 1.5 WW-SNOW
3.00	○	CFS 3 WW-SNOW

CFS WY intro



Home
Sample Application:
Headphone Extension

Produktinformation Specification		
Kabel Cable	intro cable 2	
Belegung Cable Assign	VK	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold Jack 3.5 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CFS 3 WY
5.00	●	CFS 5 WY

CIM VV intro



Stage/Studio
Sample Application:
Short Balanced Patch Cable

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	VV	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	Plug 6.3 mm stereo Plug 6.3 mm stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CIM 0.3 VV
0.60	●	CIM 0.6 VV
0.90	●	CIM 0.9 VV
1.50	●	CIM 1.5 VV
3.00	●	CIM 3 VV
6.00	●	CIM 6 VV
9.00	●	CIM 9 VV

CIM FV intro



Stage/Studio
Sample Application:
Short Balanced Patch Cable

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	FV	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	XLR-female Plug 6.3 mm stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CIM 0.3 FV
0.60	●	CIM 0.6 FV
1.50	●	CIM 1.5 FV
3.00	●	CIM 3 FV
6.00	●	CIM 6 FV
9.00	●	CIM 9 FV

CIM MV intro



Stage/Studio
Sample Application:
Balanced Patch Cable

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	MV	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	XLR-male Plug 6.3 mm stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CIM 0.3 MV
0.60	●	CIM 0.6 MV
1.50	●	CIM 1.5 MV
3.00	●	CIM 3 MV
6.00	●	CIM 6 MV
9.00	●	CIM 9 MV

CPM VV

peak



Stage/Studio
Sample Application:
Long Balanced Connections

CPP TT

peak



Studio
Sample Application:
Patchbay Cable

Produktinformation Specification			
Kabel Cable		CMK 222	
Belegung Cable Assign		VV	
Steckermarke Plug Brand		NEUTRIK	
Stecker Plug		Plug 6.3 mm stereo Plug 6.3 mm stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
2.50	●	CPM 2.5 VV	
5.00	●	CPM 5 VV	
10.00	●	CPM 10 VV	

Produktinformation Specification			
Kabel Cable		CPK 220	
Belegung Cable Assign		VV	
Steckermarke Plug Brand		NEUTRIK	
Stecker Plug		TT-Phone stereo TT-Phone stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
0.30	●	CPP 0.3 TT	
0.60	● ● ●	CPP 0.6 TT	
0.90	●	CPP 0.9 TT	

CPM FV

peak



Stage/Studio
Sample Application:
Long Balanced Connections

CRM VV

encore



Stage/Installation
Ultra Rugged
Sample Application:
Long Balanced Connections

Produktinformation Specification			
Kabel Cable		CMK 222	
Belegung Cable Assign		FV	
Steckermarke Plug Brand		NEUTRIK	
Stecker Plug		XLR-female Plug 6.3 mm stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
2.50	●	CPM 2.5 FV	
5.00	●	CPM 5 FV	
10.00	●	CPM 10 FV	

Produktinformation Specification			
Kabel Cable		CMK ROAD 250	
Belegung Cable Assign		VV	
Steckermarke Plug Brand		NEUTRIK	
Stecker Plug		Plug 6.3 mm stereo Plug 6.3 mm stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
2.50	●	CRM 2.5 VV	
5.00	●	CRM 5 VV	
10.00	●	CRM 10 VV	

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CPM MV

peak



Stage/Studio
Sample Application:
Long Balanced Connections

Produktinformation Specification			
Kabel Cable		CMK 222	
Belegung Cable Assign		MV	
Steckermarke Plug Brand		NEUTRIK	
Stecker Plug		XLR-male Plug 6.3 mm stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
2.50	●	CPM 2.5 MV	
5.00	●	CPM 5 MV	
10.00	●	CPM 10 MV	

CRM FV encore



Stage/Installation
Ultra Rugged
Sample Application:
Long Balanced Connections

Produktinformation Specification		
Kabel Cable	CMK ROAD 250	
Belegung Cable Assign	FV	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR-female Plug 6.3 mm stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
2.50	●	CRM 2.5 FV
5.00	●	CRM 5 FV
10.00	●	CRM 10 FV

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CRM MV encore



Stage/Installation
Ultra Rugged
Sample Application:
Long Balanced Connections

Produktinformation Specification		
Kabel Cable	CMK ROAD 250	
Belegung Cable Assign	MV	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR-male Plug 6.3 mm stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
2.50	●	CRM 2.5 MV
5.00	●	CRM 5 MV
10.00	●	CRM 10 MV

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CRM CONV-V encore



Stage
Sample Application:
Balanced multi-adapter

Produktinformation Specification		
Kabel Cable	CMK ROAD 250	
Belegung Cable Assign	FV	
Steckermarke Plug Brand	NEUTRIK/CORDIAL	
Stecker Plug	XLR-female/male (convertCON) Plug 6.3 mm stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.15	●	CRM 0.15 CONV-V


CFU CC intro



Home/DJ
Sample Application:
CD Player to Mixer

Produktinformation Specification			
Kabel Cable	intro cable 3		
Belegung Cable Assign	CC		
Steckermarke Plug Brand	REAN		
Stecker Plug	2 x Cinch/RCA gold 2 x Cinch/RCA gold		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
0.30	●	CFU 0.3 CC	
0.60	●	CFU 0.6 CC	
0.90	●	CFU 0.9 CC	
1.50	●	CFU 1.5 CC	
3.00	●	CFU 3 CC	
6.00	●	CFU 6 CC	

CFU CC-SNOW intro

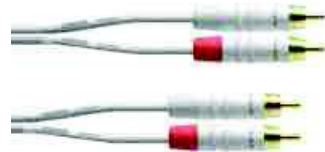

Home/DJ
Sample Application:
CD Player to Mixer

Produktinformation Specification			
Kabel Cable	intro cable 3		
Belegung Cable Assign	CC		
Steckermarke Plug Brand	REAN		
Stecker Plug	2 x Cinch/RCA gold 2 x Cinch/RCA gold		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
0.60	○	CFU 0.6 CC-SNOW	
0.90	○	CFU 0.9 CC-SNOW	
1.50	○	CFU 1.5 CC-SNOW	
3.00	○	CFU 3 CC-SNOW	
6.00	○	CFU 6 CC-SNOW	

CFU CE

intro



Stage/Studio

Produktinformation | Specification

Kabel Cable	intro cable 3	
Belegung Cable Assign	CE	
Steckermarke Plug Brand	REAN	
Stecker Plug	Cinch/RCA gold Cinch/RCA Jack gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFU 1.5 CE
3.00	●	CFU 3 CE

CFU MC

intro



Home/DJ
Don't use for phantom
powered outputs

Produktinformation | Specification

Kabel Cable	intro cable 3	
Belegung Cable Assign	MC	
Steckermarke Plug Brand	REAN	
Stecker Plug	2 x Cinch/RCA gold 2 x XLR-male	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFU 1.5 MC
3.00	●	CFU 3 MC
6.00	●	CFU 6 MC

CFU FC

intro



Home/DJ
Sample Application:
To use Record Outputs

Produktinformation | Specification

Kabel Cable	intro cable 3	
Belegung Cable Assign	FC	
Steckermarke Plug Brand	REAN	
Stecker Plug	2 x Cinch/RCA gold 2 x XLR-female	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFU 1.5 FC
3.00	●	CFU 3 FC

CFU MC-SNOW

intro



Home/DJ
Don't use for phantom
powered outputs

Produktinformation | Specification

Kabel Cable	intro cable 3	
Belegung Cable Assign	MC	
Steckermarke Plug Brand	REAN	
Stecker Plug	2 x Cinch/RCA gold 2 x XLR-male	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	○	CFU 1.5 MC-SNOW
3.00	○	CFU 3 MC-SNOW
6.00	○	CFU 6 MC-SNOW

CFU FC-SNOW

intro



Home/DJ
Sample Application:
To use Record Outputs

Produktinformation | Specification

Kabel Cable	intro cable 3	
Belegung Cable Assign	FC	
Steckermarke Plug Brand	REAN	
Stecker Plug	2 x Cinch/RCA gold 2 x XLR-female	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	○	CFU 1.5 FC-SNOW
3.00	○	CFU 3 FC-SNOW

CFU PC

intro



Home/DJ
Sample Application:
CD Player to Mixer

Produktinformation Specification		
Kabel Cable	intro cable 3	
Belegung Cable Assign	PC	
Steckermarke Plug Brand	REAN	
Stecker Plug	2 x Cinch/RCA gold 2 x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CFU 0.3 PC
0.60	●	CFU 0.6 PC
0.90	●	CFU 0.9 PC
1.50	●	CFU 1.5 PC
3.00	●	CFU 3 PC
6.00	●	CFU 6 PC

CFU PC-SNOW

intro



Home/DJ
Sample Application:
CD Player to Mixer

Produktinformation Specification		
Kabel Cable	intro cable 3	
Belegung Cable Assign	PC	
Steckermarke Plug Brand	REAN	
Stecker Plug	2 x Cinch/RCA gold 2 x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.60	○	CFU 0.6 PC-SNOW
0.90	○	CFU 0.9 PC-SNOW
1.50	○	CFU 1.5 PC-SNOW
3.00	○	CFU 3 PC-SNOW
6.00	○	CFU 6 PC-SNOW

CFU PP

intro



Home/DJ
Sample Application:
Keys to Mixer

Produktinformation Specification		
Kabel Cable	intro cable 3	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	REAN	
Stecker Plug	2x Plug 6.3 mm mono gold 2x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CFU 0.3 PP
0.60	●	CFU 0.6 PP
0.90	●	CFU 0.9 PP
1.50	●	CFU 1.5 PP
3.00	●	CFU 3 PP
6.00	●	CFU 6 PP

CFU PP-SNOW

intro



Home/DJ
Sample Application:
Keys to Mixer

Produktinformation Specification		
Kabel Cable	intro cable 3	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	REAN	
Stecker Plug	2x Plug 6.3 mm mono gold 2x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	○	CFU 1.5 PP-SNOW
3.00	○	CFU 3 PP-SNOW
6.00	○	CFU 6 PP-SNOW

CIU CC

intro



Home/DJ
Sample Application:
CD Player to Mixer

Produktinformation | Specification

Kabel Cable	intro cable 4	
Belegung Cable Assign	CC	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	2x Cinch/RCA 2x Cinch/RCA	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CIU 0.3 CC
0.60	●	CIU 0.6 CC
0.90	●	CIU 0.9 CC
1.50	●	CIU 1.5 CC
3.00	●	CIU 3 CC
6.00	●	CIU 6 CC

CIU FC

intro



Home/DJ
Sample Application:
Recording outs

Produktinformation | Specification

Kabel Cable	intro cable 4	
Belegung Cable Assign	FC	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	2x Cinch/RCA 2x XLR-female	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.90	●	CIU 0.9 FC
1.50	●	CIU 1.5 FC
3.00	●	CIU 3 FC
6.00	●	CIU 6 FC

CIU MC

intro



Home/DJ
Sample Application:
Combining Mixers

Produktinformation | Specification

Kabel Cable	intro cable 4	
Belegung Cable Assign	MC	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	2x Cinch/RCA 2x XLR-male	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.90	●	CIU 0.9 MC
1.50	●	CIU 1.5 MC
3.00	●	CIU 3 MC
6.00	●	CIU 6 MC

CIU PC

intro



Home/DJ
Sample Application:
CD Player to Mixer

Produktinformation | Specification

Kabel Cable	intro cable 4	
Belegung Cable Assign	PC	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	2x Cinch/RCA 2x Plug 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CIU 0.3 PC
0.60	●	CIU 0.6 PC
0.90	●	CIU 0.9 PC
1.50	●	CIU 1.5 PC
3.00	●	CIU 3 PC
6.00	●	CIU 6 PC

CIU PP intro



Home/DJ
Sample Application:
Keys to Mixer

Produktinformation Specification		
Kabel Cable	intro cable 4	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	2x Plug 6.3 mm mono 2x Plug 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CIU 0.3 PP
0.60	●	CIU 0.6 PP
0.90	●	CIU 0.9 PP
1.50	●	CIU 1.5 PP
3.00	●	CIU 3 PP
6.00	●	CIU 6 PP

CCFI PP intro



Stage/Home

Produktinformation Specification		
Kabel Cable	intro cable 5	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	REAN/CORDIAL	
Stecker Plug	Plug 6.3 mm mono tip gold Plug 6.3 mm mono tip gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CCFI 0.3 PP
0.60	●	CCFI 0.6 PP
0.90	●	CCFI 0.9 PP
1.50	●	CCFI 1.5 PP
3.00	●	CCFI 3 PP
4.50	●	CCFI 4.5 PP
6.00	●	CCFI 6 PP
9.00	●	CCFI 9 PP

CCI PP intro



Stage/Home
Sample Application:
Unbalanced Patch Cable

Produktinformation Specification		
Kabel Cable	intro cable 5	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 6.3 mm mono gold Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CCI 0.3 PP
0.60	●	CCI 0.6 PP
0.90	●	CCI 0.9 PP
1.50	●	CCI 1.5 PP
3.00	●	CCI 3 PP
6.00	●	CCI 6 PP
9.00	●	CCI 9 PP

CCI PR

intro



Stage/Home

Produktinformation Specification			
Kabel Cable	intro cable 5		
Belegung Cable Assign	PP		
Steckermarke Plug Brand	REAN		
Stecker Plug	Plug rectangular 6.3 mm mono Plug 6.3 mm mono gold		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
3.00	●	CCI 3 PR	
6.00	●	CCI 6 PR	
9.00	●	CCI 9 PR	

CFI RR

intro



Stage
Sample Application:
Effect/patch combination

Produktinformation Specification			
Kabel Cable	intro cable 5		
Belegung Cable Assign	PP		
Steckermarke Plug Brand	REAN		
Stecker Plug	Plug rectangular 6.3 mm mono Plug rectangular 6.3 mm mono		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
0.15	●	CFI 0.15 RR	
0.30	●	CFI 0.3 RR	
0.60	●	CFI 0.6 RR	
0.90	●	CFI 0.9 RR	
1.50	●	CFI 1.5 RR	
3.00	●	CFI 3 RR	
6.00	●	CFI 6 RR	

CII PP

intro



Stage/Home

Produktinformation Specification			
Kabel Cable	intro cable 5		
Belegung Cable Assign	PP		
Steckermarke Plug Brand	REAN SILVER		
Stecker Plug	Plug 6.3 mm mono Plug 6.3 mm mono		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
0.30	●	CII 0.3 PP	
0.60	●	CII 0.6 PP	
0.90	●	CII 0.9 PP	
1.50	●	CII 1.5 PP	
3.00	●	CII 3 PP	
6.00	●	CII 6 PP	
9.00	●	CII 9 PP	



CII PR

intro



Stage/Home

Produktinformation Specification			
Kabel Cable	intro cable 5		
Belegung Cable Assign	PP		
Steckermarke Plug Brand	REAN SILVER		
Stecker Plug	Plug rectangular 6.3 mm mono Plug 6.3 mm mono		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
3.00	●	CII 3 PR	
6.00	●	CII 6 PR	
9.00	●	CII 9 PR	

CXI PP



peak

Stage

Produktinformation | Specification

Kabel Cable	CIK 122	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono Plug 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CXI 1.5 PP
3.00	●	CXI 3 PP
6.00	●	CXI 6 PP
9.00	●	CXI 9 PP

CXI PR



peak

Stage

Produktinformation | Specification

Kabel Cable	CIK 122	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono Plug rectangular 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CXI 3 PR
6.00	●	CXI 6 PR
9.00	●	CXI 9 PR

CXI PR30



peak

Stage
Useful for some guitar models

Produktinformation | Specification

Kabel Cable	CIK 122	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono Plug rect. 30° 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CXI 3 PR30
6.00	●	CXI 6 PR30
9.00	●	CXI 9 PR30

CPI PP



peak

Stage

Produktinformation | Specification

Kabel Cable	CIK 122	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono Plug 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	● ● ●	CPI 3 PP
6.00	● ● ●	CPI 6 PP
9.00	●	CPI 9 PP

CPI PR



peak

Stage

Produktinformation | Specification

Kabel Cable	CIK 122	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono Plug rectangular 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CPI 3 PR
6.00	●	CPI 6 PR
9.00	●	CPI 9 PR

CPI RR



peak

Stage
Sample Application:
Connecting Effects

Produktinformation | Specification

Kabel Cable	CIK 122	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug rectangular 6.3 mm mono Plug rectangular 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.15	●	CPI 0.15 RR
0.30	●	CPI 0.3 RR

CPI ZZ

peak



Stage/Studio
Sample Application:
Modular Instrument

Produktinformation Specification	
Kabel Cable	CIK 122
Belegung Cable Assign	PP
Steckermarke Plug Brand	REAN
Stecker Plug	Plug 3.5 mm mono Plug 3.5 mm mono
Länge Length	Farbe Colour
0.15	● (Tülle Sleeve)
0.30	● (Tülle Sleeve)
0.60	● (Tülle Sleeve)
0.90	● (Tülle Sleeve)
1.20	● (Tülle Sleeve)



Verschieden farbige Tüllen zur Längenkennzeichnung der Kabel | Different colored sleeve per length

CPI FP-RT 3

peak



Stage
Sample Application:
Connecting Guitar
to Transmitter

Produktinformation Specification	
Kabel Cable	CMK 209
Belegung Cable Assign	FP
Steckermarke Plug Brand	NEUTRIK/REAN
Stecker Plug	XLR-female tiny 3-pole Plug 6.3 mm mono
Länge Length	Farbe Colour
1.00	●

CPI FP-RT 4

peak



Stage
Sample Application:
Connecting Guitar
to Transmitter

Produktinformation Specification	
Kabel Cable	CMK 209
Belegung Cable Assign	F4P
Steckermarke Plug Brand	NEUTRIK/REAN
Stecker Plug	XLR-female tiny 4-pole Plug 6.3 mm mono
Länge Length	Farbe Colour
1.00	●

CXI PP-SNOW

encore



Stage

Produktinformation Specification	
Kabel Cable	CIK 122
Belegung Cable Assign	PP
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	Plug 6.3 mm mono Plug 6.3 mm mono
Länge Length	Farbe Colour
3.00	○
6.00	○
9.00	○

CXI RP-SNOW-SILENT

encore



Stage
Signal muted
if plug not connected

Produktinformation Specification	
Kabel Cable	CIK 122
Belegung Cable Assign	PP
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	Plug rectangular 6.3 mm mono gold SILENT Plug 6.3 mm mono
Länge Length	Farbe Colour
3.00	○
6.00	○

CXI PP-VINTAGE

encore



Stage

Produktinformation Specification	
Kabel Cable	CIK 122 VINTAGE
Belegung Cable Assign	PP
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	Plug 6.3 mm mono Plug 6.3 mm mono
Länge Length	Farbe Colour
3.00	●
6.00	●
9.00	●

CXI PP-TWEED

encore



Stage

Produktinformation Specification		
Kabel Cable	CIK 122 TWEED	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono Plug 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CXI 3 PP-TWEED
6.00	●	CXI 6 PP-TWEED
9.00	●	CXI 9 PP-TWEED

CXI PP-SKY

encore



Stage

Produktinformation Specification		
Kabel Cable	CIK 122 SKY	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono Plug 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CXI 3 PP-SKY
6.00	●	CXI 6 PP-SKY
9.00	●	CXI 9 PP-SKY



CSI PP-CRYSTAL

encore



Stage

Produktinformation Specification		
Kabel Cable	-	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono gold Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CSI 3 PP-CRYSTAL
6.00	●	CSI 6 PP-CRYSTAL
9.00	●	CSI 9 PP-CRYSTAL

SMOLSKI

encore



Stage/Studio
According to Victor Smolski's
Specifications

Produktinformation Specification		
Kabel Cable	CGK 122	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono gold Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	SMOLSKI 3
6.00	●	SMOLSKI 6



CSI PP-METAL

encore





Stage
Ultra Rugged
Low Attenuation

Produktinformation Specification		
Kabel Cable	CGK 175 METAL TRANSPARENT	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono gold Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CSI 3 PP-METAL
6.00	●	CSI 6 PP-METAL
9.00	●	CSI 9 PP-METAL
12.00	●	CSI 12 PP-METAL
15.00	●	CSI 15 PP-METAL



the soul of pure copper

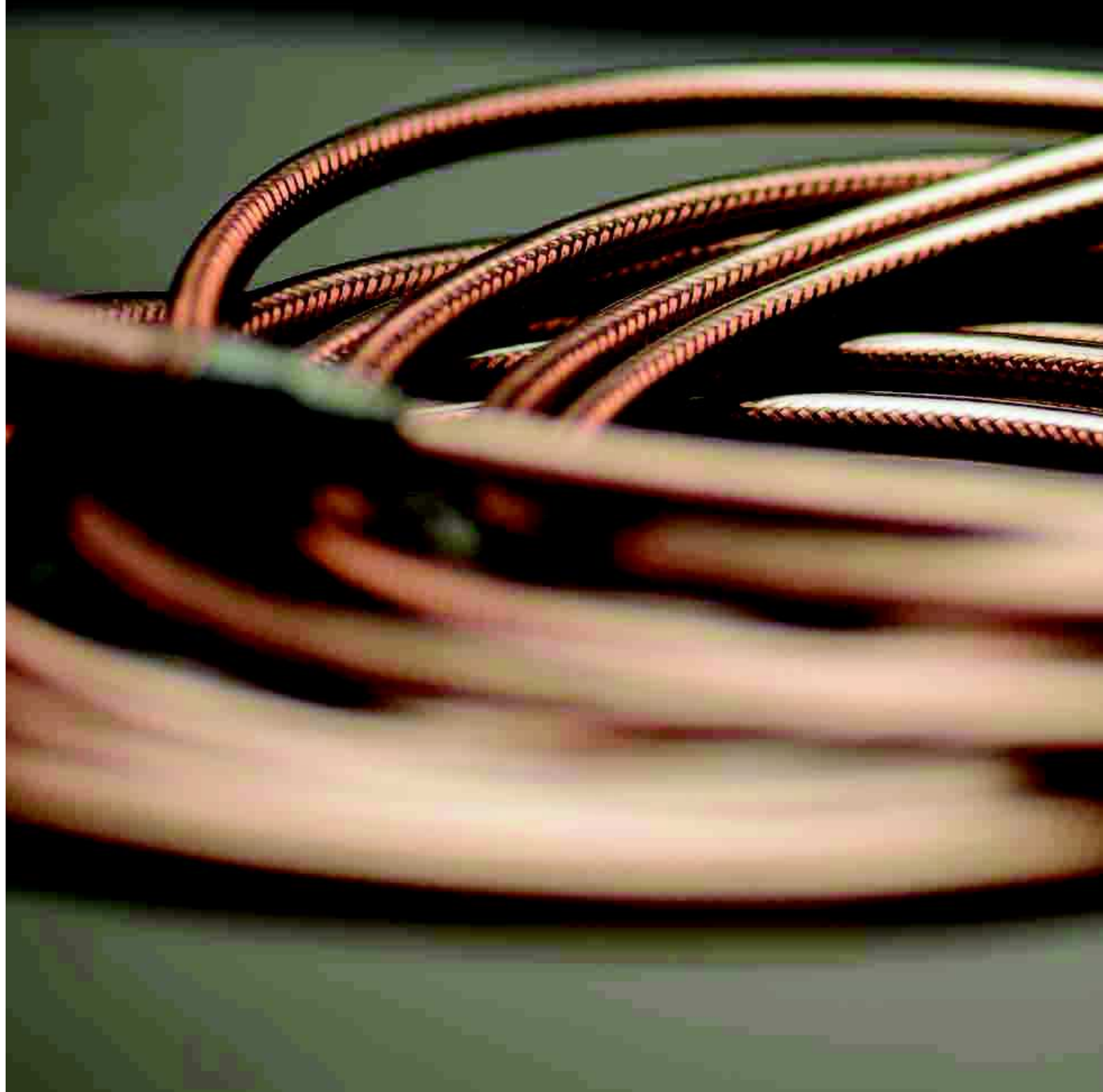

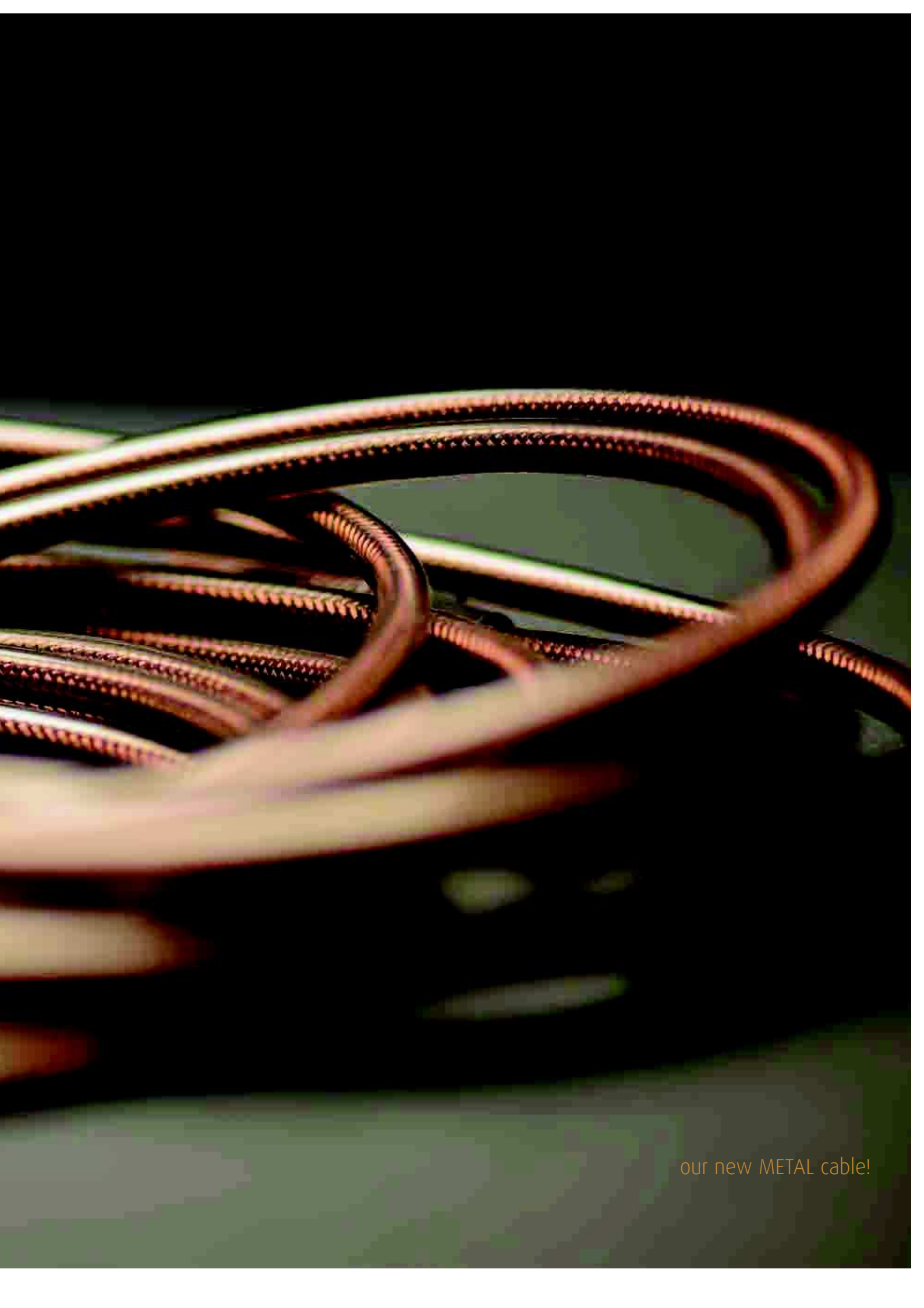

our new METAL cable!

CRI PP

encore



Stage
Ultra Rugged
Low Attenuation

CRI RR

encore



Stage
Ultra Rugged
Sample Application:
Connecting Effects

Produktinformation | Specification

Kabel | Cable CGK ROAD 75

Belegung | Cable Assign PP

Steckermarke | Plug Brand NEUTRIK/CORDIAL

Stecker | Plug Plug 6.3 mm mono gold | Plug 6.3 mm mono gold

Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CRI 3 PP
6.00	●	CRI 6 PP
9.00	●	CRI 9 PP

CRI PR

encore



Stage
Ultra Rugged
Low Attenuation

CSI PP-GOLD

encore



Studio
Ideal for Studio recording

Produktinformation | Specification

Kabel | Cable CGK ROAD 75

Belegung | Cable Assign PP

Steckermarke | Plug Brand NEUTRIK/CORDIAL

Stecker | Plug Plug 6.3 mm mono gold | Plug rectangular 6.3 mm mono gold

Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CRI 3 PR
6.00	●	CRI 6 PR
9.00	●	CRI 9 PR

Produktinformation | Specification

Kabel | Cable CGK 122

Belegung | Cable Assign PP

Steckermarke | Plug Brand NEUTRIK

Stecker | Plug Plug 6.3 mm mono gold | Plug 6.3 mm mono gold

Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CSI 3 PP-GOLD
6.00	●	CSI 6 PP-GOLD
9.00	●	CSI 9 PP-GOLD

CSI PR-GOLD

encore



Studio
Ideal for Studio recording

Produktinformation | Specification

Kabel Cable	CGK 122
Belegung Cable Assign	PP
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	Plug 6.3 mm mono gold Plug rectangular 6.3 mm mono gold

Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CSI 3 PR-GOLD
6.00	●	CSI 6 PR-GOLD
9.00	●	CSI 9 PR-GOLD

CSI PR 175

encore



Stage
Perfect for live applications

Produktinformation | Specification

Kabel Cable	CGK 175
Belegung Cable Assign	PP
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	Plug 6.3 mm mono gold Plug rectangular 6.3 mm mono gold

Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CSI 3 PR 175
6.00	●	CSI 6 PR 175
9.00	●	CSI 9 PR 175

CSI PP 175

encore



Stage
Perfect for live applications

Produktinformation | Specification

Kabel Cable	CGK 175
Belegung Cable Assign	PP
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	Plug 6.3 mm mono gold Plug 6.3 mm mono gold

Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CSI 3 PP 175
6.00	●	CSI 6 PP 175
9.00	●	CSI 9 PP 175

CSI PP-SILENT

encore



Stage
Do not plug into amplifier output
Not effective when tip-ring-sleeve jacks activate guitar power supply

Produktinformation | Specification

Kabel Cable	CGK 175
Belegung Cable Assign	PP
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	Plug 6.3 mm mono gold SILENT Plug 6.3 mm mono gold

Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CSI 3 PP-SILENT
6.00	●	CSI 6 PP-SILENT
9.00	●	CSI 9 PP-SILENT



CSI RP-SILENT



encore

Stage
Do not plug
into amplifier output
Not effective when
tip-ring-sleeve jacks activate
guitar power supply

CFY WCC



intro

Stage/DJ
Short split
15,2 cm on 2 x Plug Side
Sample Application:
MP3 Player to Mixer

Produktinformation | Specification

Kabel | Cable CGK 175

Belegung | Cable Assign PP

Steckermarke | Plug Brand NEUTRIK

Stecker | Plug Plug rectangular 6.3 mm mono gold SILENT | Plug 6.3 mm mono gold

Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CSI 3 RP-SILENT
6.00	●	CSI 6 RP-SILENT
9.00	●	CSI 9 RP-SILENT

Produktinformation | Specification

Kabel | Cable intro cable 2

Belegung | Cable Assign WCC

Steckermarke | Plug Brand REAN

Stecker | Plug Plug 3.5 mm stereo gold | 2x Cinch/RCA gold

Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.90	●	CFY 0.9 WCC
1.50	●	CFY 1.5 WCC
3.00	●	CFY 3 WCC
6.00	●	CFY 6 WCC

 
CSI RP-TIMBRE



encore

Stage/Studio
Changes sound at passive
guitars

CFY WCC-SNOW



intro

Stage/DJ
Short split
15,2 cm on 2 x Plug Side
Sample Application:
MP3 Player to Mixer

Produktinformation | Specification

Kabel | Cable CGK 175

Belegung | Cable Assign PP

Steckermarke | Plug Brand NEUTRIK

Stecker | Plug Plug 6.3 mm mono gold TIMBRE | Plug 6.3 mm mono gold

Länge Length	Farbe Colour	Bestell-Nr. Part No.
3.00	●	CSI 3 RP-TIMBRE
6.00	●	CSI 6 RP-TIMBRE

Produktinformation | Specification

Kabel | Cable intro cable 2

Belegung | Cable Assign WCC

Steckermarke | Plug Brand REAN

Stecker | Plug Plug 3.5 mm stereo gold | 2x Cinch/RCA gold

Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	○	CFY 1.5 WCC-SNOW
3.00	○	CFY 3 WCC-SNOW
6.00	○	CFY 6 WCC-SNOW

CFY WCC-LONG

intro



Stage/DJ
Long split
15,2 cm on 1 x Plug Side
Sample Application:
MP3 Player to Mixer

Produktinformation | Specification

Kabel Cable	intro cable 2	
Belegung Cable Assign	WCC	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold 2x Cinch/RCA gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.90	●	CFY 0.9 WCC-LONG
1.50	●	CFY 1.5 WCC-LONG
3.00	●	CFY 3 WCC-LONG
6.00	●	CFY 6 WCC-LONG

CFY WCC-LONG-SNOW

intro



Stage/DJ
Long split
15,2 cm on 1 x Plug Side
Sample Application:
MP3 Player to Mixer

Produktinformation | Specification

Kabel Cable	intro cable 2	
Belegung Cable Assign	WCC	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold 2x Cinch/RCA gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.90	○	CFY 0.9 WCC-LONG-SNOW
1.50	○	CFY 1.5 WCC-LONG-SNOW
3.00	○	CFY 3 WCC-LONG-SNOW
6.00	○	CFY 6 WCC-LONG-SNOW

CFY WEE

intro



Stage/Studio
Short split
15,2 cm on 2 x Plug Side

Produktinformation | Specification

Kabel Cable	intro cable 2	
Belegung Cable Assign	VEE	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold 2x Cinch/RCA Jack gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CFY 0.3 WEE

CFY WPP

intro



Stage/Studio
Short split
15,2 cm on 2 x Plug Side
Sample Application:
Laptop to DI-Box

Produktinformation | Specification

Kabel Cable	intro cable 2	
Belegung Cable Assign	WPP	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold 2x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.90	●	CFY 0.9 WPP
1.50	●	CFY 1.5 WPP
3.00	●	CFY 3 WPP
6.00	●	CFY 6 WPP

CFY WPP-SNOW

intro



Stage/Studio
Short split
15,2 cm on 2x Plug Side
Sample Application:
Laptop to DI-Box

Produktinformation Specification		
Kabel Cable	intro cable 2	
Belegung Cable Assign	WPP	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold 2x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	○	CFY 1.5 WPP-SNOW
3.00	○	CFY 3 WPP-SNOW
6.00	○	CFY 6 WPP-SNOW

CFY WPP-LONG

intro



Studio/Home
Long split
15,2 cm on 1x Plug Side

Produktinformation Specification		
Kabel Cable	intro cable 2	
Belegung Cable Assign	WPP	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold 2x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFY 1.5 WPP-LONG
3.00	●	CFY 3 WPP-LONG

CFY WPP-LONG-SNOW

intro



Studio/Home
Long split
15,2 cm on 1x Plug Side

Produktinformation Specification		
Kabel Cable	intro cable 2	
Belegung Cable Assign	WPP	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold 2x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	○	CFY 1.5 WPP-LONG-SNOW
3.00	○	CFY 3 WPP-LONG-SNOW

CFY WYY

intro



Home
Short split
15,2 cm on 2x Plug Side
Sample Application:
Headphone Splitting

Produktinformation Specification		
Kabel Cable	intro cable 2	
Belegung Cable Assign	VKK	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold 2x Jack 3.5 mm stereo gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CFY 0.3 WYY

CFY WGG

intro



Stage
Short split
15,2 cm on 2x Plug Side

Produktinformation Specification		
Kabel Cable	intro cable 2	
Belegung Cable Assign	VGG	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 3.5 mm stereo gold 2x Jack 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CFY 0.3 WGG

CFY WFF

intro



Stage/Studio
Short split
15,2 cm on 2x Plug Side
Sample Application:
Record Out/Matrix Out

Produktinformation Specification	
Kabel Cable	intro cable 2
Belegung Cable Assign	WFF
Steckermarke Plug Brand	REAN
Stecker Plug	Plug 3.5 mm stereo gold 2x XLR-female
Länge Length	Farbe Colour
1.80	●
3.00	●
Bestell-Nr. Part No.	
	CFY 1.8 WFF
	CFY 3 WFF

CFY WMM-LONG

intro



Studio/Home
Long split
15,2 cm on 1x Plug Side

Produktinformation Specification	
Kabel Cable	intro cable 2
Belegung Cable Assign	WMM
Steckermarke Plug Brand	REAN
Stecker Plug	Plug 3.5 mm stereo gold 2x XLR-male
Länge Length	Farbe Colour
1.50	●
3.00	●
Bestell-Nr. Part No.	
	CFY 1.5 WMM-LONG
	CFY 3 WMM-LONG

CFY WMM

intro



Stage/Studio
Short split
15,2 cm on 2x Plug Side
Don't use for phantom
powered inputs

Produktinformation Specification	
Kabel Cable	intro cable 2
Belegung Cable Assign	WMM
Steckermarke Plug Brand	REAN
Stecker Plug	Plug 3.5 mm stereo gold 2x XLR-male
Länge Length	Farbe Colour
1.80	●
3.00	●
Bestell-Nr. Part No.	
	CFY 1.8 WMM
	CFY 3 WMM

CFY WMM-LONG-SNOW

intro



Studio/Home
Long split
15,2 cm on 1x Plug Side

Produktinformation Specification	
Kabel Cable	intro cable 2
Belegung Cable Assign	WMM
Steckermarke Plug Brand	REAN
Stecker Plug	Plug 3.5 mm stereo gold 2x XLR-male
Länge Length	Farbe Colour
1.50	○
3.00	○
6.00	○
9.00	○
Bestell-Nr. Part No.	
	CFY 1.5 WMM-LONG-SNOW
	CFY 3 WMM-LONG-SNOW
	CFY 6 WMM-LONG-SNOW
	CFY 9 WMM-LONG-SNOW

CFY WMM-SNOW

intro



Stage/Studio
Short split
15,2 cm on 2x Plug Side
Don't use for phantom
powered inputs

Produktinformation Specification	
Kabel Cable	intro cable 2
Belegung Cable Assign	WMM
Steckermarke Plug Brand	REAN
Stecker Plug	Plug 3.5 mm stereo gold 2x XLR-male
Länge Length	Farbe Colour
1.80	○
3.00	○
Bestell-Nr. Part No.	
	CFY 1.8 WMM-SNOW
	CFY 3 WMM-SNOW

CFY VCC

intro



Studio/Home
Short split
15,2 cm on 2x Plug Side
Sample Application:
Keys Line out Stereo to Mixer

CFY VPP-SNOW

intro



Stage/Studio
Short split
15,2 cm on 2x Plug Side
Sample Application:
Y-Insert Cable

Produktinformation Specification		
Kabel Cable	intro cable 2	
Belegung Cable Assign	WCC	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 6.3 mm stereo gold 2x Cinch/RCA gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.90	●	CFY 0.9 VCC
1.50	●	CFY 1.5 VCC
3.00	●	CFY 3 VCC
6.00	●	CFY 6 VCC

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	VPP	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 6.3 mm stereo gold 2x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	○	CFY 1.5 VPP-SNOW
3.00	○	CFY 3 VPP-SNOW

CFY VPP

intro



Stage/Studio
Short split
15,2 cm on 2x Plug Side
Sample Application:
Y-Insert Cable

CFY VPP-LONG

intro



Stage/Studio
Long split
15,2 cm on 1x Plug Side
Sample Application:
Y-Insert Cable

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	VPP	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 6.3 mm stereo gold 2x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.90	●	CFY 0.9 VPP
1.50	●	CFY 1.5 VPP
3.00	●	CFY 3 VPP
6.00	●	CFY 6 VPP

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	VPP	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 6.3 mm stereo gold 2x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFY 1.5 VPP-LONG
3.00	●	CFY 3 VPP-LONG

CFY VPP-LONG-SNOW

intro



Stage/Studio
Long split
15,2 cm on 1x Plug Side
Sample Application:
Y-Insert Cable

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	VPP	
Steckermarke Plug Brand	REAN	
Stecker Plug	Plug 6.3 mm stereo gold 2x Plug 6.3 mm mono gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	○	CFY 1.5 VPP-LONG-SNOW
3.00	○	CFY 3 VPP-LONG-SNOW

CFY VYY

intro



Home
Short split
15,2 cm on 2 x Plug Side
Sample Application:
Headphone Splitting
+ Adapter

Produktinformation Specification	
Kabel Cable	intro cable 2
Belegung Cable Assign	VKK
Steckermarke Plug Brand	REAN
Stecker Plug	Plug 6.3 mm stereo gold 2x Jack 3.5 mm stereo gold
Länge Length	Farbe Colour
0.30	●
Bestell-Nr. Part No.	CFY 0.3 VYY

CFY VGG

intro



Stage
Short split
15,2 cm on 2 x Plug Side

Produktinformation Specification	
Kabel Cable	intro cable 1
Belegung Cable Assign	VGG
Steckermarke Plug Brand	REAN
Stecker Plug	Plug 6.3 mm stereo gold 2x Jack 6.3 mm mono gold
Länge Length	Farbe Colour
0.30	●
Bestell-Nr. Part No.	CFY 0.3 VGG

CFY VKK

intro



Studio/Home
Short split
15,2 cm on 2 x Plug Side
Sample Application:
Headphone Splitting

Produktinformation Specification	
Kabel Cable	intro cable 1
Belegung Cable Assign	VKK
Steckermarke Plug Brand	REAN
Stecker Plug	Plug 6.3 mm stereo gold 2x Jack 6.3 mm stereo gold
Länge Length	Farbe Colour
0.30	●
Bestell-Nr. Part No.	CFY 0.3 VKK

CFY VFM

intro



Stage/Studio
Short split
15,2 cm on 2 x Plug Side
Sample Application:
Y-Insert Cable

Produktinformation Specification	
Kabel Cable	intro cable 1
Belegung Cable Assign	VFM
Steckermarke Plug Brand	REAN
Stecker Plug	Plug 6.3 mm stereo gold XLR-male and XLR-female
Länge Length	Farbe Colour
1.80	●
3.00	●
Bestell-Nr. Part No.	CFY 1.8 VFM
	CFY 3 VFM

CFY KPP

intro



Stage/Studio
Short split
15,2 cm on 2 x Plug Side

Produktinformation Specification	
Kabel Cable	intro cable 1
Belegung Cable Assign	KPP
Steckermarke Plug Brand	REAN
Stecker Plug	Jack 6.3 mm stereo gold 2x Plug 6.3 mm mono gold
Länge Length	Farbe Colour
0.30	●
Bestell-Nr. Part No.	CFY 0.3 KPP

CFY PGG

intro



Stage
Short split
15,2 cm on 2x Plug Side

CFY ECC

intro



Home
Short split
15,2 cm on 2x Plug Side

Produktinformation Specification	
Kabel Cable	intro cable 1
Belegung Cable Assign	PGG
Steckermarke Plug Brand	REAN
Stecker Plug	Plug 6.3 mm mono gold 2x Jack 6.3 mm mono gold
Länge Length	Farbe Colour
0.30	●
	Bestell-Nr. Part No.
	CFY 0.3 PGG

Produktinformation Specification		
Kabel Cable	intro cable 2	
Belegung Cable Assign	ECC	
Steckermarke Plug Brand	REAN	
Stecker Plug	Cinch/RCA Jack gold 2x Cinch/RCA gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CFY 0.3 ECC

CFY GPP

intro



Stage
Short split
15,2 cm on 2x Plug Side

CFY YCC

intro



Home
Short split
15,2 cm on 2x Plug Side

Produktinformation Specification	
Kabel Cable	intro cable 1
Belegung Cable Assign	GPP
Steckermarke Plug Brand	REAN
Stecker Plug	Jack 6.3 mm mono gold 2x Plug 6.3 mm mono gold
Länge Length	Farbe Colour
0.30	●
	Bestell-Nr. Part No.
	CFY 0.3 GPP

Produktinformation Specification		
Kabel Cable	intro cable 2	
Belegung Cable Assign	YCC	
Steckermarke Plug Brand	REAN	
Stecker Plug	Jack 3.5 mm stereo gold 2x Cinch/RCA gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CFY 0.3 YCC

CFY CEE

intro



Home
Short split
15,2 cm on 2x Plug Side
Sample Application:
Split CD Players Signal

CFY FMM

intro



Stage
Short split
15,2 cm on 2x Plug Side
Sample Application:
microphone splitting

Produktinformation Specification	
Kabel Cable	intro cable 2
Belegung Cable Assign	CEE
Steckermarke Plug Brand	REAN
Stecker Plug	Cinch/RCA gold 2x Cinch/RCA Jack gold
Länge Length	Farbe Colour
0.30	●
	Bestell-Nr. Part No.
	CFY 0.3 CEE

Produktinformation Specification		
Kabel Cable	intro cable 1	
Belegung Cable Assign	FMM	
Steckermarke Plug Brand	REAN	
Stecker Plug	XLR-female 2x XLR-male	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CFY 0.3 FMM

CFCA S

peak



Stage
Do not plug under load

Produktinformation Specification		
Kabel Cable	H 05 VV F3G1.50	
Belegung Cable Assign		
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	PowerCON blue type A power in CEE 7/7	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFCA 1.5 S
3.00	●	CFCA 3 S
5.00	●	CFCA 5 S
10.00	●	CFCA 10 S

CFCA SRC

peak



Stage
Do not plug under load

Produktinformation Specification		
Kabel Cable	H 05 VV F3G1.50	
Belegung Cable Assign		
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	PowerCON blue type A power in CEE 7/7 rectangular	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFCA 1.5 SRC
3.00	●	CFCA 3 SRC

CFCA FCB

peak



Stage
Do not plug under load

Produktinformation Specification		
Kabel Cable	H 05 VV F3G1.50	
Belegung Cable Assign	FCAFCB	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	PowerCON blue type A power in PowerCON grey type B power out	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFCA 1.5 FCB
3.00	●	CFCA 3 FCB
5.00	●	CFCA 5 FCB
10.00	●	CFCA 10 FCB

CFCA S-TRUE1

peak



Stage/Outdoor
Titanex® cable
Dust & water resistant(IP65)
can be plugged under load
on PowerCON TRUE1

Produktinformation Specification		
Kabel Cable	H 07 RN F3G1.50	
Belegung Cable Assign	FCAFCB	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	PowerCON TRUE1 power in CEE 7/7	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFCA 1.5 S-TRUE
3.00	●	CFCA 3 S-TRUE
5.00	●	CFCA 5 S-TRUE
10.00	●	CFCA 10 S-TRUE

CFCA S-TRUE1-PVC

peak



Stage
Can be plugged under load
on PowerCON TRUE1 side
only

CPH DMX 1-5 PWR 1

peak



Stage
Efficient laying of
Power DMX connections
5-pole DMX

Produktinformation Specification		
Kabel Cable	H 05 VV F3G1.50	
Belegung Cable Assign	FCAFCB	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	PowerCON TRUE1 power in CEE 7/7	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFCA 1.5 S-TRUE-PVC
3.00	●	CFCA 3 S-TRUE-PVC
5.00	●	CFCA 5 S-TRUE-PVC
10.00	●	CFCA 10 S-TRUE-PVC



Produktinformation Specification		
Kabel Cable	CDP 1	
Belegung Cable Assign	CPH_DMX1-5 PWR1	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR F 5-pol. / PowerCON blue A in XLR M 5-pol. / PowerCON grey B out	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CPH 1.5 DMX 1-5 PWR 1
3.00	●	CPH 3 DMX 1-5 PWR 1
5.00	●	CPH 5 DMX 1-5 PWR 1
10.00	●	CPH 10 DMX 1-5 PWR 1

CFCA FCB-TRUE1

peak



Stage/Outdoor
Titanex® cable
Dust & water resistant(IP65)
PowerCON can be plugged
under load

CPH DMX 1 PWR 1

peak



Stage
Efficient laying of
Power DMX connections

Produktinformation Specification		
Kabel Cable	H 07 RN F3G1.50	
Belegung Cable Assign	FCAFCB	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	PowerCON TRUE1 power in PowerCON TRUE1 power out	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFCA 1.5 FCB-TRUE
3.00	●	CFCA 3 FCB-TRUE
5.00	●	CFCA 5 FCB-TRUE
10.00	●	CFCA 10 FCB-TRUE

Produktinformation Specification		
Kabel Cable	CDP 1	
Belegung Cable Assign	CPH_DMX1 PWR1	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR F 3-pol. / PowerCON blue A in XLR M 3-pol. / PowerCON grey B out	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CPH 1.5 DMX 1 PWR 1
3.00	●	CPH 3 DMX 1 PWR 1
5.00	●	CPH 5 DMX 1 PWR 1
10.00	●	CPH 10 DMX 1 PWR 1

CPL PP

peak



Stage
Safe operation until
50 Volt max
Sample Application:
Between Amp + Cabinet

Produktinformation Specification		
Kabel Cable	CLS 215	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono Plug 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.00	●	CPL 1 PP
1.50	●	CPL 1.5 PP
3.00	●	CPL 3 PP
5.00	●	CPL 5 PP
10.00	●	CPL 10 PP

CPL PP 25

peak



Stage
Safe operation until
50 Volt max
Sample Application:
Between Amp + Cabinet

Produktinformation Specification		
Kabel Cable	CLS 225	
Belegung Cable Assign	PP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Plug 6.3 mm mono Plug 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CPL 1.5 PP 25
10.00	●	CPL 10 PP 25
20.00	●	CPL 20 PP 25

CPL LP 25

peak



Stage
Safe operation until
50 Volt max

Produktinformation Specification		
Kabel Cable	CLS 225	
Belegung Cable Assign	LP	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Speakon 2-pole Plug 6.3 mm mono	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CPL 1.5 LP 25
5.00	●	CPL 5 LP 25
10.00	●	CPL 10 LP 25

CPL LL 2-215

peak



Stage

Produktinformation Specification		
Kabel Cable	CLS 215	
Belegung Cable Assign	LL2	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Speakon 2-pole Speakon 2-pole	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.00	●	CPL 1 LL 2-215

CPL LL 2



peak

Stage

CPL LL 4



peak

Stage
Sample Application:
Connecting Powermixer
to Speaker
4-Pole Connection

Produktinformation Specification		
Kabel Cable	CLS 225	
Belegung Cable Assign	LL2	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Speakon 2-pole Speakon 2-pole	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CPL 1.5 LL 2
3.00	●	CPL 3 LL 2
5.00	●	CPL 5 LL 2
10.00	●	CPL 10 LL 2
15.00	●	CPL 15 LL 2
20.00	●	CPL 20 LL 2

Produktinformation Specification		
Kabel Cable	CLS 425	
Belegung Cable Assign	LL4	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Speakon 4-pole Speakon 4-pole	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CPL 1.5 LL 4
5.00	●	CPL 5 LL 4
10.00	●	CPL 10 LL 4
15.00	●	CPL 15 LL 4
20.00	●	CPL 20 LL 4

CPL LL



peak

Stage
2-Pole Connection

CRL LL



encore

Stage
2-Pole Connection
Ultra Rugged

Produktinformation Specification		
Kabel Cable	CLS 225	
Belegung Cable Assign	LL2	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Speakon 4-pole Speakon 4-pole	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
5.00	●	CPL 5 LL
10.00	●	CPL 10 LL
15.00	●	CPL 15 LL
20.00	●	CPL 20 LL

Produktinformation Specification		
Kabel Cable	CLS ROAD 225	
Belegung Cable Assign	LL2	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Speakon 4-pole Speakon 4-pole	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
2.50	●	CRL 2.5 LL
5.00	●	CRL 5 LL
10.00	●	CRL 10 LL
15.00	●	CRL 15 LL
20.00	●	CRL 20 LL

CML 8-0 FM C

intro



Stage/Studio
split length(cable)=0,4m
Sample Application:
Patch Ponnexion
Siderack

Produktinformation		Specification	
Kabel Cable	intro cable 6		
Belegung Cable Assign	FM		
Steckermarke Plug Brand	REAN		
Stecker Plug	8x XLR-female 8x XLR-male		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
3.00	●	CML 8-0 FM 3 C	
5.00	●	CML 8-0 FM 5 C	

CML 8-0 PP C

intro



Stage/Studio
split length(cable)=0,4m
Sample Application:
Patch Ponnexion
Siderack

Produktinformation		Specification	
Kabel Cable	intro cable 6		
Belegung Cable Assign	PP		
Steckermarke Plug Brand	REAN		
Stecker Plug	8x Plug 6.3 mm mono 8x Plug 6.3 mm mono		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
3.00	●	CML 8-0 PP 3 C	
5.00	●	CML 8-0 PP 5 C	

CML 8-0 FV C

intro



Stage/Studio
split length(cable)=0,4m
Sample Application:
Patch Ponnexion
Siderack

Produktinformation		Specification	
Kabel Cable	intro cable 6		
Belegung Cable Assign	FV		
Steckermarke Plug Brand	REAN		
Stecker Plug	8x XLR-female 8x Plug 6.3 mm stereo		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
3.00	●	CML 8-0 FV 3 C	
5.00	●	CML 8-0 FV 5 C	

CML 8-0 VV C

intro



Stage/Studio
split length(cable)=0,4m
Sample Application:
Patch Ponnexion
Siderack

Produktinformation		Specification	
Kabel Cable	intro cable 6		
Belegung Cable Assign	VV		
Steckermarke Plug Brand	REAN		
Stecker Plug	8x Plug 6.3 mm stereo 8x Plug 6.3 mm stereo		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
3.00	●	CML 8-0 VV 3 C	
5.00	●	CML 8-0 VV 5 C	

CML 8-0 MV C

intro



Stage/Studio
split length(cable)=0,4m
Sample Application:
Patch Ponnexion
Siderack

Produktinformation		Specification	
Kabel Cable	intro cable 6		
Belegung Cable Assign	MV		
Steckermarke Plug Brand	REAN		
Stecker Plug	8x XLR-male 8x Plug 6.3 mm stereo		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
3.00	●	CML 8-0 MV 3 C	
5.00	●	CML 8-0 MV 5 C	

CML 8-0 CC C

intro




Stage/Studio
split length(cable)=0,4m
Sample Application:
Patch Ponnexion
Siderack

Produktinformation		Specification	
Kabel Cable	intro cable 6		
Belegung Cable Assign	CC		
Steckermarke Plug Brand	REAN		
Stecker Plug	8x Cinch/RCA gold 8x Cinch/RCA gold		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
1.50	●	CML 8-0 CC 1.5 C	
3.00	●	CML 8-0 CC 3 C	
5.00	●	CML 8-0 CC 5 C	

CFD DFMY

intro

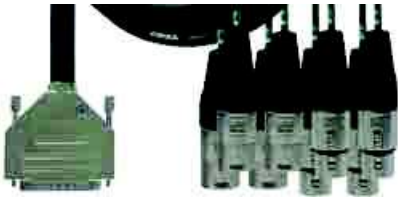

Studio
Sample Application:
Yamaha Interface Cards

Produktinformation Specification		
Kabel Cable	CMD 8	
Belegung Cable Assign	DFMY	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	D-Sub 4x XLR-male 4x XLR female	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFD 1.5 DFMY
3.00	●	CFD 3 DFMY
5.00	●	CFD 5 DFMY

CFD DDT

intro



Studio
Sample Application:
Tascam Card Connection

Produktinformation Specification		
Kabel Cable	-	
Belegung Cable Assign	-	
Steckermarke Plug Brand	-	
Stecker Plug	D-Sub D-Sub	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFD 1.5 DDT
3.00	●	CFD 3 DDT
5.00	●	CFD 5 DDT

CFD DFMT

intro



Studio
Sample Application:
Tascam Interface Cards

Produktinformation Specification		
Kabel Cable	CMD 8	
Belegung Cable Assign	DFMT	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	D-Sub 4x XLR-male 4x XLR female	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFD 1.5 DFMT
3.00	●	CFD 3 DFMT
5.00	●	CFD 5 DFMT

CFD DDTY

intro



Studio
Sample Application:
Tascam-Yamaha
Card Connection

Produktinformation Specification		
Kabel Cable	-	
Belegung Cable Assign	DDTY	
Steckermarke Plug Brand	-	
Stecker Plug	D-Sub D-Sub	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFD 1.5 DDTY
3.00	●	CFD 3 DDTY
5.00	●	CFD 5 DDTY

CCFD DFT

intro



Studio
Economy
Sample Application:
Tascam Interface Cards In

Produktinformation		Specification	
Kabel Cable	Intro cable 6		
Belegung Cable Assign	DFT		
Steckermarke Plug Brand	-		
Stecker Plug	D-Sub 8x XLR-female		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
1.50	●	CCFD 1.5 DFT	
3.00	●	CCFD 3 DFT	
5.00	●	CCFD 5 DFT	

CCFD DMT

intro



Studio
Economy
Sample Application:
Tascam Interface Cards Out

Produktinformation		Specification	
Kabel Cable	Intro cable 6		
Belegung Cable Assign	DMT		
Steckermarke Plug Brand	-		
Stecker Plug	D-Sub 8x XLR-male		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
1.50	●	CCFD 1.5 DMT	
3.00	●	CCFD 3 DMT	
5.00	●	CCFD 5 DMT	

CFD DFT

intro



Studio
Sample Application:
Tascam Interface Cards In

Produktinformation		Specification	
Kabel Cable	CMD 8		
Belegung Cable Assign	DFT		
Steckermarke Plug Brand	REAN SILVER		
Stecker Plug	D-Sub 8x XLR-female		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
1.50	●	CFD 1.5 DFT	
3.00	●	CFD 3 DFT	
5.00	●	CFD 5 DFT	

CFD DMT

intro



Studio
Sample Application:
Tascam Interface Cards Out

Produktinformation		Specification	
Kabel Cable	CMD 8		
Belegung Cable Assign	DMT		
Steckermarke Plug Brand	REAN SILVER		
Stecker Plug	D-Sub 8x XLR-male		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
1.50	●	CFD 1.5 DMT	
3.00	●	CFD 3 DMT	
5.00	●	CFD 5 DMT	

CFD DVT

intro




Studio
Sample Application:
Tascam Interface Cards

Produktinformation Specification		
Kabel Cable	CMD 8	
Belegung Cable Assign	DVT	
Steckermarke Plug Brand	REAN	
Stecker Plug	D-Sub 8x Plug 6.3 mm stereo	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFD 1.5 DVT
3.00	●	CFD 3 DVT
5.00	●	CFD 5 DVT

CFD DDA

intro

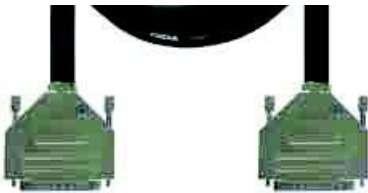

Studio
Sample Application:
Tascam Analog Assignment

Produktinformation Specification		
Kabel Cable	CMD 8	
Belegung Cable Assign	DDA	
Steckermarke Plug Brand	-	
Stecker Plug	D-Sub D-Sub	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.50	●	CFD 1.5 DDA
3.00	●	CFD 3 DDA
5.00	●	CFD 5 DDA

CFDM FM

intro



Stage

Produktinformation Specification		
Kabel Cable	CDMX 1	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	REAN SILVER	
Stecker Plug	XLR-female 3-pole XLR-male 3-pole	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.00	●	CFDM 1 FM
3.00	●	CFDM 3 FM
5.00	●	CFDM 5 FM
10.00	●	CFDM 10 FM

CPD FM

peak



Stage
Ideal for stage applications

Produktinformation Specification		
Kabel Cable	CDMX 234	
Belegung Cable Assign	FM	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	XLR-female 3-pole XLR-male 3-pole	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.50	●	CPD 0.5 FM
1.00	●	CPD 1 FM
2.00	●	CPD 2 FM
3.00	●	CPD 3 FM
5.00	●	CPD 5 FM
10.00	●	CPD 10 FM
20.00	●	CPD 20 FM

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CTOS

intro



Studio/Home

Produktinformation | Specification

Kabel Cable	optical core	
Belegung Cable Assign	TOS	
Steckermarke Plug Brand		
Stecker Plug	Toslink Toslink	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.50	●	CTOS 0.5
1.00	●	CTOS 1
2.00	●	CTOS 2
3.00	●	CTOS 3
5.00	●	CTOS 5
10.00	●	CTOS 10

CFD AA

intro



Stage/Studio
Sample Application:
Midi Connection

Produktinformation | Specification

Kabel Cable	intro cable 1	
Belegung Cable Assign	AA	
Steckermarke Plug Brand	REAN	
Stecker Plug	DIN 5 pole DIN 5 pole	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.60	●	CFD 0.6 AA
0.90	●	CFD 0.9 AA
1.80	●	CFD 1.8 AA
3.00	●	CFD 3 AA
6.00	●	CFD 6 AA
9.00	●	CFD 9 AA

CFD AA-SNOW

intro



Stage/Studio
Sample Application:
MIDI Connection

Produktinformation | Specification

Kabel Cable	intro cable 2	
Belegung Cable Assign	AA	
Steckermarke Plug Brand	REAN	
Stecker Plug	DIN 5 pole DIN 5 pole	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.80	○	CFD 1.8 AA-SNOW
3.00	○	CFD 3 AA-SNOW
6.00	○	CFD 6 AA-SNOW

CFDW BB

intro



Studio
Wordclock
MADI

Produktinformation | Specification

Kabel Cable	RG 59	
Belegung Cable Assign	BB	
Steckermarke Plug Brand		
Stecker Plug	UG 1789 U BNC UG 1789 U BNC	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.00	●	CFDW 1 BB
2.00	●	CFDW 2 BB
3.00	●	CFDW 3 BB
5.00	●	CFDW 5 BB
10.00	●	CFDW 10 BB

CPDS CC

peak



Studio/Home
Sample Application:
Digital Connection

Produktinformation Specification		
Kabel Cable	CDS 122	
Belegung Cable Assign	CC	
Steckermarke Plug Brand	REAN	
Stecker Plug	Cinch/RCA gold Cinch/RCA gold	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.00	●	CPDS 1 CC
2.00	●	CPDS 2 CC
3.00	●	CPDS 3 CC
5.00	●	CPDS 5 CC
10.00	●	CPDS 10 CC

CHDMI

intro



Stage/Studio
HDMI Highspeed

Produktinformation Specification		
Kabel Cable	-	
Belegung Cable Assign		
Steckermarke Plug Brand		
Stecker Plug	HDMI A-connector HDMI A-connector	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.00	●	CHDMI 1
3.00	●	CHDMI 3
5.00	●	CHDMI 5
10.00	●	CHDMI 10

CUSB

intro



Stage/Studio
USB 2.0

Produktinformation Specification		
Kabel Cable	-	
Belegung Cable Assign		
Steckermarke Plug Brand		
Stecker Plug	USB connector A USB connector B	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.80	●	CUSB 1.8
3.00	●	CUSB 3
5.00	●	CUSB 5

CFIREWIRE

intro



Stage/Studio
FireWire 400

Produktinformation Specification		
Kabel Cable	-	
Belegung Cable Assign		
Steckermarke Plug Brand		
Stecker Plug	FireWire 6pol. connector FireWire 6pol. connector	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.80	●	CFIREWIRE 1.8

CDX-1

peak



Stage
3 Pin Assign

Produktinformation Specification	
Kabel Cable	CDMX 1
Belegung Cable Assign	CDX1
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-female 5-pole XLR-male 5-pole
Länge Length	Farbe Colour
2.00	●
5.00	●
10.00	●
20.00	●

CDX-2

peak



Stage
5 Pin Assign
Twin Cable

Produktinformation Specification	
Kabel Cable	CDMX 2
Belegung Cable Assign	CDX2
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-female 5-pole XLR-male 5-pole
Länge Length	Farbe Colour
2.00	●
5.00	●
10.00	●
20.00	●

CFDM FM

intro



Stage

Produktinformation Specification	
Kabel Cable	CDMX 1
Belegung Cable Assign	FM
Steckermarke Plug Brand	REAN SILVER
Stecker Plug	XLR-female 3-pole XLR-male 3-pole
Länge Length	Farbe Colour
1.00	●
3.00	●
5.00	●
10.00	●

CPD FM

peak



Stage
Ideal for stage applications

Produktinformation Specification	
Kabel Cable	CDMX 234
Belegung Cable Assign	FM
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-female 3-pole XLR-male 3-pole
Länge Length	Farbe Colour
0.50	●
1.00	●
2.00	●
3.00	●
5.00	●
10.00	●
20.00	●

CPH DMX 1-5 PWR 1

peak



Stage
Efficient laying of
Power DMX connections
5-pole DMX

Produktinformation Specification	
Kabel Cable	CDP 1
Belegung Cable Assign	CPH_DMX1-5 PWR1
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR F 5-pol. / PowerCON blue A in XLR M 5-pol. / PowerCON grey B out
Länge Length	Farbe Colour
1.50	●
3.00	●
5.00	●
10.00	●

CPH DMX 1 PWR 1

peak



Stage
Efficient laying of
Power DMX connections

Produktinformation Specification	
Kabel Cable	CDP 1
Belegung Cable Assign	CPH_DMX1 PWR1
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR F 3-pol. / PowerCON blue A in XLR M 3-pol. / PowerCON grey B out
Länge Length	Farbe Colour
1.50	●
3.00	●
5.00	●
10.00	●

CPD FM 3-5

peak



Stage
Sample Application:
Classical DMX Adapter

Produktinformation Specification	
Kabel Cable	CDMX 234
Belegung Cable Assign	FM_3-5
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-female 3-pole XLR-male 5-pole
Länge Length	Farbe Colour
0.15	●

CPD FM 5-3

peak



Stage
Sample Application:
Classical DMX Adapter

Produktinformation Specification	
Kabel Cable	CDMX 234
Belegung Cable Assign	FM_5-3
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-female 5-pole XLR-male 3-pole
Länge Length	Farbe Colour
0.15	●

CPD FM-RING

peak



Stage
Sample Application:
DMX Adapter Set
CPD FM 3-5 + 5-3

Produktinformation Specification	
Kabel Cable	-
Belegung Cable Assign	
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	2x XLR-female 2x XLR-male
Länge Length	Farbe Colour
0.15	●

CDX FN 3 QUAD-DMX

peak



3 pole
Adapter 4x DMX
to 1x etherCON socket

Allows utilizing
Ethernet cable for
DMX transmission

Produktinformation Specification	
Kabel Cable	Intro cable 9
Belegung Cable Assign	F3H
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	4x XLR-female etherCON socket
Länge Length	Farbe Colour
0.70	●

CDX MN 3 QUAD-DMX

peak



3 pole
Adapter 4x DMX
to 1x etherCON socket

Allows utilizing
Ethernet cable for
DMX transmission

Produktinformation Specification	
Kabel Cable	Intro cable 9
Belegung Cable Assign	M3H
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	4x XLR-male etherCON socket
Länge Length	Farbe Colour
0.70	●

CDX FN 5 QUAD-DMX



peak

5 pole:
Adapter 4x DMX
to 1x etherCON socket

Allows utilizing
Ethernet cable for
DMX transmission

Produktinformation | Specification

Kabel Cable	Intro cable 9	
Belegung Cable Assign	F3H	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	4x XLR-female etherCON socket	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.70	●	CDX 0.7 FN 5 QUAD-DMX



CDX MN 5 QUAD-DMX



peak

5 pole
Adapter 4x DMX
to 1x etherCON socket

Allows utilizing
Ethernet cable for
DMX transmission

Produktinformation | Specification

Kabel Cable	Intro cable 9	
Belegung Cable Assign	M3H	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	4x XLR-male etherCON socket	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.70	●	CDX 0.7 MN 5 QUAD-DMX



CIT 3



peak

Stage
Sample Application:
Terminate DMX Chains

Produktinformation | Specification

Kabel Cable	-
Belegung Cable Assign	3-PIN-DMX-TERMINATOR
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-male 3-pole XLR-male 3-pole

Bestell-Nr. | Part No.
CIT 3

CIT 5



peak

Stage
Sample Application:
Terminate DMX Chains

Produktinformation | Specification

Kabel Cable	-
Belegung Cable Assign	5-PIN-DMX-TERMINATOR
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-male 5-pole XLR-male 5-pole

Bestell-Nr. | Part No.
CIT 5

CIT-SET



peak

Stage
Sample Application:
Terminator Set
CIT 3+5

Produktinformation | Specification

Kabel Cable	-
Belegung Cable Assign	
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	XLR-male 3-pole XLR-male 5-pole

Bestell-Nr. | Part No.
CIT SET

CSE NN 5

encore



Stage
Sample Application:
Controller Connection
Digital Media Network

CSE HH 5

encore



Stage
Sample Application:
Switch/Router Patchcable

Produktinformation | Specification

Kabel Cable	CCAT 5	
Belegung Cable Assign	HH	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	etherCON carrier etherCON carrier	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CSE 0.3 NN 5
0.50	●	CSE 0.5 NN 5
1.00	●	CSE 1 NN 5
2.50	●	CSE 2.5 NN 5
5.00	●	CSE 5 NN 5
10.00	●	CSE 10 NN 5
15.00	●	CSE 15 NN 5
20.00	●	CSE 20 NN 5

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

Produktinformation | Specification

Kabel Cable	CCAT 5	
Belegung Cable Assign	HH	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	RJ 45 RJ 45	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CSE 0.3 HH 5
0.50	●	CSE 0.5 HH 5
1.00	●	CSE 1 HH 5
2.50	●	CSE 2.5 HH 5
5.00	●	CSE 5 HH 5
10.00	●	CSE 10 HH 5
15.00	●	CSE 15 HH 5
20.00	●	CSE 20 HH 5

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CSE NH 5

encore



Stage
Sample Application:
Laptop to Controller

CSE NN 5 D

encore



Stage
Stagedrum Removable

Produktinformation | Specification

Kabel Cable	CCAT 5	
Belegung Cable Assign	HH	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	etherCON carrier RJ 45	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CSE 0.3 NH 5
0.50	●	CSE 0.5 NH 5
1.00	●	CSE 1 NH 5
2.50	●	CSE 2.5 NH 5
5.00	●	CSE 5 NH 5
10.00	●	CSE 10 NH 5
15.00	●	CSE 15 NH 5
20.00	●	CSE 20 NH 5

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

Produktinformation | Specification

Kabel Cable	CCAT 5	
Belegung Cable Assign	HH	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	etherCON carrier etherCON carrier	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
25.00	●	CSE 25 NN 5 D
50.00	●	CSE 50 NN 5 D
75.00	●	CSE 75 NN 5 D
100.00	●	CSE 100 NN 5 D

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CSE NN 5 SD

encore



Stage
Stagedrum 2 m
spooled outside

Produktinformation Specification	
Kabel Cable	CCAT 5
Belegung Cable Assign	HH
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	etherCON carrier etherCON carrier
Länge Length	Farbe Colour
25.00	●
50.00	●
75.00	●
100.00	●

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

Also available with lockable door.

CSE NN 5 SD 1

encore



Stage
Stagedrum with Socket

Produktinformation Specification	
Kabel Cable	CCAT 5
Belegung Cable Assign	HH
Steckermarke Plug Brand	NEUTRIK
Stecker Plug	etherCON carrier etherCON socket
Länge Length	Farbe Colour
25.00	●
50.00	●
75.00	●
100.00	●

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CSE NN 7

encore



Stage
Sample Application:
Controller Connection
Digital Media Network

Produktinformation Specification		
Kabel Cable	CCAT 7	
Belegung Cable Assign	HH	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	etherCON carrier etherCON carrier	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
5.00	●	CSE 5 NN 7
10.00	●	CSE 10 NN 7
15.00	●	CSE 15 NN 7
20.00	●	CSE 20 NN 7

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CSE NH 7

encore



Stage
Sample Application:
Laptop to Controller

Produktinformation Specification		
Kabel Cable	CCAT 7	
Belegung Cable Assign	HH	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	etherCON carrier RJ 45	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
5.00	●	CSE 5 NH 7
10.00	●	CSE 10 NH 7
15.00	●	CSE 15 NH 7
20.00	●	CSE 20 NH 7

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CSE HH 7

encore



Stage
Sample Application:
Switch/Router Patchcable

Produktinformation Specification			
Kabel Cable	CCAT 7		
Belegung Cable Assign	HH		
Steckermarke Plug Brand	NEUTRIK		
Stecker Plug	RJ 45 RJ 45		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
0.30	●	CSE 0.3 HH 7	
0.50	●	CSE 0.5 HH 7	
2.50	●	CSE 2.5 HH 7	
5.00	●	CSE 5 HH 7	
10.00	●	CSE 10 HH 7	

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CSE NN 7 D

encore



Stage
Stagedrum Removable

Produktinformation Specification			
Kabel Cable	CCAT 7		
Belegung Cable Assign	HH		
Steckermarke Plug Brand	NEUTRIK		
Stecker Plug	etherCON carrier etherCON carrier		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
25.00	●	CSE 25 NN 7 D	
50.00	●	CSE 50 NN 7 D	
75.00	●	CSE 75 NN 7 D	
100.00	●	CSE 100 NN 7 D	

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CSE NN 7 SD

encore



Stage
Stagedrum 2 m
spooled outside

Produktinformation Specification			
Kabel Cable	CCAT 7		
Belegung Cable Assign	HH		
Steckermarke Plug Brand	NEUTRIK		
Stecker Plug	etherCON carrier etherCON carrier		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
25.00	●	CSE 25 NN 7 SD	
50.00	●	CSE 50 NN 7 SD	
75.00	●	CSE 75 NN 7 SD	
100.00	●	CSE 100 NN 7 SD	

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

Also available with lockable door.

CSE NN 7 LONG-RUN-SD

encore



Stage
Stagedrum 4 m
spooled outside
Long Distance, High Speed

Produktinformation Specification			
Kabel Cable	CCAT 7A LONG-RUN		
Belegung Cable Assign	HH		
Steckermarke Plug Brand	NEUTRIK		
Stecker Plug	etherCON CAT 6A etherCON CAT 6A		
Länge Length	Farbe Colour	Bestell-Nr. Part No.	
75.00	●	CSE 75 NN 7A LONG-RUN-SD	
100.00	●	CSE 100 NN 7A LONG-RUN-SD	
125.00	●	CSE 125 NN 7A LONG-RUN-SD	
150.00	●	CSE 150 NN 7A LONG-RUN-SD	

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads



CVP BB-HD 08-32

peak



Stage
Precise Impedance
High Definition Video
Flexible

Produktinformation Specification		
Kabel Cable	CVM 08-32 HD-FLEX	
Belegung Cable Assign	BB	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Rear Twist BNC Rear Twist BNC	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
0.30	●	CVP 0.3 BB-HD 08-32
0.50	●	CVP 0.5 BB-HD 08-32
1.00	●	CVP 1 BB-HD 08-32
2.00	●	CVP 2 BB-HD 08-32
3.00	●	CVP 3 BB-HD 08-32
5.00	●	CVP 5 BB-HD 08-32
10.00	●	CVP 10 BB-HD 08-32

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CVP BB-HD 12-50 SD

peak



Stage
Flexible
Stagedrum Removable

Produktinformation Specification		
Kabel Cable	CVM 12-50 HD-FLEX	
Belegung Cable Assign	BB	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Rear Twist BNC Rear Twist BNC	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
50.00	●	CVP 50 BB-HD 12-50 SD
75.00	●	CVP 75 BB-HD 12-50 SD
100.00	●	CVP 100 BB-HD 12-50 SD

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads

CVP BB-HD 12-50

peak



Stage
Precise Impedance
High Definition Video
Flexible

Produktinformation Specification		
Kabel Cable	CVM 12-50 HD-FLEX	
Belegung Cable Assign	BB	
Steckermarke Plug Brand	NEUTRIK	
Stecker Plug	Rear Twist BNC Rear Twist BNC	
Länge Length	Farbe Colour	Bestell-Nr. Part No.
1.00	●	CVP 1 BB-HD 12-50
2.00	●	CVP 2 BB-HD 12-50
3.00	●	CVP 3 BB-HD 12-50
5.00	●	CVP 5 BB-HD 12-50
10.00	●	CVP 10 BB-HD 12-50
15.00	●	CVP 15 BB-HD 12-50
20.00	●	CVP 20 BB-HD 12-50
25.00	●	CVP 25 BB-HD 12-50

Mit zwei transparenten Schrumpfschläuchen zur freien Kennzeichnung der Kabelenden | With two transparent heat shrink tubes for free labeling of cable heads