

Starfix® ferrules and crimping tools



0376 50



0376 66



0376 87



0376 43



0376 09 + refill 0376 43



Adjustable cross-section



0376 06



0376 39



0376 92

Pack	Cat. Nos.	Ferrules with insulating flange			
		Provide an equipotential link for all the strands of a flexible conductor Active part in tinned electrolytic copper Conform to NF C 63-023			
		Single ferrules (in strips)			
		For cables cross-section (mm ²)	Colour	Strips	Ferrules
		0-25	turquoise	10	50
		0-34	green	12	40
		0-5	white	12	40
		0-75	blue	12	40
		1	red	25	40
		1-5	black	25	40
		2-5	grey	25	40
		4	orange	10	25
		6	green	10	25
		Single ferrules (individual)			
		10	brown		
		16	white		
		25	black		
		Double ferrules			
		2 x 0-75	blue		
		2 x 1	red		
		2 x 1-5	black		
		2 x 2-5	grey		

Pack	Cat. Nos.	Large capacity Starfix refills		
		Large capacity for less frequent applicator reloading Translucent packaging For direct mounting on crimping tool Cat. No. 0376 09		
		Cross-section (mm ²)	Colour	Number of ferrules per strip
		0-5	White	300
		0-75	Blue	300
		1	Red	300
		1-5	Black	300
		2-5	Grey	250


Pack	Cat. Nos.	Crimping tools for ferrules in strips	
		Cut and carry out 4-point crimping of ferrules from 0-25 to 6 mm ² in one operation Recommended for spring connections Dedicated applicator for each crimping tool for dispensing strips	
		Starfix crimping tool for 0-25 and 0-34 mm² cross-sections	
		Supplied with empty applicator fitted	
		Starfix crimping tool for 0-5 to 2-5 mm² cross-sections	
		Fitted with an adjustment wheel Supplied with empty applicator fitted	
		Assorted kit, comprising :	
		- 1 Starfix crimping tool, Cat. No. 0376 09 with empty applicator fitted	
		- 120 x 0-5 mm ² ferrules	
		- 120 x 0-75 mm ² ferrules	
		- 240 x 1 mm ² ferrules	
		- 320 x 1-5 mm ² ferrules	
		- 200 x 2-5 mm ² ferrules	
		Starfix crimping tool for 4 and 6 mm² cross-sections	
		Fitted with an adjustment wheel Supplied complete with empty applicator	
		Starfix S multi-purpose crimping tool for 0-5 to 2-5 mm² cross-sections	
		Tool cuts, strips, twists, crimps Supplied complete with 5 empty applicators For left and right-handed usage	
		Crimping tool for single and double ferrules	
		Starfix crimping tool for 0-25 to 6 mm² cross-sections	
		For 4-point crimping of ferrules from 0-25 to 6 mm ² Recommended for spring connections	
		Crimping tool with disengageable control system, crimping at end Right or left-handed	
		Starfix clamp for 10 to 50 mm² cross-section	
		Assorted kit. Supplied with :	
		- 1 tool with crimping operation control system for individual ferrules 10 to 50 mm ²	
		- 30 individual ferrules 10 mm ²	
		- 20 individual ferrules 16 mm ²	
		- 15 individual ferrules 25 mm ²	
		- 10 individual ferrules 35 mm ²	
		- 10 individual ferrules 50 mm ²	

Starfix® applicators



0376 47


0376 81

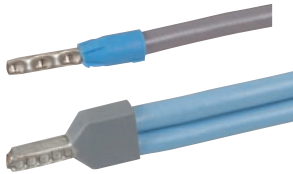

Example of single/double ferrules on cables



Example of different cables and ferrules

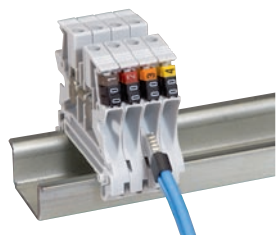

Example of use with Viking 3 terminals

Pack	Cat. Nos.	Starfix applicators
		For Starfix crimping tool
		For dispensing strips of ferrules in Starfix crimping tools Cat. Nos. 0376 08/09/10/97
		For ferrules cross-section (mm ²)
		0.25 and 0.34
		0.5 to 2.5
		4 and 6
		Colour
		yellow
		red
		orange
		For Starfix S multi-purpose crimping tool
		For dispensing colour-coded strips of ferrules
		Removable transparent cover
		For ferrules cross-section (mm ²)
		0.5
		0.75 ⁽¹⁾
		1 ⁽¹⁾
		1.5
		2.5
		Colour
		white
		blue
		red
		black
		grey

Pack	Cat. Nos.	Starfix applicators
		For Starfix crimping tool
		For dispensing strips of ferrules in Starfix crimping tools Cat. Nos. 0376 08/09/10/97
		For ferrules cross-section (mm ²)
		0.25 and 0.34
		0.5 to 2.5
		4 and 6
		Colour
		yellow
		red
		orange
		For Starfix S multi-purpose crimping tool
		For dispensing colour-coded strips of ferrules
		Removable transparent cover
		For ferrules cross-section (mm ²)
		0.5
		0.75 ⁽¹⁾
		1 ⁽¹⁾
		1.5
		2.5
		Colour
		white
		blue
		red
		black
		grey


Starfix® applicators

Correspondance table

Cross-section (mm ²)	Single ferrule	Large capacity ferrule - refills	Starfix applicator	Starfix S applicator
0.5	0376 61	0376 41	0376 47	0376 80
0.75	0376 62	0376 42	0376 47	0376 81
1	0376 63	0376 43	0376 47	0376 82
1.5	0376 64	0376 44	0376 47	0376 83
2.5	0376 66	0376 45	0376 47	0376 84


Dimensions (mm)

Single ferrules

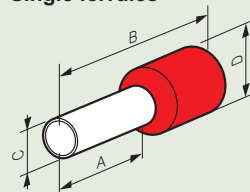

Cat. Nos.	Cross-section (mm ²)	A	B	C	D
0376 50	0.25	8	14.5	1.1	3
0376 60	0.34	8	14.5	1.1	3
0376 61	0.5	8	14.5	1.5	3.4
0376 62	0.75	8	14.5	1.5	3.4
0376 63	1	8	14.5	1.7	3.6
0376 64	1.5	8	14.5	2	4.1
0376 66	2.5	8	14.5	2.6	4.8
0376 67	4	12	21	3.2	5.7
0376 68	6	12	23	3.9	7.2
0376 69	10	12	21	4.9	8.1
0376 70	16	18	29	6.3	9.8
0376 71	25	18	31	7.9	12

Double ferrules

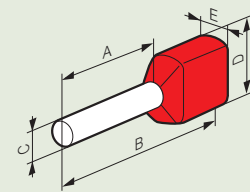

Cat. Nos.	Cross-section (mm ²)	A	B	C	D	E
0376 87	2 x 0.75	8	15	2.1	6	3.3
0376 88	2 x 1	8	15	2.35	6	4
0376 89	2 x 1.5	8	16	2.6	7.2	4.2
0376 90	2 x 2.5	10	18.5	3.3	8.4	4.8

Starfix usage example



1 Fit the applicator



2 Adjust



The 2 material handle gives an excellent grip



3 Insert the cable




4 Crimp

Starfix S usage example


Starfix S tool



1 Adjust the cross-section

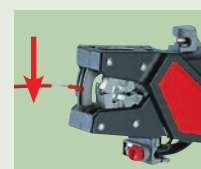

2 Strip and twist

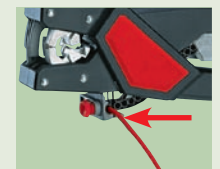

3 Crimp

(1) If Tri-rated use one size larger applicator