


# INTERCONNECTION

## Pluggable Terminal Strips Plug in Style

- Moulded in natural PA6, self extinguishing to UL94-V2 or white PA6.6, self extinguishing to UL94-V0
- Easily cut to size
- Supplied cut to length on request
- Printing available on request
- CE Approved

CTSN/MF

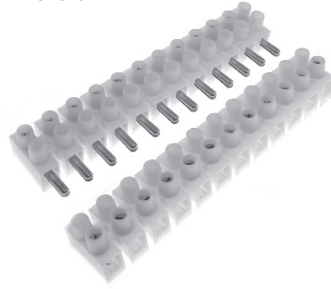

### SPECIFICATION


Voltage (max)	450V AC
Working temperature	110°C
No. of poles	12
Moulding	UL94-V2 Self extinguishing PA6 UL94-V0 Self extinguishing PA6.6
Conducting bush	Nikel plated brass
Screws	Zinc, plated steel

### UL94-V2 Material


TYPE NO.	SIZE / RATING	INSERT DIAMETER	TERMINAL SCREWS	LENGTH	WIDTH	HEIGHT	PITCH	FIXING HOLE DIAMETER	MAX
CTSN431/12MF	8mm/6A	2.9mm	M3	94mm	16mm	15.5mm	8mm	2.75mm	
CTSN433/12MF	10.25mm/10A	3.4mm	M3	119.4mm	20.5mm	16.4mm	10.25mm	3.2mm	17.5A
CTSN434/12MF	12.5mm/16A	4.3mm	M3.5	143mm	23.5mm	19mm	12.3mm	3.5mm	24A 57A

### UL94-V0 Material


TYPE NO.	SIZE / RATING	INSERT DIAMETER	TERMINAL SCREWS	LENGTH	WIDTH	HEIGHT	PITCH	FIXING HOLE DIAMETER	MAX
CTSN631/12MF	8mm/6A	2.9mm	M3	94mm	16mm	15.5mm	8mm	2.75mm	
CTSN633/12MF	10.25mm/10A	3.4mm	M3	119.4mm	20.5mm	16.4mm	10.25mm	3.2mm	17.5A
CTSN634/12MF	12.5mm/16A	4.3mm	M3.5	143mm	23.5mm	19mm	12.3mm	3.5mm	24A 57A

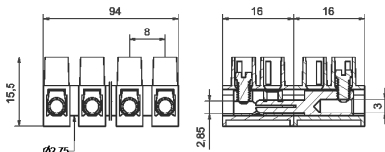

CTSN431/12MF

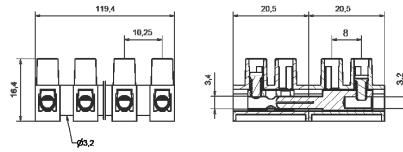

CTSN433/12MF



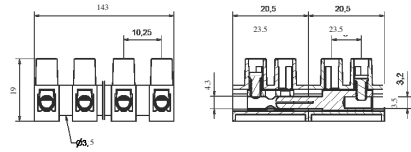


CTSN434/12MF


### Strain relief

- Clamps external conductors in lighting fixtures according to EN60598
- Natural colour PA6
- Takes the strain on the wires
- Prevents conductors from twisting
- Protects wire coating from abrasion and friction

CSR

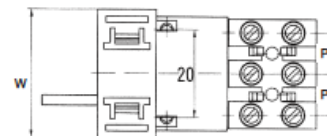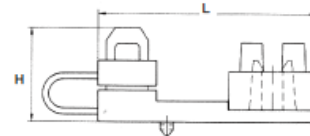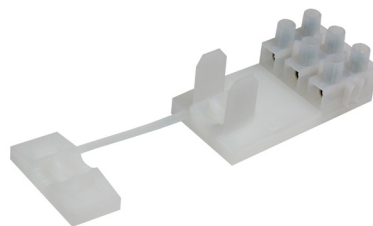

TYPE NO.	TERMINAL STRIP	LENGTH	WIDTH	HEIGHT
CSR1	CTSN431	49.5mm	31mm	22.5mm
CSR2	CTSN433 / CTSN433T	52.5mm	31mm	22.5mm
CSR3	CTSN434	54.5mm	31mm	22.5mm

 

Maximum plate thickness 1mm