


Cabinets - NOVASTAR

Depth members

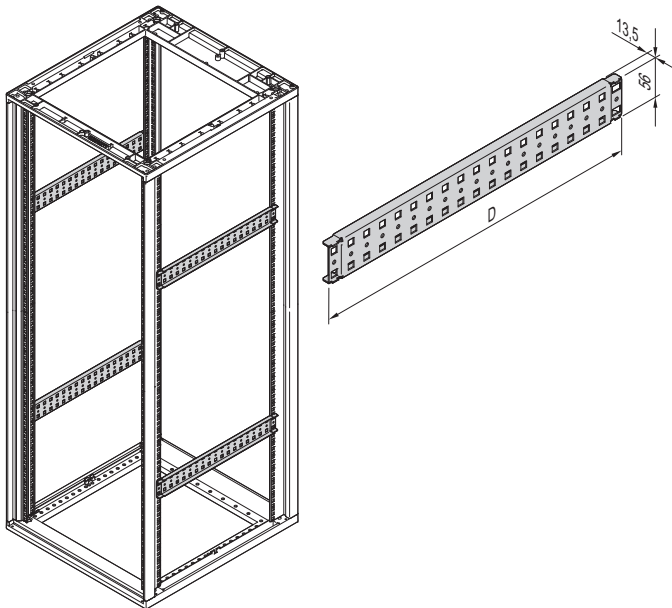

07011112

07011114

- For assembly on cabinet uprights
- Adjustable in 1 U increments
- Finish ALZn


Order Information

For cabinet depth mm	D mm	Part no.
500	366	27230-121
600	466	27230-122
800	666	27230-123



For further information www.schroff.biz/oneclick
oneClick search code = Part no.

19" panel/slide mounts with universal perforation grid (EIA)

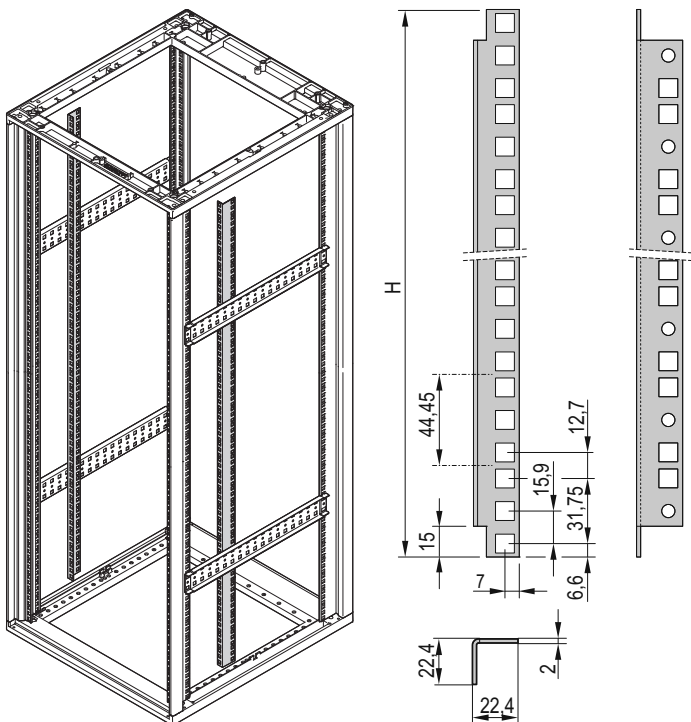

07011111

07011115

19" panel/slide mount mounted
on depth members

- For fitting to depth members (25 mm grid)
- For recessed installation of 19" components
- Load-carrying capacity 400 kg
- Slide rails can be fitted
- A partial-height 19" mounting is possible with short 19" panel/slide mounts

Delivery comprises

Item	Qty	Description
1	2	19" panel/slide mount, St, 2 mm, RAL 7021
2	1	Assembly kit

Order Information

For cabinet height U	Usable height mm	H mm	Part no.
Partial-height mounting	6	267	27230-200
9	456	400	27230-201
12	589	534	27230-202
16	767	712	27230-203
20	945	889	27230-204
25	1167	1112	27230-205
34	1567	1512	27230-206
38	1745	1690	27230-207
43	1967	1912	27230-208
47	2145	2090	27230-209

- Slide rails see page 1.252
- Depth members are required for fitting, see page 1.251



For further information www.schroff.biz/oneclick
oneClick search code = Part no.