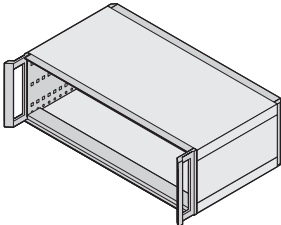
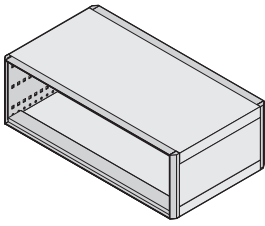
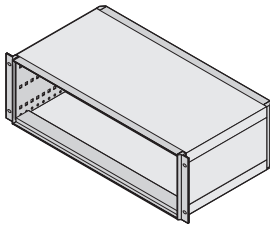


# Desk-top cases - *ratiopac* PRO

## ratiopacPRO cases

### Order Information

	Width w HP	Depth D mm	Case height H						
			2 U	3 U	4 U	5 U	6 U		
			Part no.	Part no.	Part no.	Part no.	Part no.		
			Side panel subdivision (1 U-3 U-1 U)		Side panel subdivision (3 U-2 U)				
					1	3			
					3	2			
					1				
	<b>with front handles</b>	28	255.5		24571-702	24571-750	24572-213	24572-357	24571-798
		28	315.5		24571-705	24571-753	24572-216	24572-360	24571-801
		42	255.5		24571-714	24571-762	24572-225	24572-369	24571-810
		42	315.5		24571-717	24571-765	24572-228	24572-372	24571-813
		42	375.5		24571-718	24571-766	24572-229	24572-373	24571-814
		63	255.5		24571-726	24571-774	24572-237	24572-381	24571-822
		63	315.5		24571-729	24571-777	24572-240	24572-384	24571-825
		63	375.5		24571-730	24571-778	24572-241	24572-385	24571-826
		84	255.5		24571-738	24571-786	24572-249	24572-393	24571-834
		84	315.5		24571-741	24571-789	24572-252	24572-396	24571-837
		84	375.5		24571-742	24571-790	24572-253	24572-397	24571-838
		84	435.5		24571-743	24571-791	24572-254	24572-398	24571-839
	RPPR6630	84	495.5		24571-744	24571-792	24572-255	24572-399	24571-840
	<b>with cover strips</b>	28	255.5	24572-500	24571-002	24571-050	24572-117	24572-261	24571-098
		28	315.5	24572-503	24571-005	24571-053	24572-120	24572-264	24571-101
		42	255.5	24572-510	24571-014	24571-062	24572-129	24572-273	24571-110
		42	315.5	24572-513	24571-017	24571-065	24572-132	24572-276	24571-113
		42	375.5	24572-514	24571-018	24571-066	24572-133	24572-277	24571-114
		63	255.5	24572-520	24571-026	24571-074	24572-141	24572-285	24571-122
		63	315.5	24572-523	24571-029	24571-077	24572-144	24572-288	24571-125
		63	375.5	24572-524	24571-030	24571-078	24572-145	24572-289	24571-126
		84	255.5	24572-530	24571-038	24571-086	24572-153	24572-297	24571-134
		84	315.5	24572-533	24571-041	24571-089	24572-156	24572-300	24571-137
		84	375.5	24572-534	24571-042	24571-090	24572-157	24572-301	24571-138
		84	435.5	24572-535	24571-043	24571-091	24572-158	24572-302	24571-139
	RPPR6629	84	495.5	24572-536	24571-044	24571-092	24572-159	24572-303	24571-140
	<b>with 19" mounting bracket</b>	84	255.5	24572-570	24571-438	24571-486	24572-201	24572-345	24571-534
		84	315.5	24572-573	24571-441	24571-489	24572-204	24572-348	24571-537
		84	375.5	24572-574	24571-442	24571-490	24572-205	24572-349	24571-538
		84	435.5	24572-575	24571-443	24571-491	24572-206	24572-350	24571-539
	RPPR6631	84	495.5	24572-576	24571-444	24571-492	24572-207	24572-351	24571-540

#### Note

- Dimension drawings and mounting depths see page 5.9
- Components see page 5.18