

## Climate control – Accessories

### Heaters from 30 W to 150 W




01102004

- Radiator heater (without fan)
- Simple and fast assembly with clip-on attachment and press-on terminal connection
- Wide input voltage range 110 ... 250 V<sub>AC</sub>
- Temperature limiting with PTC resistor



**Delivery comprises** (completely assembled)

Item	Qty	Description
1	1	Heater element, voltage range 110 ... 250 V <sub>AC</sub> ; resistor (PTC) self-regulating
2	1	Heating body, Al extrusion, anodised Fixing: clip for 35 mm DIN rail EN 50022
3	1	Connection: type 30, with connecting cable (3 x 0.5 mm <sup>2</sup> , 300 mm long, black); type 45, 100, 150 with press-on terminal connection (for stranded/rigid wire 3 x 0.5 ... 2.5 mm <sup>2</sup> )

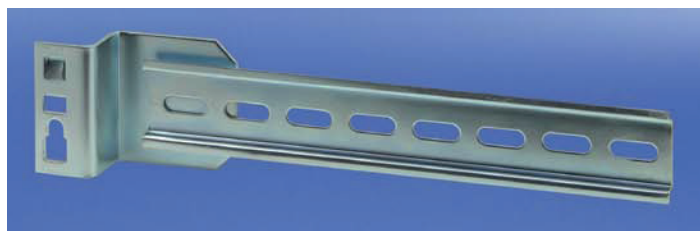

00508013

Support rail

### Order Information

Description	30 Part no.	45 Part no.	100 Part no.	150 Part no.
Heaters from 30 W to 150 W	<b>60715-020</b>	<b>60715-021</b>	<b>60715-023</b>	<b>60715-030</b>
Support rail DIN rail EN 50022 (35 mm), length 215 mm, 1 piece				<b>20715-001</b>

### Technical data

	30 W	45 W	100 W	150 W
Heater output in W	30	45	100	150
Surface temperature in °C	approx. 100	approx. 105	approx. 130	approx. 140
Max. switch-on current in A	3,0	3,5	4,0	9,0
Type of protection	IP 54	IP 20	IP 20	IP 20
Class of protection	I	I	I	I
Dimensions h × w × d in mm	65 × 50 × 25	65 × 70 × 25	140 × 70 × 25	220 × 70 × 25
Weight in kg	0.2	0.3	0.5	0.7
Test seal	VDE, CE, UL (File E150057)	CE, UL (File E150057)	CE, UL (File E150057)	CE, UL (File E150057)
Assembly	Clip-on attachment for 35 mm DIN rail (EN 50022)			

### Note

- Thermostat for heating see page 4.63
- Hygostat see page 4.66



For further information [www.schroff.biz/oneclick](http://www.schroff.biz/oneclick)  
oneClick search code = Part no.