

SIMBOX UNIVERSAL WP WALL-MOUNTED DB SM, IP 65 1ROW, 4MW, W/O TERMINAL STRIP



Figure similar

Model		
product brand name		SIVACON
Design of the cap/top cover		closed
Design of the product / EMC version		No
Protection class		
Protection class IP		IP65
Appearance		
Color		grey
Product details		
Product component		
• DIN mounting panel		Yes
• Mounting plate		No
• transparent cover		Yes
Product expansion / optional / Side-by-side mounting		No
Number		
Number of rows		1
Mechanical Design		
Height	mm	210
Width	mm	143
Depth	mm	100
Installation depth	mm	70
Number of width units		4
Mounting type		assembly

Material / of the enclosure

others

Certificates

General Product Approval

Declaration of
Conformity

Test Certificates



[Type Test
Certificates/Test Report](#)

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/8GB13710>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/8GB13710/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mfb=8GB13710

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://ausschreibungstexte.siemens.com/tiplv>

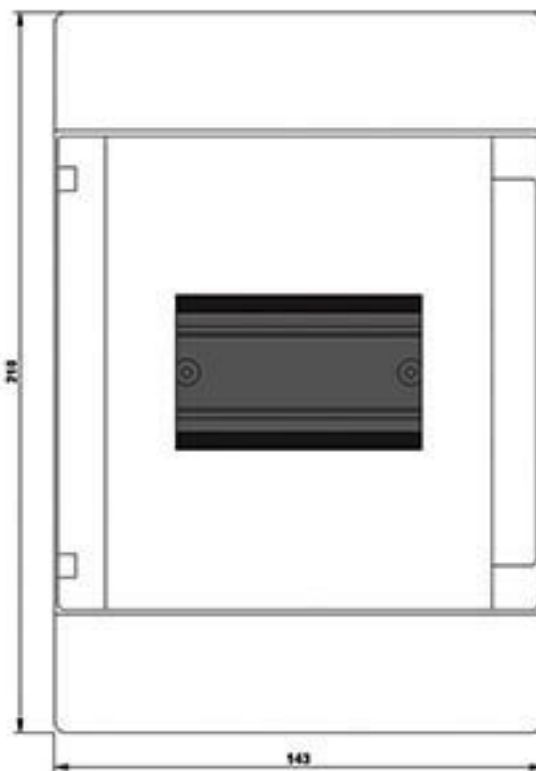

last modified:

05.05.2015