


TBS partnumber : SP-DSR-012

COILED CABLE MEASUREMENTS

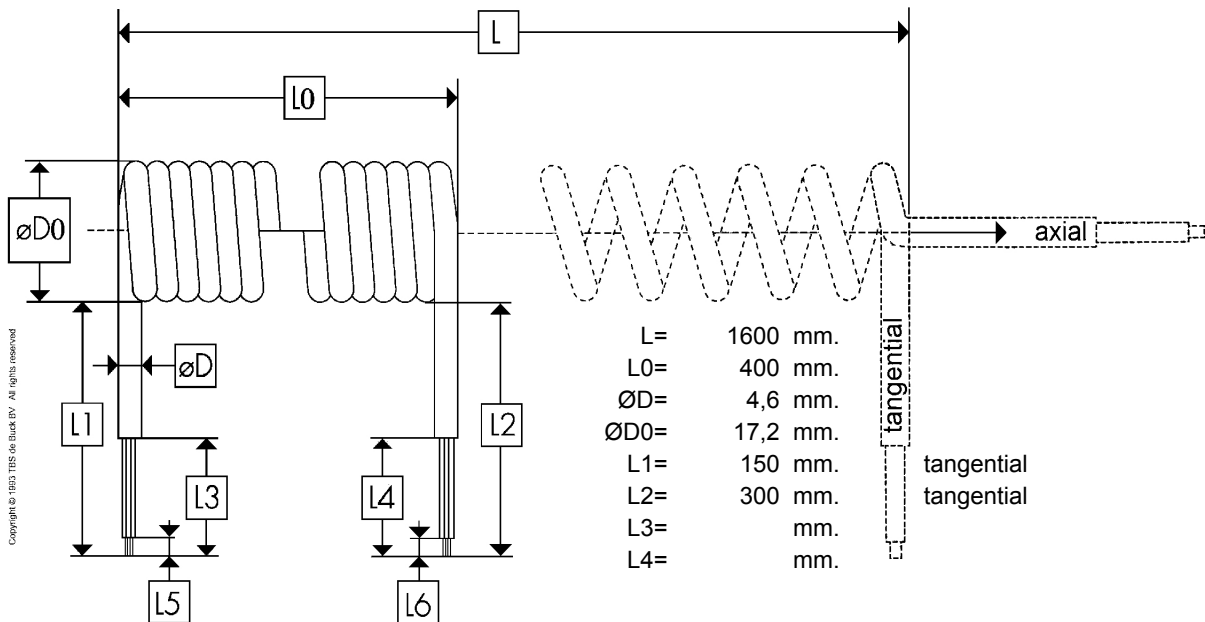

CABLE SPECIFICATION

Cable type : LiF12YD11Y 5x0,14 mm² TB50 FLEX, 18x0,10 mm bare copper wires
 Conductor insulation : TPE-E
 Conductor colours : according to DIN 47100
 Shielding : by a lap of 0,10 mm tinned copper wires
 Overall sheath : PUR Colour : black
 Temperature range : -25 °C to +70 °C
 Weight : ± 0,12 kg/pc

Tolerances ± 10% unless stated otherwise

In all cases in which we act as offeror or supplier, our offers, assignments given to us and agreements concluded with us are subject to the METAALUNIE TERMS AND CONDITIONS. These terms and conditions have been filed at the Registry of the Rotterdam District Court.

The Best Solution
 De Slof 2 5107 RJ Dongen
 The Netherlands
 V.A.T.-nr.: NL 815889215B01

HR Eindhoven nr.: 18048791
 Rabobank Tilburg nr.: 1255.77.397
 IBAN code : NL 12 RABO 0125577397
 BIC code : RABONL2U

Phone : +31 (0) 162 523 436
 Fax : +31 (0) 162 519 993
 E-mail : sales@the-best-solution.com
 Internet : www.the-best-solution.com