


HARTING RJ Industrial® 10G
field-installable RJ45 plug
part.-no.: 09 45 151 1561

HARTING Technologiegruppe
Marienwerderstr. 3
D-32339 Espelkamp



Pushing Performance

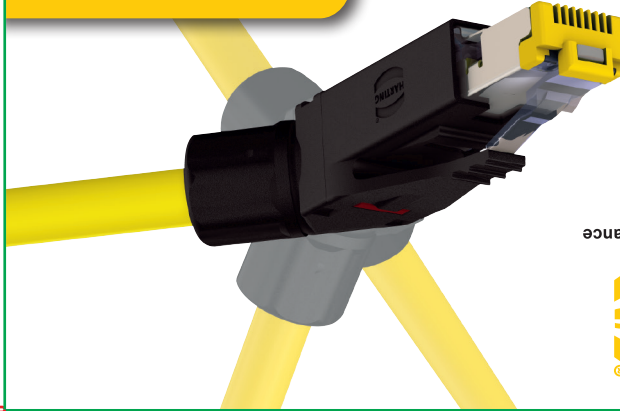

09 45 151 1561.99.00
Version 1.0-2011-07

1 pcs.



09451511561

Made in Romania

**HARTING RJ Industrial® 10G RJ45 connector
45° angled**

- 4 different cable outlets possible
- Robust industrial design
- Fully-shielded
- Field-installable with IDC technology
- For solid and stranded conductors
AWG 27 up to AWG 22
- max. wire diameter 1.6 mm Ø
- Cable diameter 4.5 up to 8 mm
- Degree of protection IP20
- Cat. 6, performance class E_A
suitable for 1 / 10 Gigabit Ethernet
- Temperature range -40 °C up to +70 °C
- 750 mating cycles



**HARTING RJ Industrial® 10G RJ45 Steckverbinder
45° gewinkelt**


- 4 unterschiedliche Kabelabgangsrichtungen möglich
- Stabiles industriegerechtes Design
- Voll geschirmt
- Feldkonfektionierbar mittels IDC-Technologie
- Für Massiv- und Litzenleiter
AWG 27 bis AWG 22
- max. Aderndurchmesser 1,6 mm Ø
- Kabeldurchmesser 4,5 bis zu 8 mm
- Schutzart IP20
- Kat. 6, Übertragungsklasse E_A
geeignet für 1 / 10 Gigabit Ethernet
- Temperaturbereich -40 °C bis +70 °C
- 750 Steckzyklen

www.HARTING.com

People | Power | Partnership

HARTING RJ Industrial® 10G
field-installable RJ45 plug
45° angled

Assembly instruction/ Montageanleitung

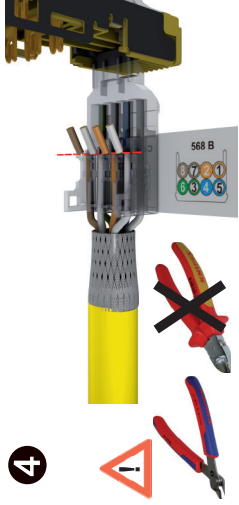

Video assembly instruction/
Video Montageanleitung:
www.HARTING.com/RJIndustrial10G

