

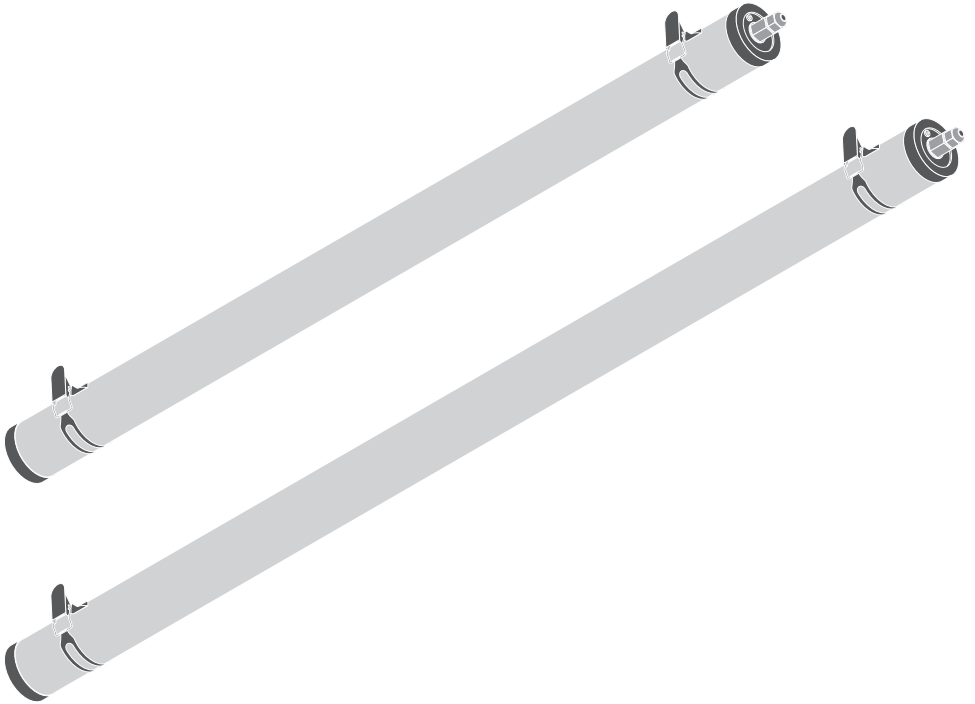
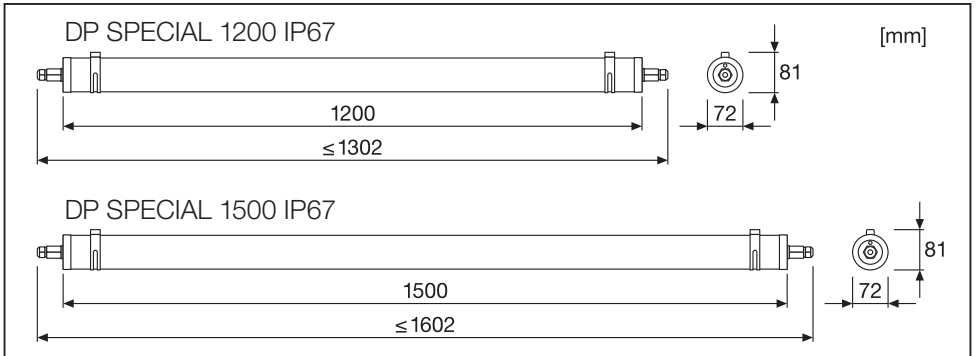


 

 

DAMPPROOF SPECIAL








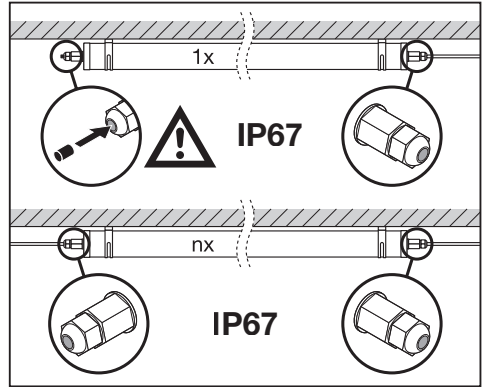










	EAN	ø x l [mm]	W	lm	lm/W	K	IP	IK
DP SPECIAL 1200 36W/4000K IP67	4058075136250	72 x 1200	36	5400	150	4000	67 / 69K	06
DP SPECIAL 1500 48W/4000K IP67	4058075136274	72 x 1500	48	7200	150	4000	67 / 69K	06

	EAN	⊖ (°C)	V _{AC}	Hz	∇	PF	R _a	👤
DP SPECIAL 1200 36W/4000K IP67	4058075136250	-20 ... +40	220-240V	50/60 Hz	120°	≥ 0.95	> 80	1.8 kg
DP SPECIAL 1500 48W/4000K IP67	4058075136274	-20 ... +40	220-240V	50/60 Hz	120°	≥ 0.95	> 80	2.2 kg

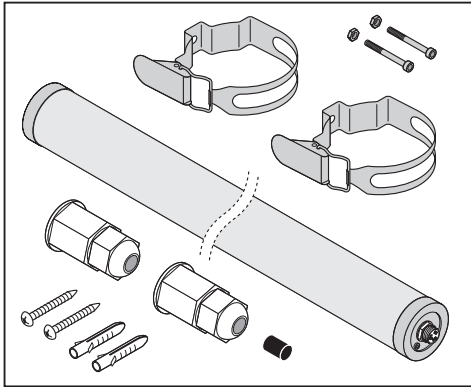

n	B10 	C10 	C16 
DP SPECIAL 1200 36W IP67	15	17	28
DP SPECIAL 1500 48W IP67	6	7	12
 	3x1.5mm ²	3x1.5mm ²	3x1.5mm ²

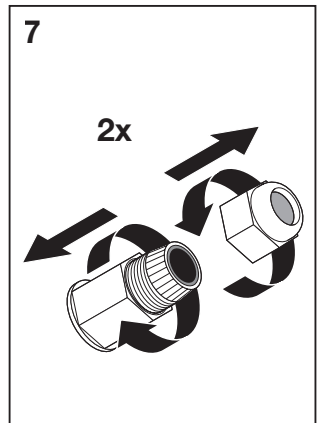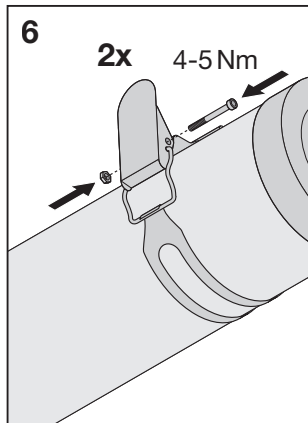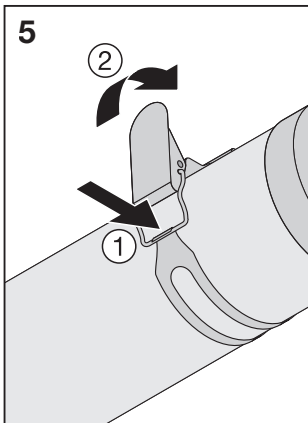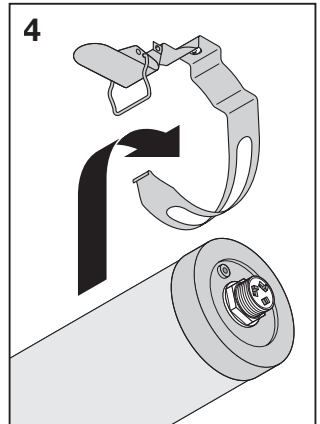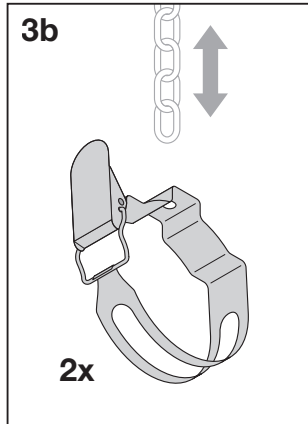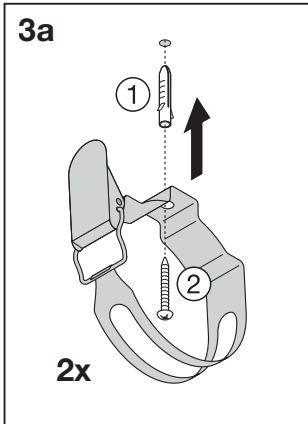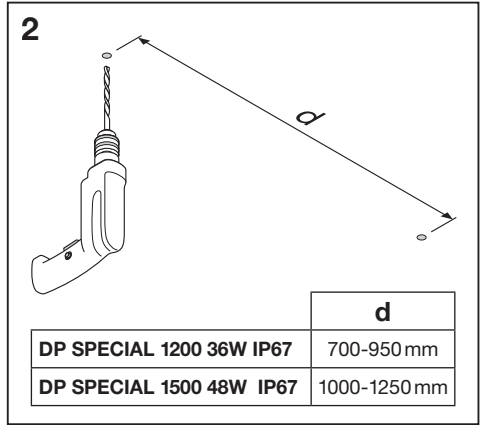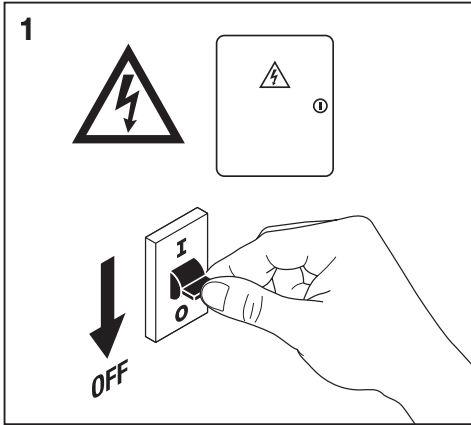

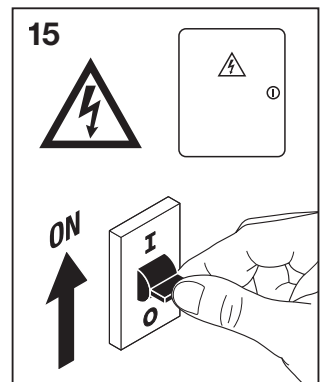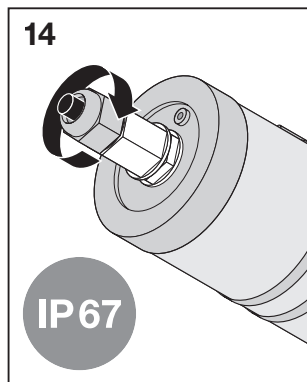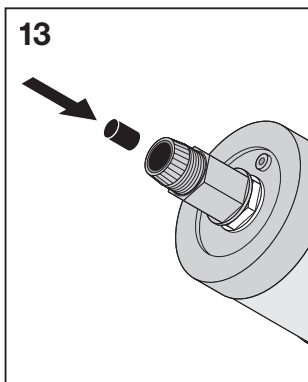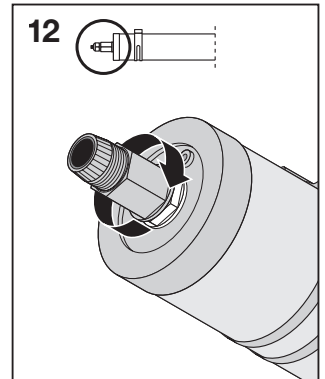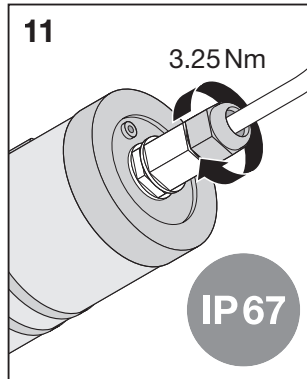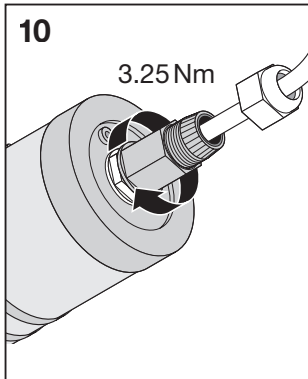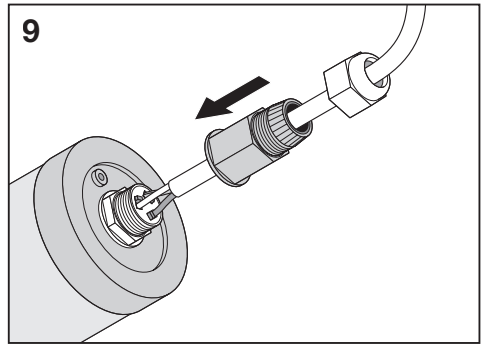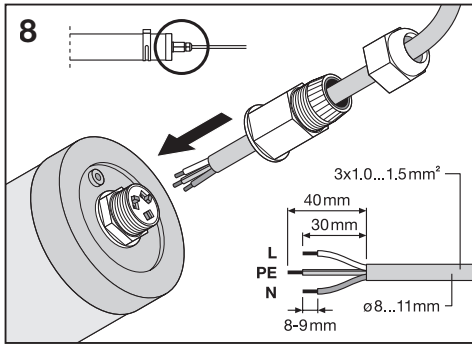

C10449057
G11053346
27.08.18



LEDVANCE GmbH
Steinerne Furt 62
86167 Augsburg, Germany
www.ledvance.com