



IDEAL NETWORKS

NavITEK NT (Plus/Pro)






Quick Reference Guide
151835 Issue 2

© IDEAL INDUSTRIES Ltd 2015

A subsidiary of IDEAL INDUSTRIES INC.



IDEAL INDUSTRIES, INC.

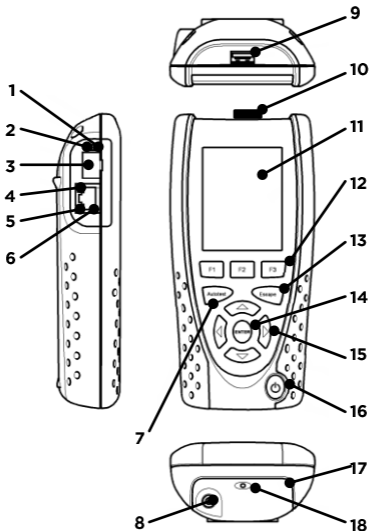


- 1 Optical link LED (Pro only)
- 2 Optical activity LED (Pro only)
- 3 Optical port (SFP) (Pro only)
- 4 Ethernet LED
- 5 Activity LED
- 6 Cable socket
- 7 Autotest button
- 8 DC in connector
- 9 USB socket
- 10 Wi-Fi adapter
- 11 Display
- 12 Function buttons
- 13 Escape button
- 14 ENTER button
- 15 Cursor buttons
- 16 Power button
- 17 Battery module
- 18 Charging indicator LED

Charging Indicator LED (18)	Status
Green	Charging
Off	Charging complete
Flashing	Not charging

Three Ways to Navigate

A

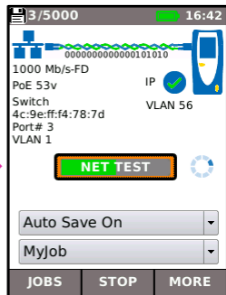



B





Escape - returns to previous screen

ENTER - accepts selection

C

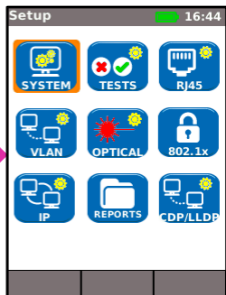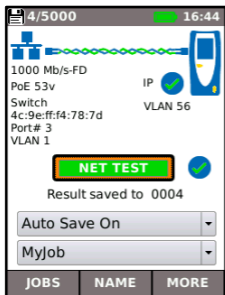


Job Setup

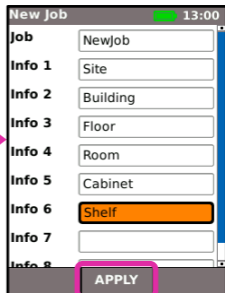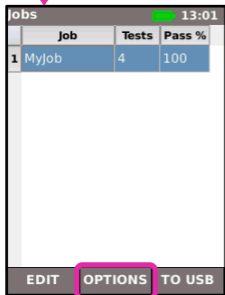

Cable Testing

MORE
SETUP

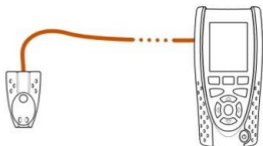

Test 14:39

Cable Type **4-Pair 568B**


Shield Type UTP/STP

Use Custom NVP

Custom NVP (%) 70

1 2 3 4 5 6 7 8 S

APPLY

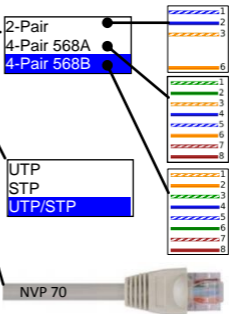

2/5000 18:32

01

Wiremap

Auto Save On

Myjob

JOB'S STOP MORE

Wiremap 18:32

STRAIGHT


4-Pair 568B UTP/STP

1 1 5m
2 2 5m
3 3 5m
4 4 5m
5 5 5m
6 6 5m
7 7 4m
8 8 4m
S S



01 4m

RUN SETUP

Network Testing over Copper

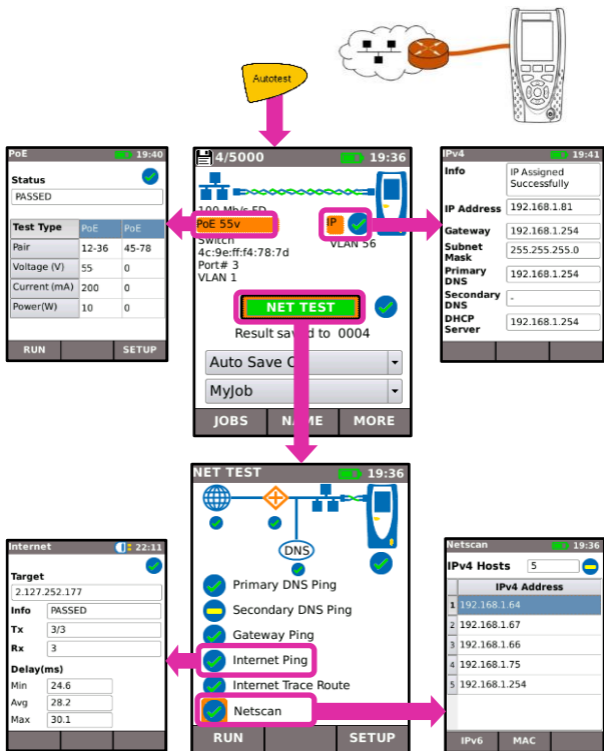

Network Testing over Fiber (Pro only)

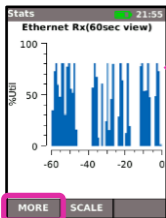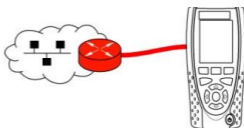

VLAN 00:59

Max Rx Bandwidth (Mb/s)
743.504

Detected VLAN IDs
20, 35

VLAN ID 50

Change VLAN 20

MORE APPLY

4/5000 19:36

Opt 1000 Mb/s
Rx Pwr: -4.13 dB
JU:23:47:cb:3b:3f
ProCurve 2910al-24G-f
Port# 1
VLAN -

NET TEST

Result saved to 0004

Auto Save On

MyJob

JOB NAME MORE

19:40

System Name: ProCurve
2910al-24G-PoE Switch
System Description: ProCurve
J9146A 2910al-24G-PoE Switch
IP Address: -
Port Address:
00:23:47:cb:3b:3f
Port Description: 1
Capabilities: B
VLAN: -

Optical 12:13

Status
Available

Vendor
AVAGO


Part No.
AFBR-57L5APZ

Rx Pwr (dBm)
-4.13

Tx Pwr (dBm)
-5.11

Test Reports

5 tests are saved /
memory capacity
is 5000 tests

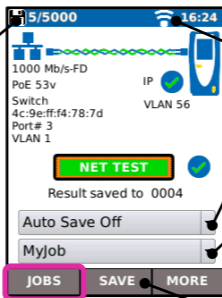


Indicates Wi-Fi
is enabled

Select result
saving mode

Select current
Job

Save the result
manually when
Auto Save is Off

View
result

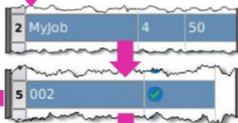

Select job


Select result



OR Save
report to
USB

OR Smartphone
downloads reports using
IDEAL AnyWARE™
app. for Android™ /
Apple

TO USB

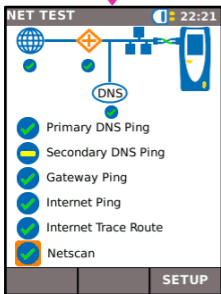

Apple is a trademark of Apple Inc., registered in the
U.S. and other countries.

Android is a trademark of Google Inc.

Menu Map

