



2745Z0

Headlamp

Peli™ safety approved headlamps are designed for use in hazardous environments. It is not only Zone 0 (Category 1) approved but also is ultra compact and lightweight. Equipped with three LEDs, it produces up to 33 lumens and provides up to 40 hours of run time and offers multiple modes (high, low, flashing). The Peli 2745Z0 is available in two colours (yellow or black) and includes both cloth and rubber straps for a variety of head / helmet applications. Count on Peli to bring you the best in lighting design and technology.

The Peli™ 2745Z0 headlight: Guiding you safely through the danger zone.



DIMENSIONS

Length 2.25" (5.7 cm)

MATERIALS

Body Anti-static Impact Modified PC/PBT
O-Ring Over-molded TPR
Lens Polycarbonate (PC)
Shroud Anti-static Impact Modified PC/PBT

COLOURS

■ Black ■ High Visibility Yellow

LIGHT SPECS

Lamp Type LED

POWER

Battery Size AAA
Battery Type Alkaline
Battery Quantity 3
Batteries Included yes
Volts 4.5v

WEIGHT

Weight With Batteries 3.3 oz (94 gr)
Weight Without Batteries 2.0 oz (57 gr)

SWITCH

Switch Type Push Button
Light Modes High / Low

CERTIFICATIONS

ATEX Zone 0



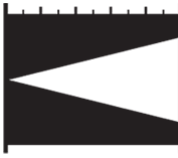


OTHER

Minimum Pack 1

Peli

c/ Provença, 388, Planta 7 • Barcelona, Spain 08025 • Phone: +34 934 674 999

info@peli.com www.peli.com

FL1 STANDARD	HIGH	LOW
	33 LUMENS	17 LUMENS
	20h 0mins	40h 0mins
	35m	25m
	309cd	155cd
	IP54	

ACCESSORIES