

SEK CAB FLAT SH RND AWG28/7 09P 30,48m

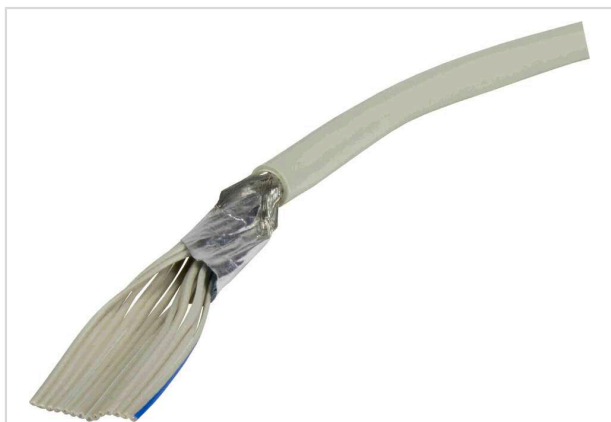


Image is for illustration purposes only. Please refer to product description.

Part number	09 18 009 7007
Specification	SEK CAB FLAT SH RND AWG28/7 09P 30,48m
HARTING eCatalogue	https://b2b.harting.com/09180097007

Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	Copper cable (round)

Version

Cable length	30.48 m
Number of cores	9
Core structure	AWG 28/7
Shielding	Shielded

Technical characteristics

Impedance	100 Ω
Limiting temperature	-30 ... +75 °C unmoved -20 ... +75 °C moved
Conductor resistance @ 20 °C	$\leq 216 \Omega/\text{km}$

Material properties

Material (cable)	PVC
Colour (cable)	Grey
RoHS	compliant
ELV status	compliant
China RoHS	e



Pushing Performance
Since 1945

Material properties

REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Specifications and approvals

Specifications	UL 1581 UL PLCC, CL2
CE	Yes

Commercial data

Packaging size	1
Net weight	1,695 g
Net weight	55 g/m
Country of origin	Germany
European customs tariff number	85444993
GTIN	5713140024267
ETIM	EC003249
eCl@ss	27061801 Data and communication cable (copper)