


EMUG 50 BK

Locknut, polyamide, RAL 9005, M50

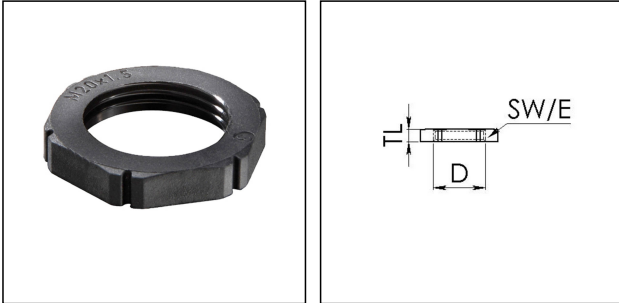

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.



Material	Polyamide, fibre reinforced
Temp. range min	-40 °C
Temp. range max	100 °C
Glow wire test	650 °C
Thread type	M
Ø Connection thread D	50
Lead	1,5
Total length TL	7 mm
Key width SW	60 mm
Collar diameter (E)	67 mm
Product Color	RAL 9005
Order no. RAL 9005	10061786
Type	EMUG 50 BK
Packing unit	25
EAN number	4007685617864
Tariff number	39269097
ETIM-Classification	EC000940

14.02.2024

Your Contact:

WISKA Hoppmann GmbH

Kisdorfer Weg 28 · 24568 Kaltenkirchen · Germany

☎ +49-4191-508-0 · 📠 +49-4191-508-209

contact@wiska.de · www.wiska.com



Your Contact:

WISKA Hoppmann GmbH

Kisdorfer Weg 28 · 24568 Kaltenkirchen · Germany

☎ +49-4191-508-0 · 📠 +49-4191-508-209

contact@wiska.de · www.wiska.com