


MVS 9

Stop end, brass

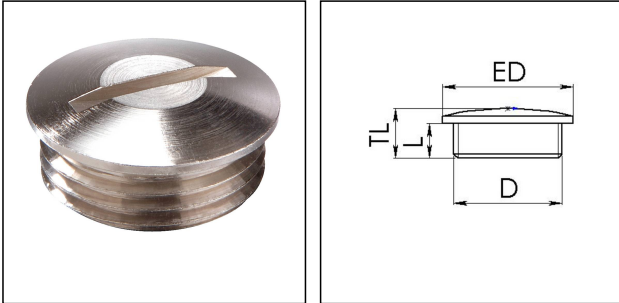

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.



| | |
|---------------------------------|-----------------------|
| Material | Brass nickel-plated |
| Surface | Nickel-plated |
| Temp. range min | -200 °C |
| Temp. range max | 250 °C |
| Protection class | IP54 |
| Thread type | PG |
| Ø Connection thread D | 9 |
| Length screw-in thread L | 6 mm |
| External diameter ED | 17 mm |
| Total length TL | 9 mm |
| Advice | with O-ring IP66/IP68 |
| Order no. nickel-plated | 10062152 |
| Type | MVS 9 |
| Packing unit | 100 |
| EAN number | 4007685621526 |
| Tariff number | 74198090 |
| ETIM-Classification | EC000032 |

Recommended accessories

| | |
|--------------|----------|
| MMU 9 | 10062142 |
|--------------|----------|

16.08.2023


Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

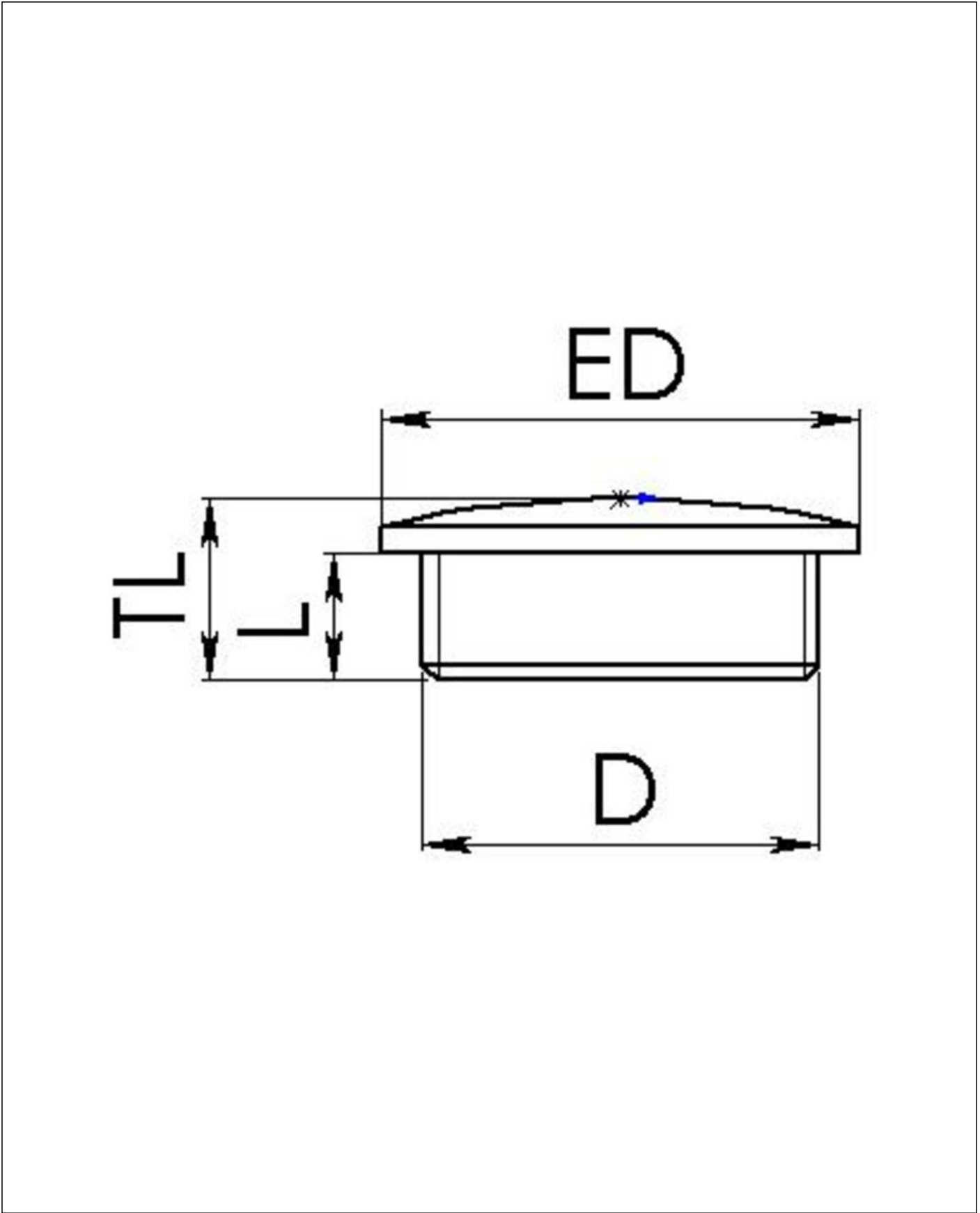

Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

Other technical data on request / subject to change without notice