


MRM 25/20

Reduction adaptor, brass

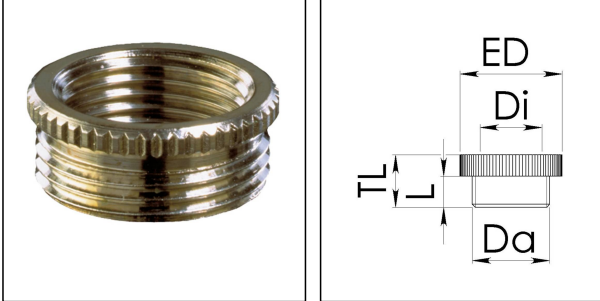

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.



Material	Brass nickel-plated
Temp. range min	-200 °C
Temp. range max	250 °C
Thread type outer	M
Ø outer thread	25
Lead outer	1,5
Length screw-in thread L	7 mm
Thread type inner	M
Ø inner thread	20
Lead inner	1,5
External diameter ED	30 mm
Total length TL	10 mm
Surface	Nickel-plated
Order no. nickel-plated	10063944
Type	MRM 25/20
Packing unit	100
EAN number	4007685639446
Tariff number	74198090
ETIM-Classification	EC000938

Recommended accessories

EMMU 25	10063144
ORD-E 25	10064700

Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708



info@wiska.co.uk · www.wiska.co.uk

16.08.2023


Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

 +44-12-08816062 ·  +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

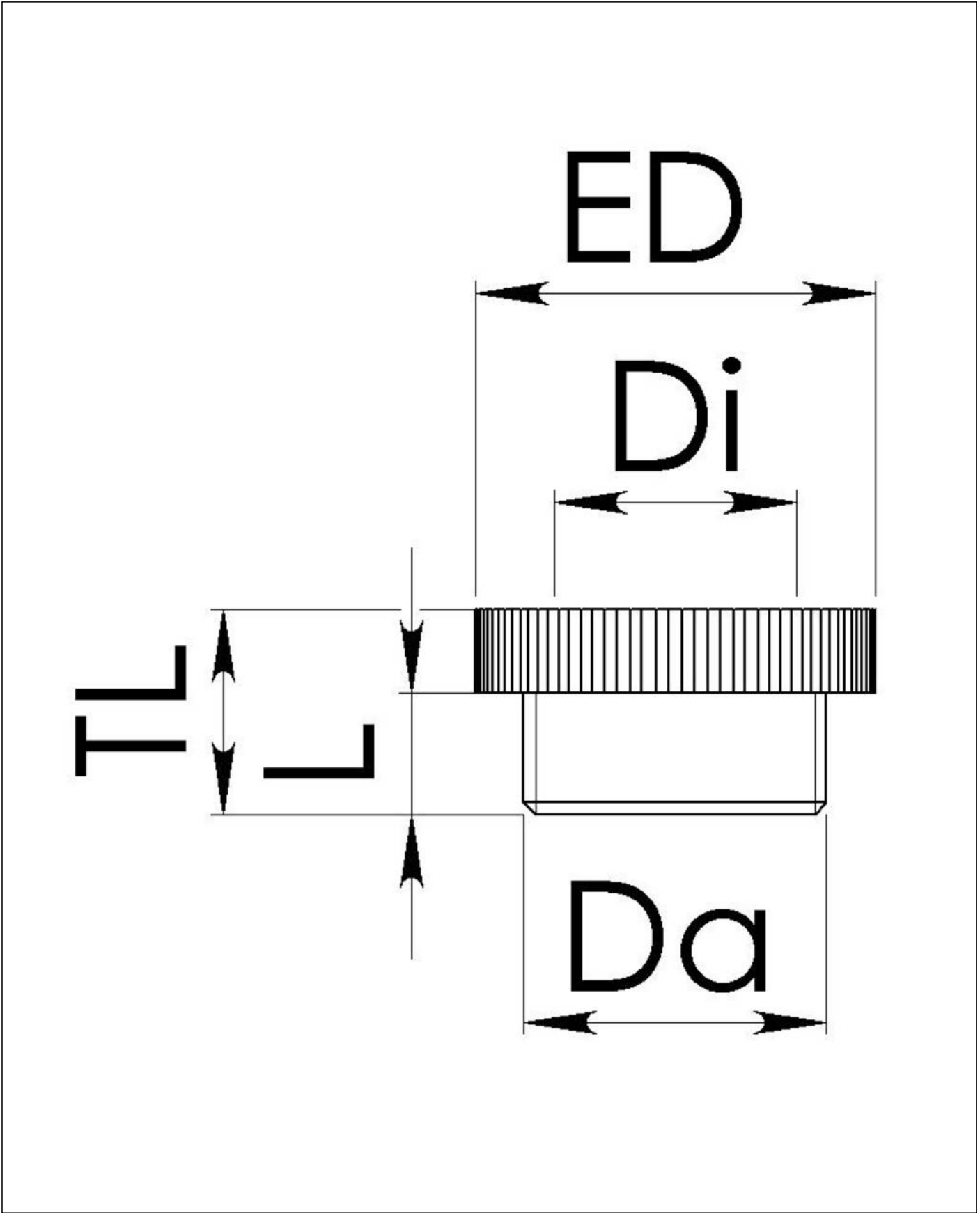

Your Contact:
WISKA UK Ltd.
Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain
☎ +44-12-08816062 · 📠 +44-12-08816708
info@wiska.co.uk · www.wiska.co.uk

Other technical data on request / subject to change without notice