


EMVS-ORD 20

Stop end, brass with O-Ring

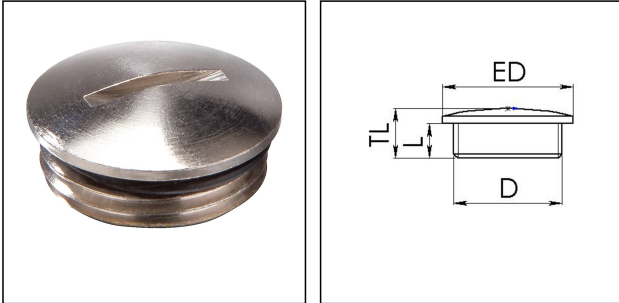

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.



Material	Brass nickel-plated
Surface	Nickel-plated
Temp. range min	-40 °C
Temp. range max	120 °C
Protection class	IP66 / IP68 (5 bar 30 min)
Thread type	M
Ø Connection thread D	20
Lead	1,5
Length screw-in thread L	6,5 mm
External diameter ED	22 mm
Total length TL	9,5 mm
Order no. nickel-plated	10065082
Type	EMVS-ORD 20
Packing unit	100
EAN number	4007685650823
Tariff number	74198090
ETIM-Classification	EC000032

Recommended accessories

EMMU 20	10063143
----------------	----------

16.08.2023


Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

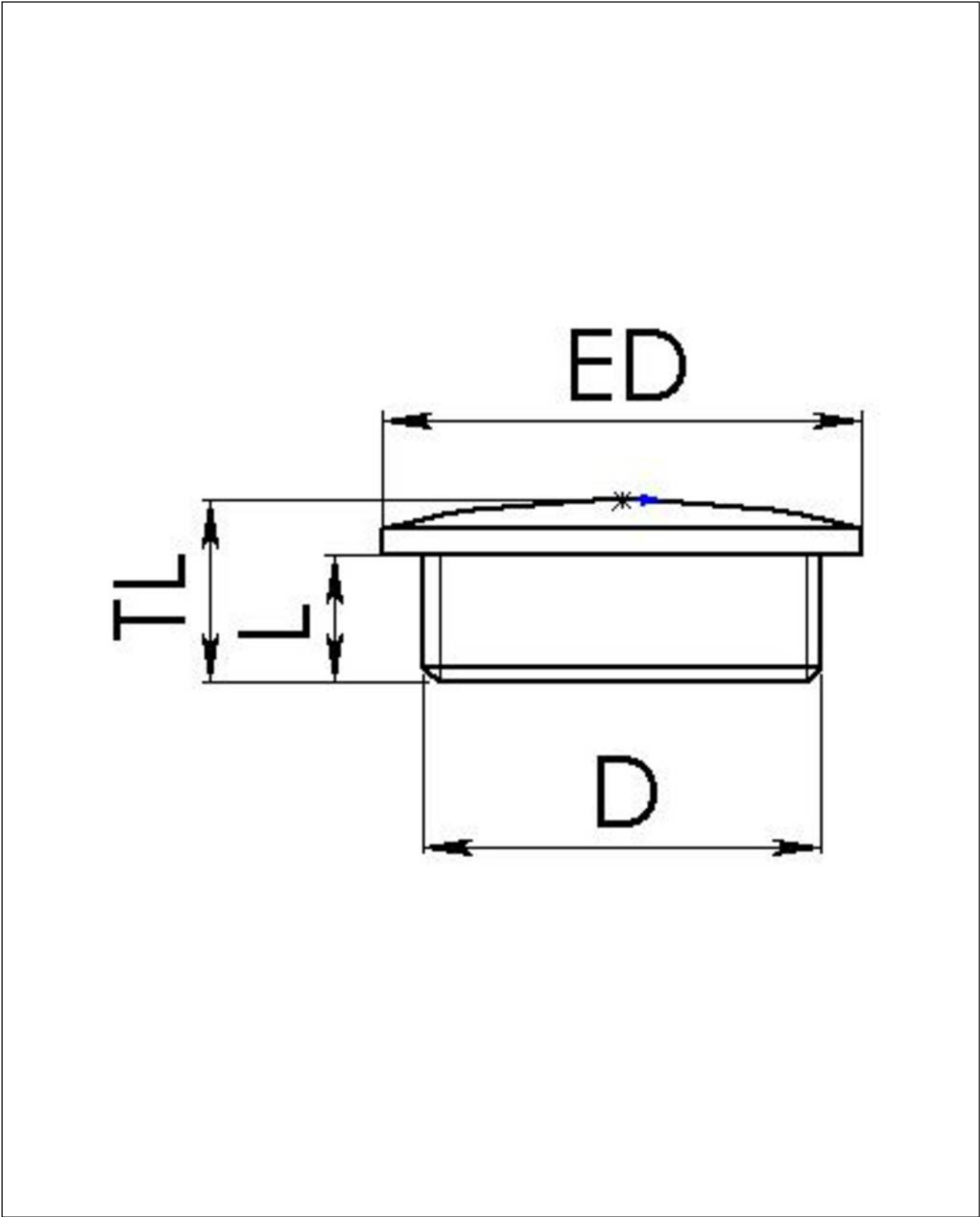

Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk